

Distributed by:




www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached material are the property of its owner.


Jameco Part Number 318844

Specification

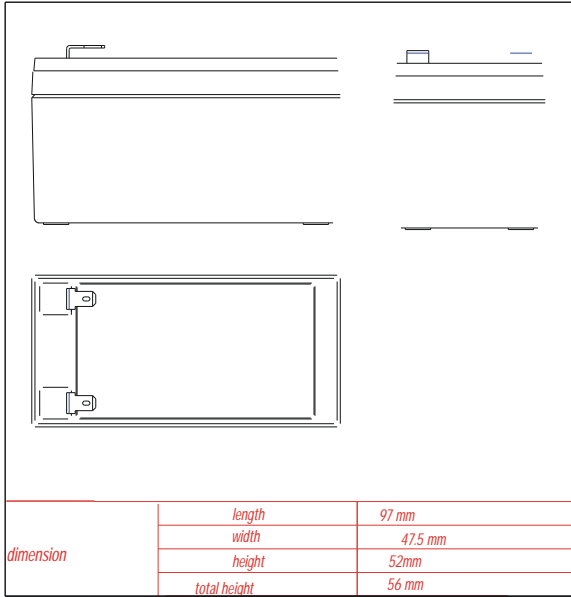


voltage	12 V	capacity	1.2 Ah
resistance	approx. 88 m Ω		
charge voltage	floating (25°C)	voltage	13.6-13.8 V
		current	≤ 0.36A
	cyclic (25°C)	voltage	14.7-15.0 V
		current	≤ 0.36A
design life	floating	25°C	6-8 years
		35°C	3-5 years
	cyclic (25°C)	100%DOD	200 cycles
		50%DOD	600 cycles
		30%DOD	1500 cycles
self discharge(25°C)	one month	4%	
	two months	7%	
	three months	10%	
weight	approx. 650 g		


Charge characteristic

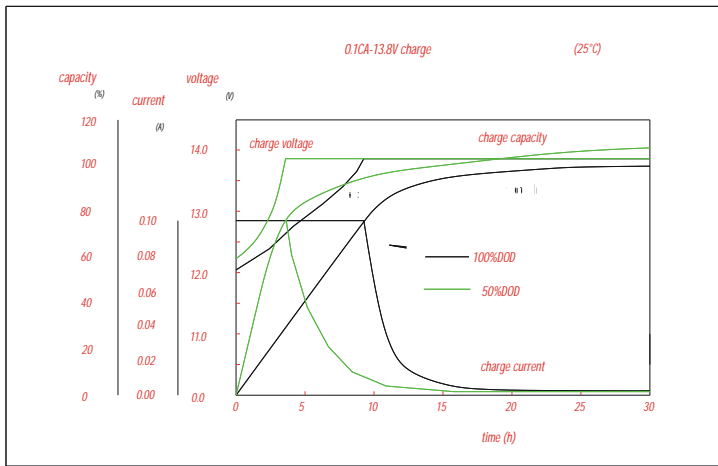

Discharge characteristic

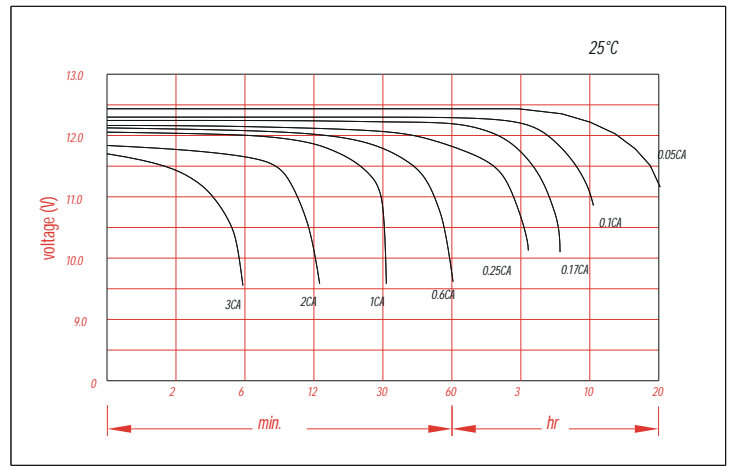

Self-disc. characteristic

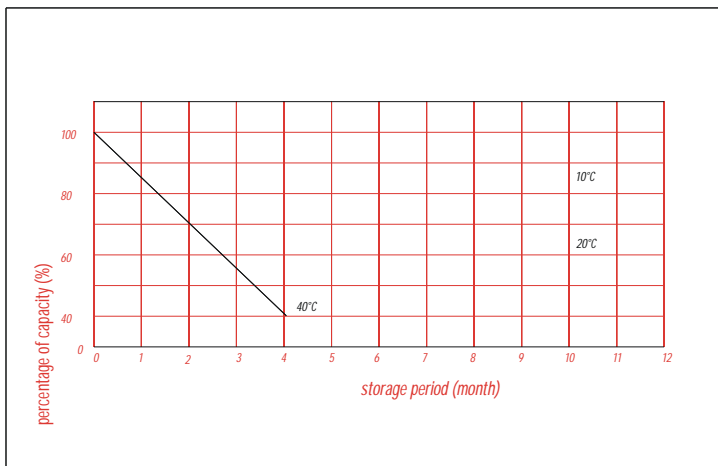

Temperature characteristic

