

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 318852

TYSONIC NON-SPILLABLE SEALED RECHARGEABLE BATTERY

TY12350 12V, 35.0Ah


☆ SPECIFICATION

- NOMINAL VOLTAGE : 12V
- NOMINAL CAPACITY(20 hrs) : 35Ah
- DIMENSIONS
 - TOTAL HEIGHT : 179 mm (7.05 inches)
 - CONTAINER HEIGHT : 163.5 mm (6.44inches)
 - LENGTH : 195.5 mm (7.70 inches)
 - WIDTH : 130 mm (5.12 inches)
- WEIGHT : APPROX 11.5Kg (25.35 lbs)
- MAX DISCHARGE CURRENT : 175A (5 sec)
- STANDARD TERMINALS : FP-09
- CONTAINER MATERIAL : GENERAL GRADE ABS


☆ CHARACTERISTICS

- CAPACITY 25 C / 77 F
 - 20 hr @ 1.75 A : 35 Ah
 - 5 hr @ 5.6 A : 26 Ah
 - 1 hr @ 21 A : 21 Ah
 - 1 C @ 35 A : 17.5 Ah
- INTERNAL RESISTANCE : 8 m Ω
- CHARGING VOLTAGE (25C , 77 F)
 - STANDBY USE : 2.2750.025 V/CELL
:(-3.3mV / C / CELL)
 - CYCLE USE : 2.2750.025 V/CELL
:(-5mV / C / CELL)°
- MAX CHARGING CURRENT : 10.5 A


Discharge Characteristics 25 C (77 F)

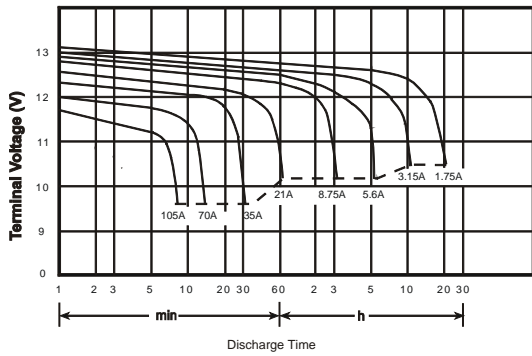

Discharge Current vs Time

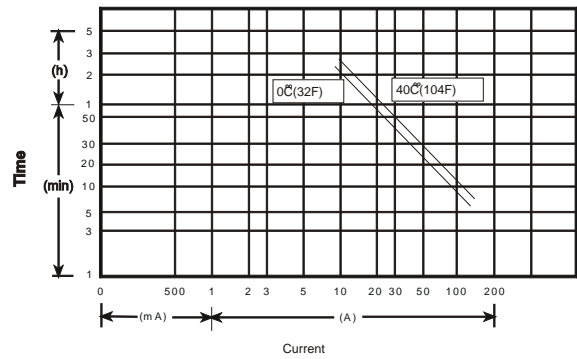

☆ Dimensions

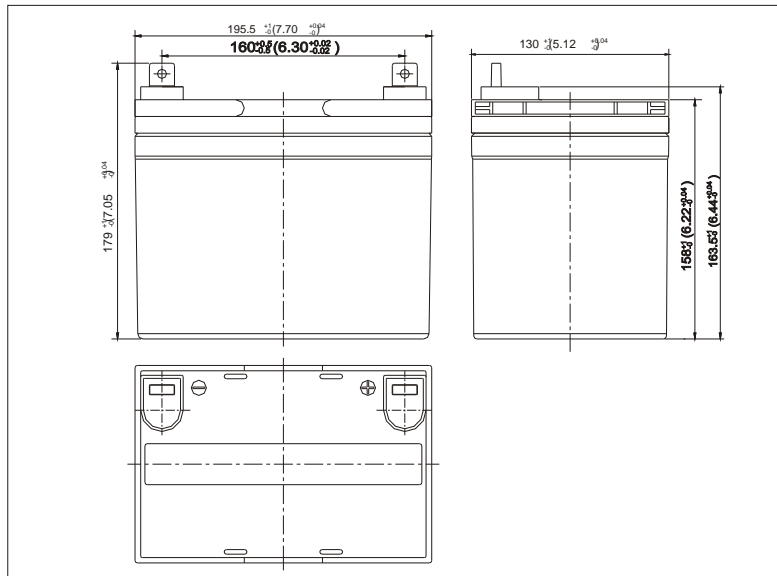

☆ Terminal

