
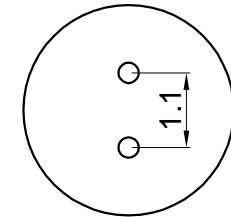


NO.	ITEM	SPECIFICATION
1	Operating Temperature Range	-10°C ~ +60 °C
2	Frequency	32.768 KHz
3	Drive Level	1 mW
4	Frequency Tolerance	± 50 PPM
5	Aging for First Year	± 3 PPM ( Max +25 °C)
6	Load Capacitance	12.5 pF

Rev.	Revision	Date
01	Update	11/9/2011

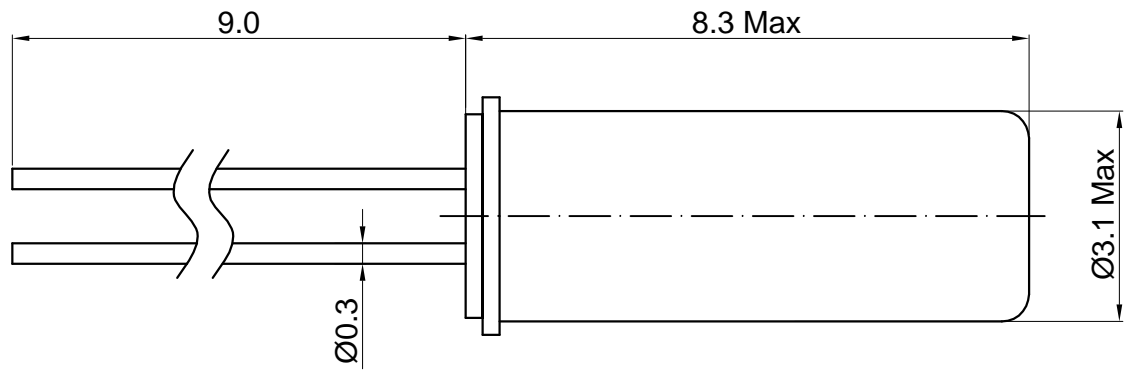

DRAWN	Emily	11/9/2011
CHECKED	Sara	11/9/2011
ENG APPR.		
MFG APPR.		
Q.A.		

UNIT: mm

Sinotech

ECS-.327-12.5-13

SIZE  
A4

P/N  
325244

REV  
01

SCALE: 20:1

Weight(kg):

SHEET 1 OF 1