



## SPECIFICATIONS SHEET

**PRODUCT TYPE : PIEZO BUZZER**

**PRODUCT SERIES : DB-E118**

**DESCRIPTION : PZ BUZZER SINGLE 12VDC PLT ABS SP RoHS**

**COLOR : BLACK**

### ELECTRICAL SPECIFICATIONS

| MODEL NO.               |                | 11S3120LF - TA |
|-------------------------|----------------|----------------|
| OPERATING VOLTAGE RANGE | ( VDC )        | 1.0 ~ 16.0     |
| RATED VOLTAGE           | ( VDC )        | 12.0           |
| * MAX. RATED CURRENT    | ( mA )         | 30.0           |
| * MIN. SOUND OUTPUT     | ( dBA/ 30 cm ) | 100.0          |
| * FREQUENCY             | ( Hz )         | 2900 ± 500     |
| tone NATURE             |                | SINGLE         |
| OPERATING TEMPERATURE   | ( ° C )        | - 20 ~ + 60    |
| TERMINAL                |                | PLATE          |
| HOUSING MATERIAL        |                | ABS            |
| WEIGHT                  | ( g )          | 35.0           |




\* Value applying at rated voltage

### DIMENSIONS


UNIT : mm

TOP VIEW

SIDE VIEW

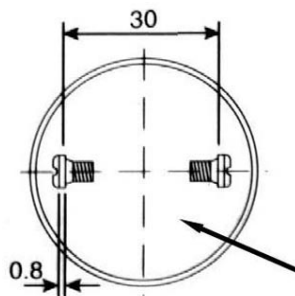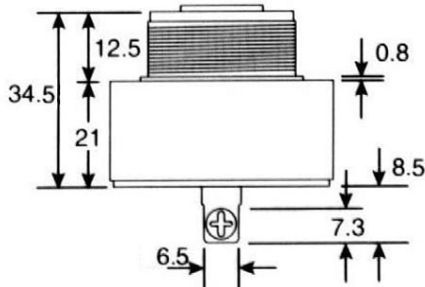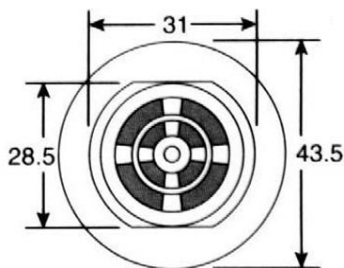

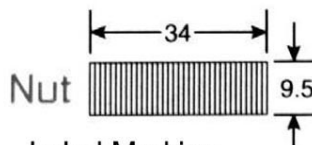

BOTTOM VIEW



Label Marking



Date Code Marking  
" 6 / F \*"  
Year | Month  
6 = 2006 F = Jun.

Approved By :    
Date : 20-Jun.-2006

Prepared By :    
Date : 20-Jun.-2006

| Modify : | Date : | By : |
|----------|--------|------|
|          |        |      |
|          |        |      |
|          |        |      |