

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**

The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 42674

# 8200serie


## DIP PLUG 2.54mm (0.100")

### Specifications:




Contact Resistance: 30mΩmax. at DC 100mA  
 Insulator Resistance: 1000MΩmin. at DC 500V  
 Current Rating: 1 AMP

### Dielectric Withstanding

Voltage: AC 500V For 1 minute  
 Operating Temperature: -55°C~+105°C  
 Contact: Phosphor Bronze  
 Housing: PBT & 40% Glass Fiber (UL 94V-0)

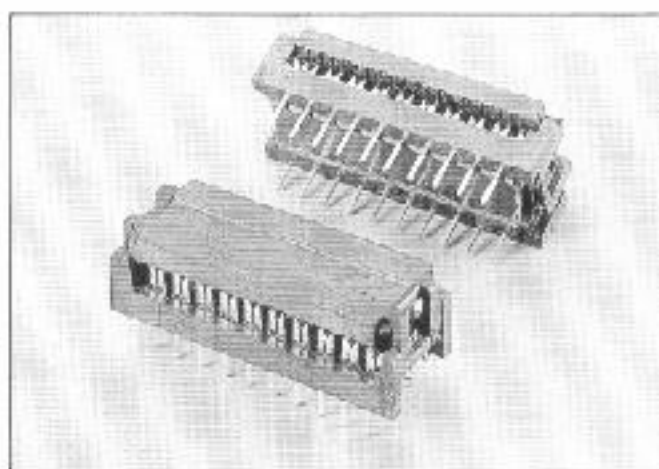

ROHS

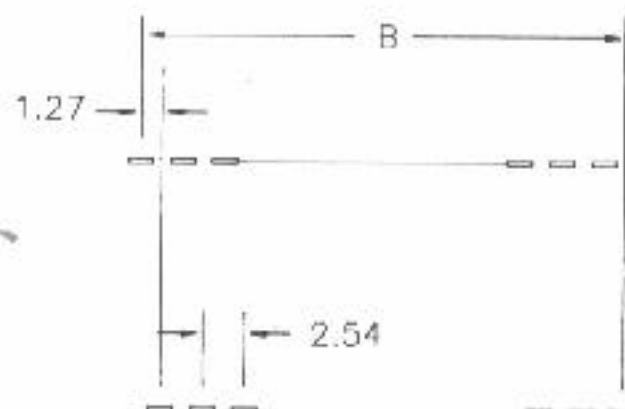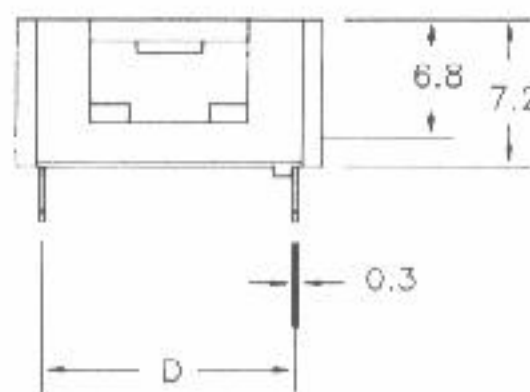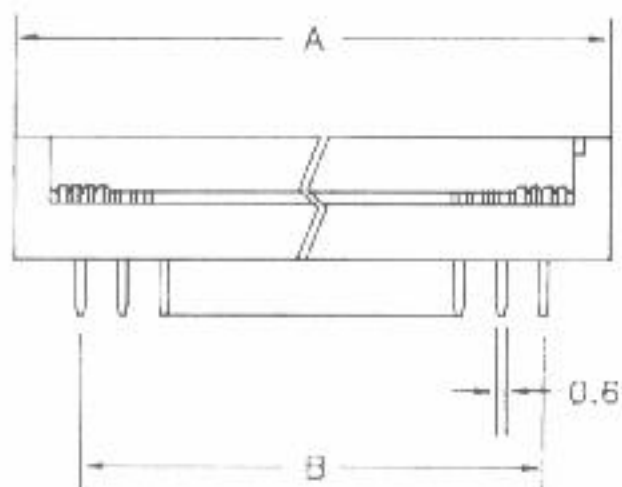

### Dimension

Position	A	B	C	D
8	14.60	7.62	10.60	7.62
10	16.96	10.16	10.60	7.62
14	22.74	15.24	10.60	7.62
16	25.12	17.78	10.60	7.62
18	26.74	20.32	10.60	7.62
20	29.74	22.86	10.60	7.62
24	35.00	27.94	18.18	15.24
28	40.10	33.02	18.18	15.24
40	55.20	48.26	18.18	15.24

**TOP WILLING CO., LTD.**  
 1FL., NO. 3, LANE 39, YU SHYH ROAD,  
 WU-KU HSIANG, TAIPEI HSIEN, TAIWAN  
 TEL: 2-2920757 FAX: 2-2941947