

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.


Jameco Part Number 527161

Housings, Free Hanging or Panel Mount


Product Specification:

Centerline spacing—.250 [6.35]


2, 3, 4, 5, 6, 8 and 10 Circuit, In-Line

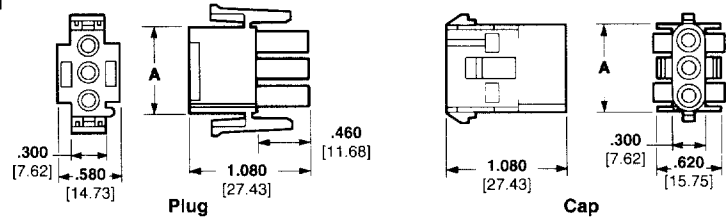


1 Circuit, Free Hanging

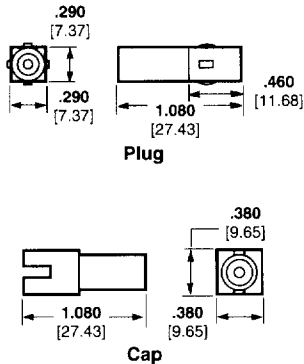

6 Circuit, Matrix

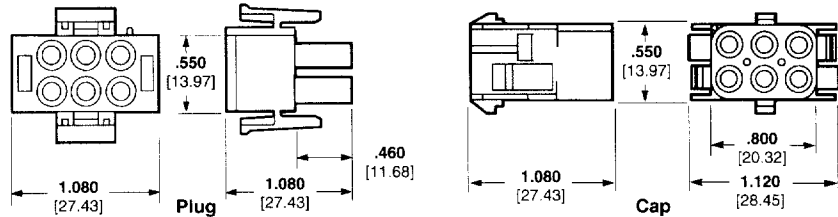

9, 12 and 15 Circuit, Matrix

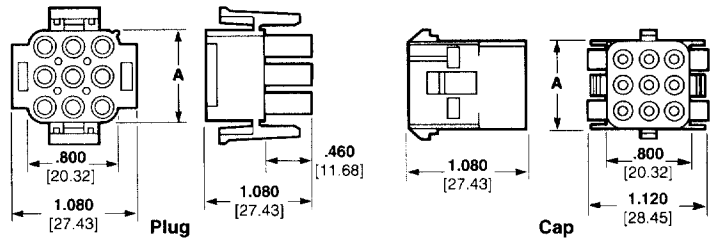

Related Product Data:

Performance Characteristics — page 9015

Contacts — pages 9017 and 9018

Panel Cutout Recommendations — page 9020

Keying Plug — page 9020

Strain Reliefs — pages 9020 and 9021

Mating Headers — pages 9025 thru 9028

Technical Documents: pages 9015 and 9080

Product Specification

108-1031 Universal MATE-N-LOK Connectors

Other Mating Connectors:

Universal MATE-N-LOK II

Housings — pages 9006 thru 9008

Number of Circuits	A Dim.	Housing Part Numbers			
		UL94V-2 Nylon, Natural Color ²		UL94V-0 Nylon ³	
		Plug	Cap	Plug	Cap
1	—	1-350867-0	770421-1	350865-1	350866-1
2	.550 13.97	1-480698-0 ¹	1-480699-0 ¹	350777-1 ¹	350778-1 ¹
3	.800 20.32	1-480700-0 ¹	1-480701-0 ¹	350766-1 ¹	350767-1 ¹
4	1.050 26.67	1-480702-0 ¹	1-480703-0 ¹	350779-1 ¹	350780-1 ¹
5	1.300 33.02	1-480763-0 ¹	1-480764-0 ¹	350809-1 ¹	350810-1 ¹
6	1.550 39.37	640585-1 ¹	926307-1 ¹	640581-1 ¹	926307-3 ¹
		1-480704-0 ¹ 794096-1 ⁴	1-480705-0	350715-1	350781-1
8	2.050 52.07	640586-1 ¹	926308-1 ¹	640582-1 ¹	926308-3 ¹
9	.800 20.32	1-480706-0	1-480707-0	350720-1	350782-1
10	2.550 64.77	926302-1 ¹	926309-1 ¹	926302-3 ¹	926309-3 ¹
12	1.050 26.67	1-480708-0	1-480709-0	350735-1	350783-1
15	1.300 33.02	1-480710-0	1-480711-0	350736-1	350784-1

¹ In-Line style.

² Housing material has 125°C temperature rating.

³ Housing material has 120°C temperature rating.

⁴ Tool Removable.

For complete product information, order Catalog 82181