

Date	Rev.	Description

L01 1.27mm FLAT RIBBON CABLE


UL File No. : E162690
 UL Style : 2651
 Operating Temperature : -20°C to +105°C
 Flammability Rating : UL-VW-1
 Voltage Rating : 300V

Physical

Insulation Material : Polyvinyl Chloride (PVC)
 Conductor : #28AWG (7*0.127) Stranded Tinned Copper
 #26AWG (7*0.16) Stranded Tinned Copper
 Color : Grey With Red Edge

Electrical

Impedance : 115Ω (Unbalanced)
 Capacitance : 12.2 pF/ft.
 Inductance : .14μH/ft.
 Propagation Delay : 1.4 ns/ft.
 Insulation Resistance : 1GΩ/M min.

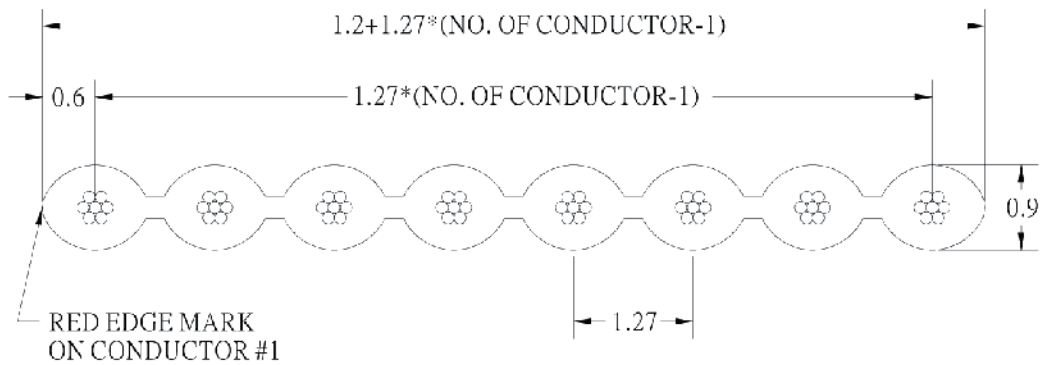

HOW TO ORDER:

L01 - ¹ - ² - ³ - ⁴ UNIT - G (RoHS)

1.NO. OF CONDUCTOR 06 TO 64	2.INSULATION MATERIAL P: PVC	3.WIRE SIZE A: 28 AWG B: 26 AWG	4.CABLE LENGTH / UNIT C: CM F: FEET I: INCH M: METER
--------------------------------	---------------------------------	---------------------------------------	--

DCC. NO.
A4 DRAWING NO.

MATERIAL		GOLDSUN ELECTRONICS CO., LTD.	
DRAWN: Kiki Chen			
VERIFIED PEOPLE: Ada Zheng , Ivy Lan		JAMECO NO. 644121	GOLDSUN NO. 171-40-25
		Description CABLE RIBBON	
		UNIT: mm	SCALE: SHEET 1 OF 1
		CAS No: ERN No:	
		Rev. 1	