

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 644615



Cablex International L.L.C.


TEL: +86-769-7770~3,5~6

FAX: +86-769-345-7779

SPECIFICATION

SPEC No:	UTP 24AWG 4PR STRANDED CAT.5 e						
Customer		Customer NO.		Date:	09/4/07	Sample NO:	
UL File NO.	E151955-A	UL Style:	UL+CM	Edition:	Original Edition	Spec NO.	SU5E-7196
CSA FILE NO.	LL79189	CSA Style:	FT4				
Construction Item			Construction ItemA				
Conductors	Construction	AWG	24# (7/32)				
	Material	--	Bare Copper				
	Filler Material	--	--				
	O.D.	mm	0.196 ± 0.005				
Insulators	Material	--	HD-PE				
	Diameter	mm	0.98 ± 0.03				
	Average Thickness	mm	0.20 ± 0.02				
Assembly	Diameter	mm	4.3Ref				
Shielding	AL/PET Tape	mm	/				
	Overlapping Rate	%	/				
	Drain Wire	mm	/				
	Braid		/				
Outside Jacket	Material	--	PVC				
	Diameter	mm	5.7 ± 0.2				
	Average Thickness	mm	0.458 Above				
	Color	--	GY126				
	Marking Color	--	Spray Blue Font				
Marking	Marking NO.		350MHZ TYPE CM 24AWG 75°C (UL) E151955-A CSA LL79189 CMG ETL VERIFIED TIA/EIA-568-B.2 CAT.5E UTP 4PR CABLE MASTER LOT NO. RoHS COMPLIANCE				

Structural picture:

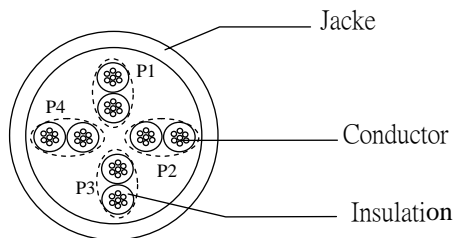

COLOR CODE

- P1. BLUE* WHITE/BLUE
- P2. ORANGE* WHITE/ORANGE
- P3. GREEN* WHITE/GREEN
- P4. BROWN* WHITE/BROWN