

Distributed by:


JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242




The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 70755



P.C.B. Socket 2.54mm (0.100")

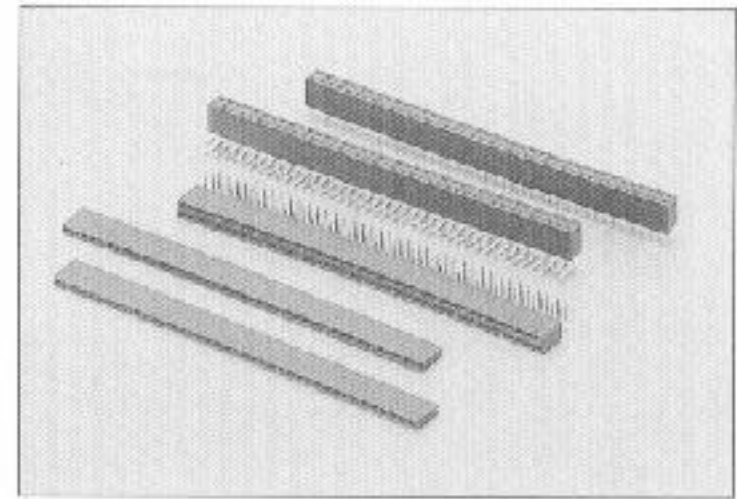



ROHS

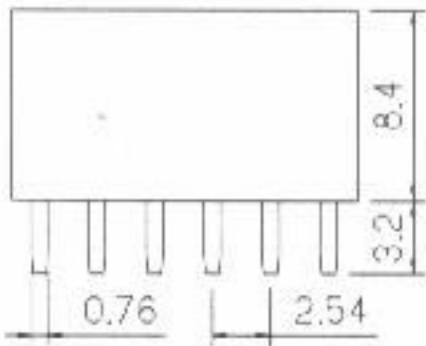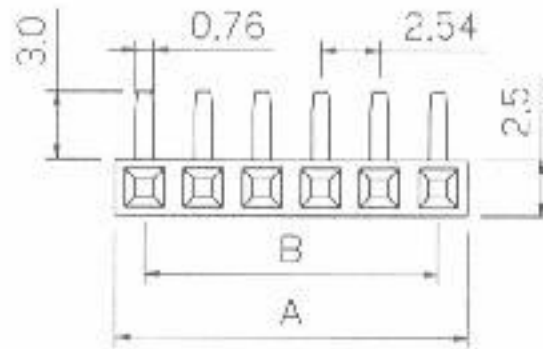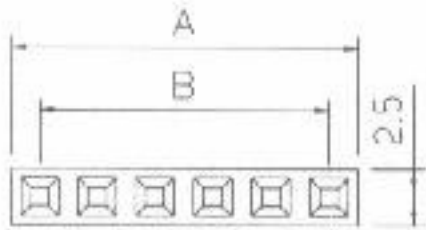

Straight Type

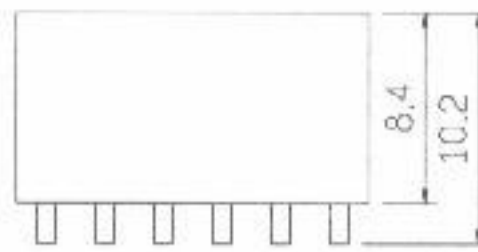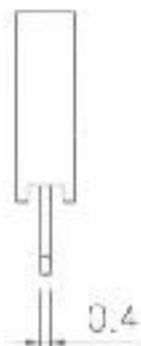


Right Angle Type
Single Row

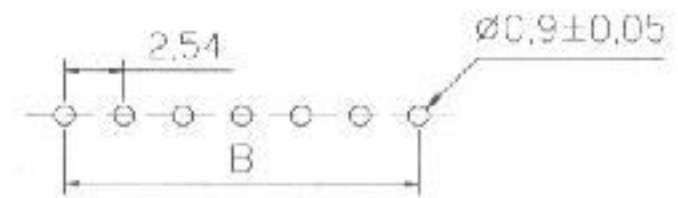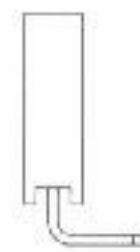




Single Row P.C.B. Layout

Dimensions



Positions	2 thru 40, 4 thru 80
A	2.54 * Position No.
B	2.54 * Position No. - 2.54

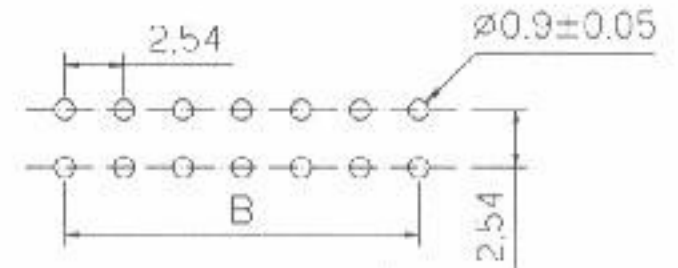


Double Row P.C.B. Layout

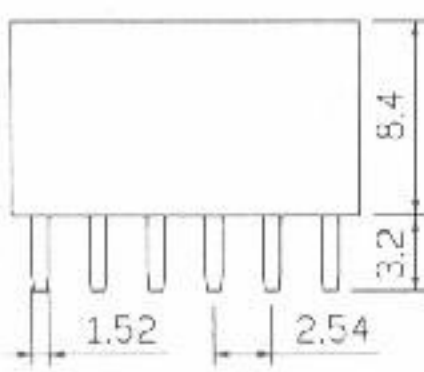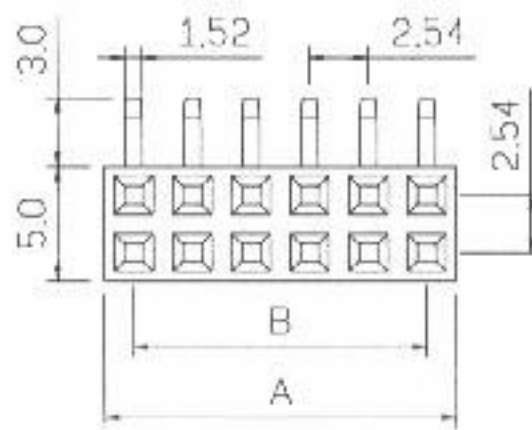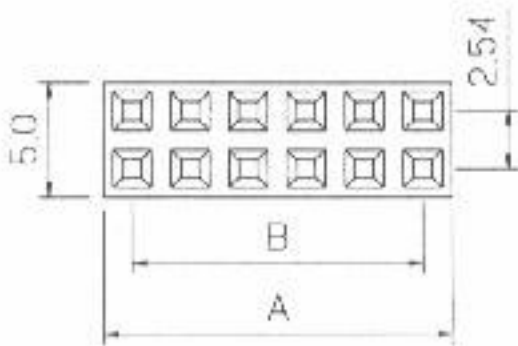

Straight Type

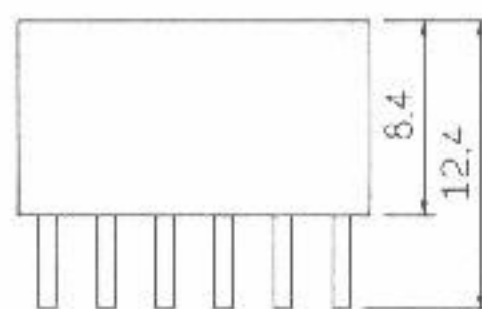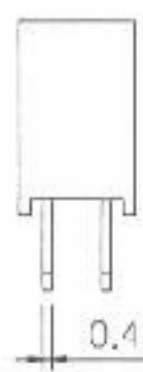

Right Angle Type

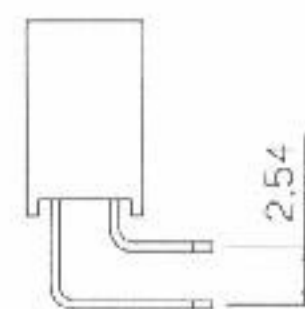

Double Row

Product Specification

Material

Insulator : Glass-Filled Thermoplastic
UL94V-0 rates, Color-Black

Contact : Brass or Phosphor Bronze
Plated full gold or selected gold in
mating area, 100u" min. tin-lead on
an termination area, with entire contact
under-plated 50u" min. Nickel

Electrical

Contact Resistance : 20 milliohms
Max at 1 AMP DC.

Insulation Resistance : 5000
megohms at 500 VDC

Dielectric Withstanding Voltage :
500 VAC/rms 60Hz for 1 minute

Current Rating : 1 AMP

Volatge Rating : , 250 VAC/rms
60Hz