


Miniature Toggle Switch

TYPE: MTS-102-C4


Specification

1. Rating: 6A 125V AC; 3A 250V AC
2. Contact R: 20mΩ max
3. Insulation R: 500V DC 1000MΩ min
4. Dielectric Strength: 1 Minute 1500V AC
5. Operating Temperature: -25°C~+85°C
6. Electrical Life: 10, 000 Cycles


Outline Drawing

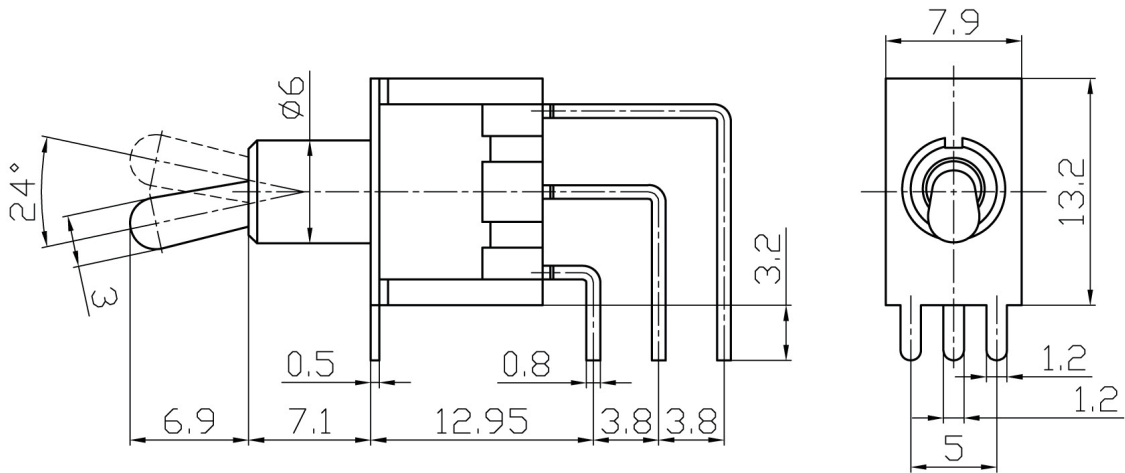

Mounting

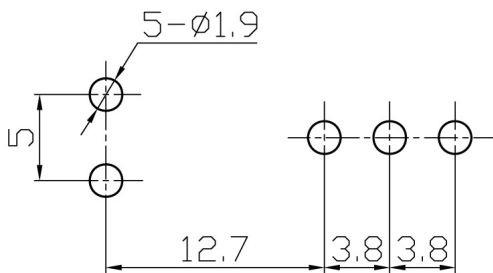

Circuitry

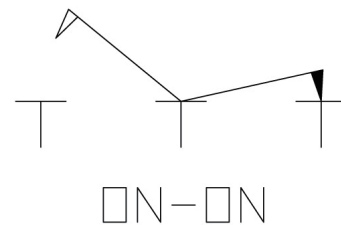

| | | | |
|--|--------------------------------|--------------|--------------------|
| GOLDSUN ELECTRONICS CO., LTD. | | | |
| JAMECO NO. 71597-100 | GOLDSUN NO. Mfg# MTS-102-C4 | | |
| Description MINIATURE TOGGLE SWITCH SPDT ON-ON, PC RIGHT ANGLE | | | Rev. 1 |
| UNIT: mm | SCALE: | SHEET 1 OF 1 | CAS No: ERN No: |