

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**

The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 71909

**BNC Series Connectors**


Commercial Grade BNC Series Connectors  
Suitable for Video and Headend Applications  
Nickel-Plated Brass/Zinc Construction  
Gold-Plated Contacts – Delrin Insulator

- 200-122** BNC Plug Twist-On for RG6 ◀ NEW
- 200-131** BNC Plug Crimp 2pc RG59
- 200-134** BNC Plug Crimp 2pc RG58
- 200-135** BNC Jack Crimp 2pc RG59/62
- 200-136** BNC Jack Crimp 2pc RG58
- 200-137** BNC Jack Crimp 2pc RG59 Plenum
- 200-138** BNC Plug Crimp 2pc RG59 Plenum
- 200-139** BNC Plug Crimp 2pc RG6
- 200-140** BNC Plug Crimp 3pc RG59 Plenum
- 200-141** BNC Plug Crimp 3pc RG6
- 200-142** BNC Plug Twist-On for RG59/62
- 200-143** BNC Plug Crimp 3pc RG59/62
- 200-144** BNC Plug Clamp for RG59/62
- 200-145** BNC Plug Crimp 3pc for RG58
- 200-146** BNC Plug Twist-On for RG58
- 200-147** BNC Plug Crimp 3pc RG58A/C  
Includes PVC and Plenum Ferrules
- 200-148** BNC Jack Isolated Panel Mount
- 200-156** BNC Jack Panel – 1/8" Holes


**BNC Series Adapters**

Commercial Grade BNC Series Adapters  
Suitable for Video and Headend Applications


- 200-130** F Jack to BNC Plug
- 200-132** UHF Jack to BNC Plug
- 200-133** BNC Coupler Plug-Plug
- 200-150** BNC Tee Adapter Jack-Jack-Jack
- 200-155** BNC Tee Adapter Jack-Plug-Jack
- 200-158** BNC Angle Adapter Jack-Plug
- 200-160** BNC Coupler Jack-Jack
- 200-165** BNC Coupler Jack-Jack Panel
- 200-173** RCA Jack to BNC Plug
- 200-174** BNC Terminator 50Ω 1% 1/2W  
with 6" Brass Chain
- 200-175** BNC Terminator 50Ω 5% 1/2W
- 200-176** BNC Terminator 50Ω 1% 1/2W
- 200-177** BNC Terminator 75Ω 5% 1/2W
- 200-178** BNC Terminator 75Ω 1% 1/2W
- 200-179** BNC Terminator 93Ω 5% 1/2W
- 200-180** BNC Terminator 93Ω 1% 1/2W
- 200-834** Mini-UHF Jack to BNC Plug

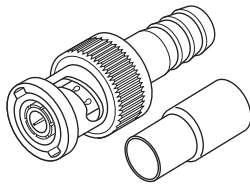


**200-131** RG59  
**200-134** RG58  
**200-138** RG59/62 Plenum  
**200-139** RG6

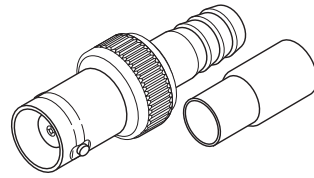


**200-135** RG59/62  
**200-136** RG58  
**200-137** RG59/62/Plenum

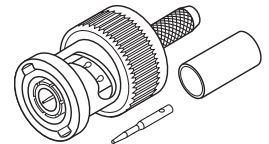



**200-140** RG59/62 Plenum  
**200-141** RG6  
**200-143** RG59/62  
**200-145** RG58  
**200-147** RG58A/C 2-Ferr.

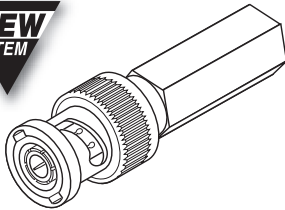


**200-122** RG6  
**200-142** RG59/62  
**200-146** RG58

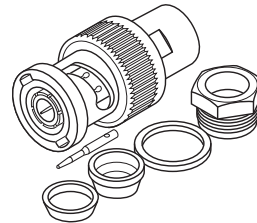


**200-144** RG59/62 UG260/U **200-148**

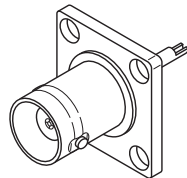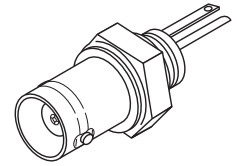


**200-156**

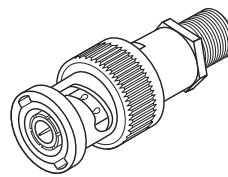


**200-130**

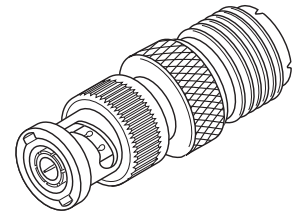


**200-132** UG255A/U

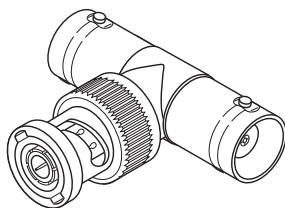


**200-155** UG274B/U

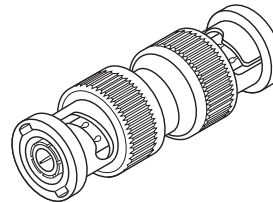


**200-133** UG491B/U

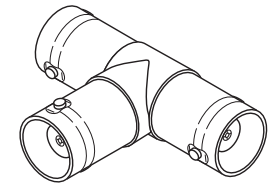


**200-150**

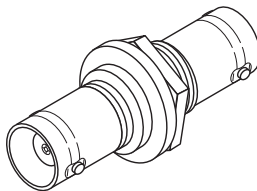


**200-165** UG492A/U

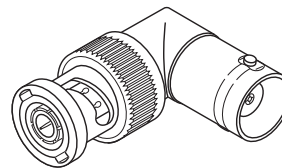


**200-158** UG306B/U

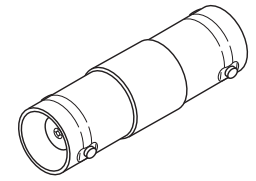


**200-160** UG914/U

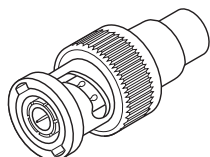

**200-173**

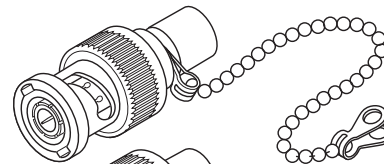

**200-174** 50Ω 1% Chain  
**200-175** 50Ω 5%  
**200-176** 50Ω 1%  
**200-177** 75Ω 5%  
**200-178** 75Ω 1%  
**200-179** 93Ω 5%  
**200-180** 93Ω 1%

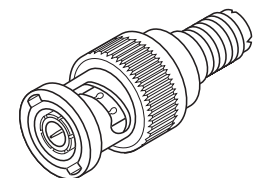

**200-834**