

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242


The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 741511



6.71mm (.264") Pitch .093" Pin and Socket Header

5219

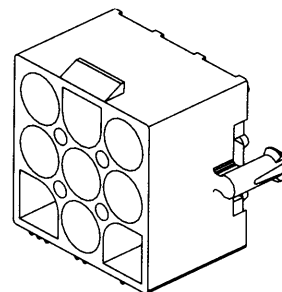

FEATURES AND SPECIFICATIONS

Features and Benefits

- Positive lock
- Fully isolated terminals
- Polarized housing assures proper mating

Reference Information

Packaging: Bag
 UL File No.: E29179
 CSA File No.: LR19980
 TUV License No.: R75107
 Mates With: 3191 receptacle
 Designed In: Inches


Electrical

Voltage: 600V
 Current: 12.0A max.
 Dielectric Withstanding Voltage: 5000V AC rms

Physical

Housing: Nylon, UL 94V-2
 Contact: Brass
 Plating: Tin
 Operating Temperature: -40 to +105°C

CATALOG DRAWING (FOR REFERENCE ONLY)

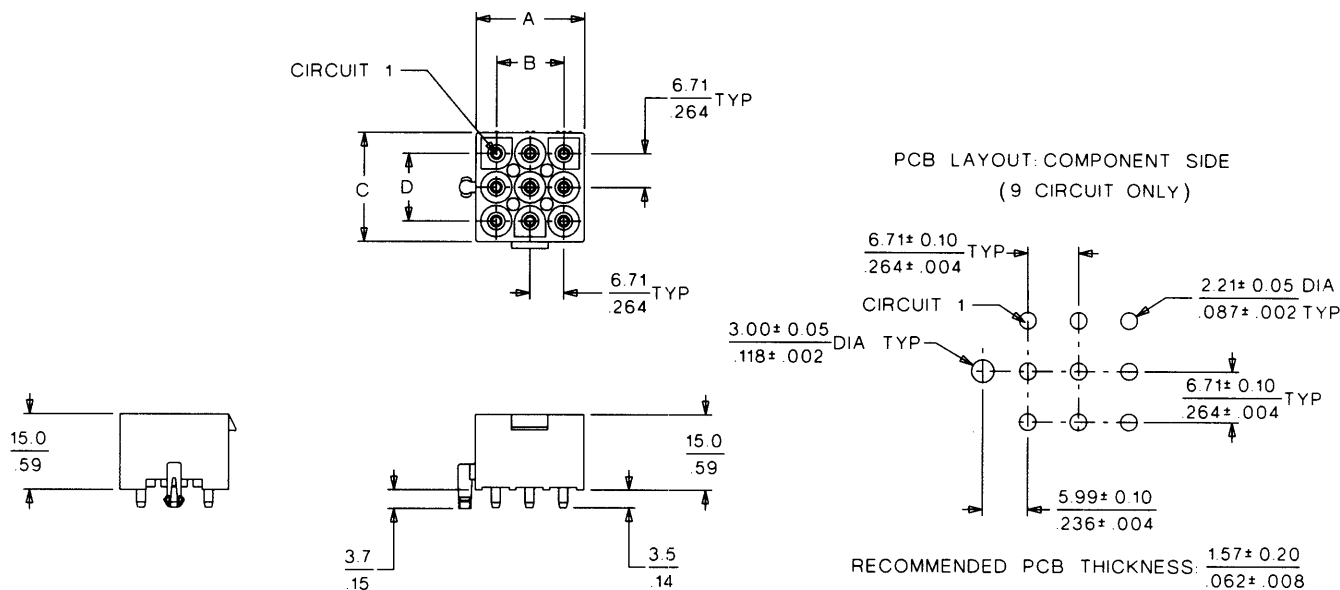

ORDERING INFORMATION AND DIMENSIONS

Circuits	Order No.	Amperes Per Circuit	Dimension			
			A	B	C	D
2	15-31-1026	12	14.30 (.560)	6.71 (.264)	7.60 (.300)	
3	15-31-1036	11	21.00 (.830)	13.42 (.528)	7.60 (.300)	
4	15-31-1046	9	27.70 (1.090)	20.13 (.792)	7.60 (.300)	
6	15-31-1066	9	21.00 (.830)	13.42 (.528)	14.30 (.560)	6.71 (.264)
9	15-31-1096	9	21.00 (.830)	13.42 (.528)	21.00 (.830)	13.42 (.528)