

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**

The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 742602

### PC Board Right-Angle Header with Fix Belt

**Material:**

**Housing** — Thermoplastic  
**Flammability Rating** — UL94V-2  
**Contacts** — Copper Alloy


**Related Product Data:**

Used by the disk drive industry

**Technical Document:**



**Product Specification**  
108-5155

**4 Circuit, In-Line**

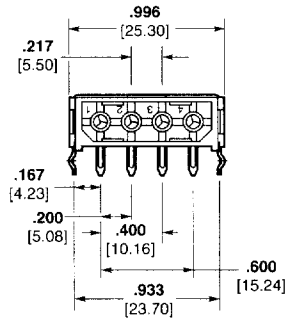

**Part Number** 174552-1

**Notes:** Mates with socket housing (plug) Part Number 1-480424-0 on page 9034. Other mating connectors include a vertical PC board socket header and the insulation displacement connectors (IDC).

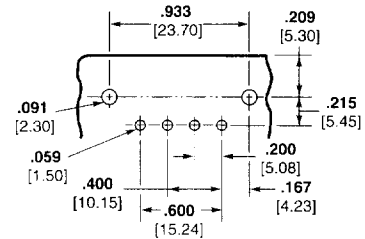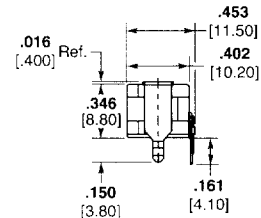

**Recommended PC Board Hole Layout**  
.062 [1.57] thick PC Board

### PC Board Right-Angle Headers with Fix Belt

**Reverse Polarization**

**Material:**

**Housing** — Nylon  
**Flammability Rating** — UL94V-2  
**Contacts** — Tin plated, Copper alloy




**Related Product Data:**

Used by the disk drive industry

**Technical Document:**

**Product Specification**  
108-5155

**4 Circuit, In-Line**

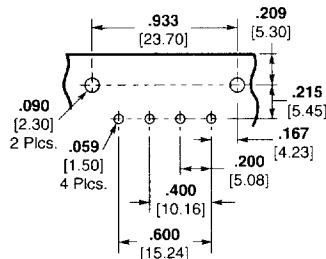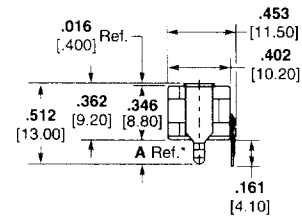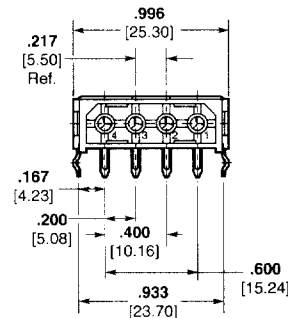

**Part Number** 174804\*

**Recommended PC Board Hole Layout**  
.062 [1.57] thick PC Board

| Part Numbers | A Dim.*      | Description          |
|--------------|--------------|----------------------|
| 174804-1     | .150<br>3.80 | Long Clamp with Kink |
| 174804-2     | .150<br>3.80 | Clamp without Kink   |
| 174804-3     | .116<br>2.95 | Short Clamp          |

For complete product information, order Catalog 82181

**Notes:** Mates with socket housing (plug) Part Number 1-480424-0 on page 9034. Other mating connectors include a vertical PC board socket header and the insulation displacement connectors (IDC).