


DB-E78 series Piezo Buzzer

P/N 76021

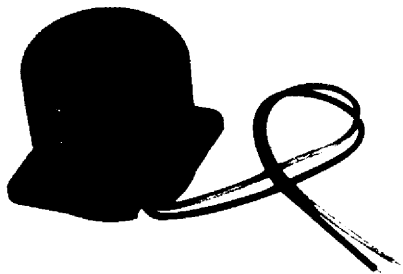

color Black
ABS Housing Material
Leadwire Terminal



ELECTRICAL SPECIFICATIONS

Model No.	753120	753240	7P3120	7D3120
Operating Voltage (VDC)	1.5 - 16	1.5 - 28	3 - 15	3 - 15
Rated Voltage (VDC)	12	24	12	12
* Max. Rated Current (mA)	15	20	10	20
* Min Sound Output (dBA/30cm)	95	95	90	95/90
* Frequency (Hz)	3500-500		3200-500	
Tone Nature	single	single	pulse	dual
Operating Temperature (°C)	-20 ~ +60	-20 ~ +60	-20 ~ +60	-20 ~ +60
Weight (g)	15	15	15	15


* Value applying at rated voltage

MENSIONS

 Top View

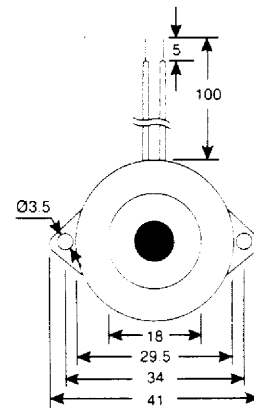

Side View

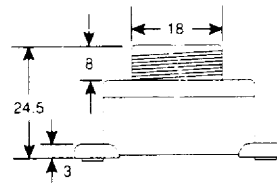

all dimensions are in mm