

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 76065

SPECIFICATIONS SHEET

PRODUCT TYPE : MAGNETIC BUZZER

PRODUCT SERIES : TDB

DESCRIPTION : MT BUZZER SINGLE 5VDC PIN NORYL

SP RoHS

COLOR : BLACK


ELECTRICAL SPECIFICATIONS

MODEL NO.	TDB05LF - PN	
OPERATING VOLTAGE RANGE (VDC)	4.0 ~ 7.0	
RATED VOLTAGE (VDC)	5.0	
* MAX. RATED CURRENT (mA)	30.0	
* MIN. SOUND OUTPUT (dBA/ 10 cm)	85.0	
* FREQUENCY (Hz)	2300 ± 300	
TONE NATURE	SINGLE	
OPERATING TEMPERATURE (° C)	- 40 ~ + 85	
TERMINAL	PIN	
HOUSING MATERIAL	NORYL	
WEIGHT (g)	2.0	

* Value applying at rated voltage

DIMENSIONS

UNIT : mm

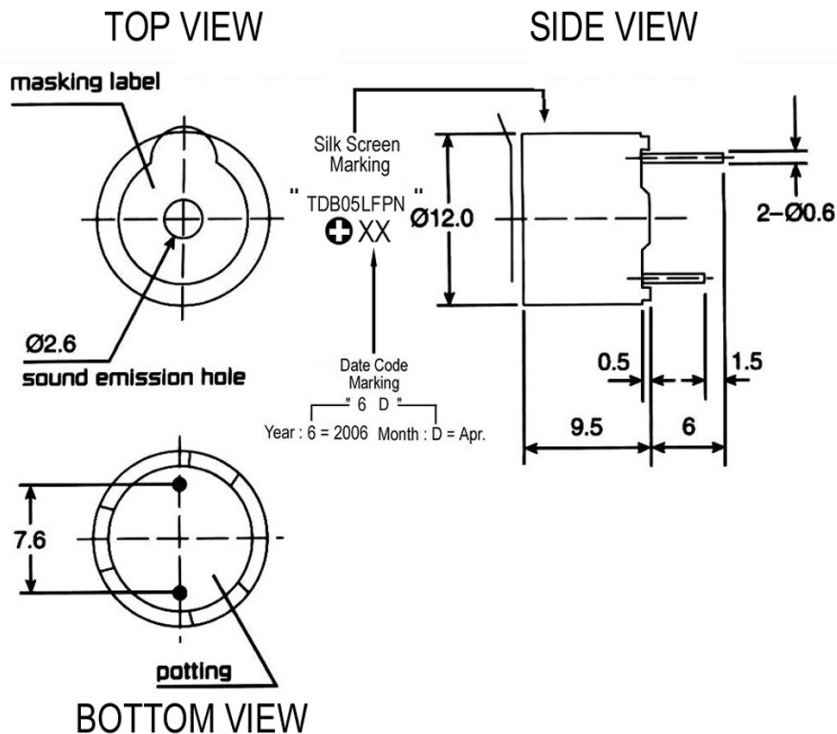

Approved By :
Date : 26-Apr.-2006

Prepared By :
Date : 26-Apr.-2006

Modify :	Date :	By :
Add Date Code Marking	26-Apr-06	Joey