

Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers

* 5V Web Code: **TAS**



* 12V Web Code: **LBZ**



695050



1581249



1809936



1951490

mm to Inches Conversion Chart

mm	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	76	80	92	95	97	120	127	150	172
Inches	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.99	3.15	3.63	3.74	3.82	4.69	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2095285	Adda	AD1505LX-K90	5	15 x 15 x 6	0.1	Hypro	50	0.25	CE	9.6	5.5"	\$10.95	\$9.95	\$8.95	\$7.95
2099809	Sunon	KDE0501PDB3-8	5	20 x 20 x 8	1.2	Ball	80	0.4	UL/CUL	21	5.5"	8.95	7.95	6.95	6.25
2095277	Adda	AD2005LX-G70	5	20 x 20 x 10	0.6	Hypro	80	0.4	UL/CUL/CSA/TUV/CE	20	5.5"	8.95	7.95	6.95	6.25
131247	Adda	AD0205LX-G50	5	25 x 25 x 10	1.8	Sleeve	100	0.5	UL/CSA/CE	15.6	5.5"	14.95	13.49	11.95	10.95
695050	Sunon	GM0502PFV2-8	5	25 x 25 x 10	3.0	Vapo	80	0.4	UL/CUL	16	5.5"	12.95	11.49	9.95	8.95
1708481	Sunon	KDE0502PHB3-8 (MS)	5	25 x 25 x 15	1.8	Ball	80	0.4	UL/CUL	16	4"	10.95	9.95	8.95	7.95
1928311	Adda	AD0305LB-K70	5	30 x 30 x 6.8	2.5	Ball	60	0.3	UL/CUL/TUV/CE	30	6"	6.95	6.25	5.59	4.95
2099497	Adda	AD0305MX-K70	5	30 x 30 x 6.8	3.3	Hypro	120	0.6	UL/CSA/TUV/CE	27.9	5.5"	8.95	7.95	6.95	6.25
1951211	Sunon	KDE0503PEV1-8 (MSN)	5	30 x 30 x 6.8	4.9	Vapo	180	0.9	UL/TUV/CE	28	6"	7.95	6.95	6.25	5.59
1951220	Sunon	KDE0503PEB3-8 (MSN)	5	30 x 30 x 6.8	4.9	Ball	180	0.9	UL/TUV/CE	28	6"	9.95	8.95	7.95	6.95
2099489	Adda	AD0305HX-G50	5	30 x 30 x 10	4.2	Hypro	170	0.85	UL/CUL/TUV/CE	30.7	5.5"	8.95	7.95	6.95	6.25
1950534	Sunon	KDE0503PFB1-8V	5	30 x 30 x 10	5.1	Ball	180	0.7	UL/TUV	22.5	5"	9.95	8.95	7.95	6.95
2120031	Sunon	GM0503PEV1-8N.GN	5	30 x 30 x 10	5.5	Vapo	140	0.7	UL/CSA/TUV	23	6"	9.95	8.95	7.95	6.95
2095293	Adda	AD305HB-D50	5	30 x 30 x 15	3.7	Ball	130	0.65	UL/CUL/TUV/CE	22.5	11"	9.95	8.95	7.95	6.95
1708457	Sunon	KDE0504PEB3-8 (MS)	5	40 x 40 x 6.8	3.5	Ball	90	0.45	UL/CUL/TUV	20	6"	8.95	7.95	6.95	5.95
1928361	Adda	AD0405MB-K90 (S)	5	40 x 40 x 6.8	5.5	Ball	90	0.45	UL/TUV/CE	25	6"	10.95	9.95	8.95	7.95
1928353	Adda	AD0405HB-K90	5	40 x 40 x 6.8	6.0	Ball	120	0.6	UL/CUL/TUV/CE	30	5"	11.95	10.95	9.95	8.95
1581249	Sunon	KDE0504PFB3-8	5	40 x 40 x 10	4.6	Ball	70	0.35	UL/CUL	23.5	12"	6.95	6.25	5.59	4.95
196373	Sunon	KD0504PFB2-8	5	40 x 40 x 10	5.5	Ball	90	0.5	UL/CUL	23	12"	8.95	7.95	6.95	5.95
2121295	Adda	AD0405MB-G76	5	40 x 40 x 10	5.7	Ball	110	0.40	UL/CSA/TUV/CE	20	11" ¹	8.95	7.95	6.95	5.95
1928370	Adda	AD0405HS-G70	5	40 x 40 x 10	6.7	Sleeve	190	0.95	UL/CUL/TUV/CE	25	3" w/conn	5.95	5.35	4.79	4.39
1581265	Sunon	KDE0504PFS1-8	5	40 x 40 x 10	7.0	Sleeve	190	1.0	UL/CUL	27	12"	6.95	6.25	5.59	4.95
1951238	Sunon	KDE0504PFB1-OC	5	40 x 40 x 10	7.5	Ball	200	1.0	UL/CE	28	12"	7.95	6.95	6.25	5.59
1952741	Elina	KDC050420MB	5	40 x 40 x 20	6.8	Ball/Sleeve	210	1.0	UL/CUL/TUV	25.5	12"	7.95	6.95	6.25	5.59
2120057	Sunon	KD0504PKB2(2).GN	5	40 x 40 x 20	7.7	Dual ball	142	0.7	UL/CSA/TUV	22	12"	7.95	6.95	6.25	5.59
1951406	Delta	AFB0405HD-R00	5	40 x 40 x 20	8.5	Ball	400	2.0	UL/CUL/TUV/CE	33	12" ¹	6.95	6.25	5.59	4.95
2095251	Adda	AD4505MX-K90	5	45 x 45 x 6	7.1	Hypro	120	0.6	CE	25.5	5.5"	8.95	7.95	6.95	6.25
136494	Delta	AFB0505LA	5	51 x 51 x 10	7.4	Ball/Sleeve	80	0.4	UL/CE/CSA/VDE	26	11"	6.95	6.25	5.59	4.95
1950500	Sunon	KDE0505PFB1-8	5	51 x 51 x 10	10.2	Ball	170	0.9	UL/TUV	31.5	12"	8.95	7.95	6.95	6.25
136275	Delta	BFB0505L [†]	5	51 x 51 x 15	2.5	Ball	140	0.7	UL/CE/CSA/VDE	26.5	12"	9.95	8.95	7.95	6.95
136283	Elina	KDC050515MB	5	51 x 51 x 15	12.7	Ball/Sleeve	380	4.0	UL/CE/CUL/TUV	28	11"	7.95	6.95	5.95	4.95
1809936	Sunon	KD0505PHB2 (GN)	5	51 x 51 x 15	12.7	Ball	180	0.8	UL/CUL/TUV/CE	27.8	12"	9.95	8.95	7.95	6.95
1809944	Sunon	KDE0506PHB3	5	60 x 60 x 15	15.2	Ball	240	1.2	UL/CUL/TUV/CE	26.5	12"	8.95	7.95	6.95	6.25
2081756	Adda	AD0605HB-D71GL	5	60 x 60 x 15	16.6	Ball	370	1.8	UL/CUL/CE	32	6"	6.95	5.95	5.25	4.95
1708431	Sunon	KD0506PHB2	5	60 x 60 x 15	18.5	Ball	380	1.9	UL/CUL/TUV/CE	32	12"	9.95	8.95	7.95	6.95
1951414	Delta	AFB0605HD	5	60 x 60 x 20	16.6	Ball	240	1.2	UL/CUL/TUV/CE	28	12"	8.95	7.95	6.95	6.25
355493	Sunon	KD0506PTS3	5	60 x 60 x 25	15.9	Sleeve	230	1.2	UL/CUL/CE	26.7	6.5" w/conn	5.95	5.25	4.59	3.95
134869	Delta	AFB0605M	5	60 x 60 x 25	16.2	Ball	220	1.1	UL/CE/CSA/TUV	24.5	12"	6.95	6.25	5.59	4.95
1951078	Mechatronics	F6025E05B2-FS	5	60 x 60 x 25	24	Ball	700	3.5	UL/CUL	36	12" ²	8.95	7.95	6.95	6.25
1951086	Mechatronics	F8025E05B2-FS	5	80 x 80 x 25	46	Ball	800	4.0	UL/CUL	32	12" ²	9.95	8.95	7.95	6.95
1951094	Mechatronics	E9225M05B2-FS	5	92 x 92 x 25	44	Ball	560	2.8	UL/CUL	32	12" ²	8.95	7.95	6.95	6.25
1951107	Mechatronics	F1238L05B2-FS	5	120 x 120 x 38	94	Ball	800	4.0	UL/CUL	36	12" ²	10.95	9.95	8.95	7.95
2095269	Adda	AD2012LX-K70	12	20 x 20 x 6	0.6	Hypro	60	0.72	CE	19.5	5.5"	8.95	7.95	6.95	6.25
2100363	Adda	AD0212LX-K50-LF	12	25 x 25 x 6	1.8	Hypro	60	0.3	UL/CUL/TUV/CE	20.5	5.5"	9.95	8.95	7.95	6.95
2095306	Adda	AD0212MB-K50 (S)	12	25 x 25 x 6	2.4	Ball/Sleeve	90	1.08	UL/CUL/TUV/CE	26	5.5"	11.95	10.95	9.95	8.95
1951641	Adda	AD0212LB-G50 (GL)	12	25 x 25 x 10	1.8	Ball	70	0.84	UL/CUL/CE	15.6	5.5"	10.95	9.95	8.95	7.95
2121316	Adda	AD0212MX-G50GL	12	25 x 25 x 10	2.3	Hypo	80	0.4	UL/CUL/TUV/CE	23.1	5.5"	10.95	9.95	8.95	7.95
1708449	Sunon	KDE1202PFB1-8 (V)	12	25 x 25 x 10	3.1	Ball	83	1.0	UL/CUL	33	6"	10.95	9.95	8.95	7.95
212767	Sunon	KDE1203PFB3-8 (V)	12	30 x 30 x 10	3.2	Ball	50	0.6	UL/CE	18.5	6"	8.95	7.95	6.95	6.25
1708465	Sunon	KDE1203PFB2-8 (MS)	12	30 x 30 x 10	4.2	Ball	66	0.8	UL/CUL	25	6"	8.95	7.95	6.95	6.25
212784	Sunon	KDE1203PFB1-8V	12	30 x 30 x 10	5.1	Ball	75	0.9	UL/CUL/TUV/CE/VDE	27	4"	7.95	6.95	6.25	5.79
212783	Sunon	KDE1203PFB1-8	12	30 x 30 x 10	5.1	Ball	75	0.9	UL/CUL/TUV/CE/VDE	27	5.9"	9.95	8.95	7.95	6.95
1928134	Adda	AD0312HB-D50	12	30 x 30 x 15	4.2	Ball	110	1.3	UL/CUL/TUV/CE	22.5	3" w/conn	6.95	6.25	5.59	4.95
212741	Sunon	KDE1235PFB2-8	12	36 x 36 x 10	4.5	Ball	60	0.8	UL/CUL/TUV/CE/VDE	21	5.9"	9.95	8.95	7.95	6.95
212760	Sunon	GM1235PFV1-8	12	36 x 36 x 10	7.0	Vapo	80	1.0	UL/CUL/TUV/CE	28	6"	14.95	13.49	11.95	10.95
1951490	Adda	AD0412HB-K90	12	40 x 40 x 6.8	6.0	Ball/Sleeve	80	1.0	UL/CUL/TUV/CE	30	5.5"	8.95	7.95	7.19	6.49
2099500	Adda	AD0412HB-K96	12	40 x 40 x 6.8	6.0	Ball	80	0.72	UL/CUL/TUV/CE	30	5.5" ¹	8.95	7.95	6.95	6.25
2100013	Delta	AFB0405LD	12	40 x 40 x 10	3.9	Ball	60	0.3	UL/CSA/VDE/CE	25	13" ²	5.95	5.35	4.79	4.29

¹ 3 leads; speed sensor ² 3 leads; locked rotor protection (These functions are optional, if needed) [†] Blower Fans continued on next page

* For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above

4 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS FACTORY OVERRUN DOLLAR SALE

DC Brushless Tubeaxial Fans & Blowers

4 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS FACTORY OVERRRUN DOLLAR SALE

Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers (Continued)



* 12V Web Code: LBZ



1585291

1950446

mm to Inches Conversion Chart

125006

114682

mm	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	76	80	92	95	97	120	127	150	172
Inches	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.99	3.15	3.63	3.74	3.82	4.69	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
1950526	Sunon	KD1204PFS3H	12	40 x 40 x 10	4.2	Sleeve	60	0.7	UL/TUV	22	12"	\$5.95	\$5.35	\$4.79	\$4.29
2095314	Adda	AD0412LX-G70	12	40 x 40 x 10	4.7	Hypro	70	0.84	UL/CUL/TUV/CE	14	12"	6.95	6.25	5.59	4.95
210797	Sunon	KD1204PFV3	12	40 x 40 x 10	4.9	Vapo	60	0.6	UL/CUL/TUV/CE	24	12"	6.95	6.25	5.59	4.95
279611	Toyo	T401012VH	12	40 x 40 x 10	5.8	Ball	90	1.1	UL/CUL/TUV/CE	33.5	12"	4.95	4.49	3.95	3.59
1585469	Y.S. Tech	FD1240107B-2N	12	40 x 40 x 10	6.6	Ball	90	1.08	UL/CUL/TUV	29	6"	4.95	4.49	3.95	3.59
1928054	Adda	AD0412HB-G70	12	40 x 40 x 10	6.7	Ball	100	1.2	UL/CUL/TUV/CE	25	2.5" w/conn	5.95	5.35	4.79	4.29
2100380	Adda	AD0412HX-G71-LF	12	40 x 40 x 10	6.7	Hypro	100	1.2	UL/CUL/TUV/CE	25	10" 2	7.95	6.95	6.25	5.59
290010	Adda	AD0412HB-G70	12	40 x 40 x 10	6.7	Ball	100	1.2	UL/CUL/TUV/CE	25	10" w/conn	9.95	8.95	7.95	6.95
212717	Sunon	KDE1204PFV2.11.MS.A.GN	12	40 x 40 x 10	7.0	Vapo	80	1.0	UL/CUL/TUV/CE/DE	27	12"	6.95	6.25	5.59	4.95
1950139	Sunon	KDE1204PFS2-11	12	40 x 40 x 10	7.0	Sleeve	92	1.1	UL/CUL/TUV/CE	27	12"	6.95	6.25	5.59	4.95
2081924	Sunon	KDE1204PFV2	12	40 x 40 x 10	7.5	Ball	90	1.1	UL/CUL/TUV/CE	30	12"	8.95	7.95	6.95	5.95
189691	Sunon	KD1204PFS1-11.GN	12	40 x 40 x 10	8.0	Sleeve	60	0.7	UL/CUL/TUV/CE	30	12"	7.95	7.19	6.49	5.79
212725	Sunon	KDE1204PFV1	12	40 x 40 x 10	8.3	Vapo	110	1.4	UL/CUL/TUV/CE/DE	34.4	12"	6.95	6.25	5.59	4.95
1708473	Sunon	KDE1204PFVX11.MS.A	12	40 x 40 x 10	9.5	Vapo	150	1.8	UL/CUL/TUV	39	12"	4.95	4.49	3.95	3.59
136178	Adda	AD0412MS-G70	12	40 x 40 x 20	5.0	Sleeve	110	1.32	UL/CSA	23	9"	5.95	5.39	4.79	4.29
1809856	Sunon	GM1204PKV3-A	12	40 x 40 x 20	6.3	Vapo	50	0.6	UL/CSA/TUV	18	12"	6.95	6.25	5.59	4.95
195899	Sunon	KDE1204PKS2	12	40 x 40 x 20	6.5	Sleeve	70	0.9	UL/CSA/TUV	25.5	12"	4.95	4.49	3.95	3.59
279620	Toyo	T402012H	12	40 x 40 x 20	6.7	Ball	70	0.84	UL/CUL/TUV/CE	26.2	12"	6.95	6.25	5.59	4.95
2120065	Sunon	KD1204PKB2(2)GN	12	40 x 40 x 20	7.7	Dual ball	62	0.7	UL/CSA/TUV	22	12"	6.95	6.25	5.59	4.95
687754	Sunon	KDE1204PKSX-8	12	40 x 40 x 20	9.5	Sleeve	90	1.1	UL/CSA	28	11"	6.95	6.25	5.59	4.95
2099518	Adda	AD0412UB-C51	12	40 x 40 x 20	9.9	Ball	180	2.16	UL/CUL/TUV/CE	36.1	11"	7.95	6.95	6.25	5.59
2082100	Sunon	KDE1204PKBX-8	12	40 x 40 x 20	10	Ball	90	1.1	UL/TUV/CE	29.4	4"	7.95	6.95	6.25	5.59
2099841	Delta	EFB0412VHD-R00	12	40 x 40 x 20	10.1	Dual ball	120	1.4	UL/CSA/VDE/CE	32.5	12" 2	9.95	8.95	7.95	6.95
1928118	Adda	AD4012HB-C50	12	40 x 40 x 20	10.5	Ball	100	1.2	UL/CUL/TUV/CE	31.9	12"	9.95	8.95	7.95	6.95
1585291	Sunon	GM1204PKVX-A	12	40 x 40 x 20	10.8	Vapo	130	1.6	UL/CUL/CSA	27.5	5"	6.95	6.25	5.59	4.95
2082089	Sanyo Denki	109P0412H302	12	40 x 40 x 28	11.3	Ball	195	2.3	UL/CSA/TUV	37	3.75"	6.95	6.25	5.59	4.95
2095162	Sunon	PMD1204PQBX-A(2)F	12	40 x 40 x 28	23.5	Ball	570	6.8	UL/CE	51.5	3" w/conn 1	12.95	11.49	9.95	8.95
1951246	Sunon	PMD1204PQBX-A(2)	12	40 x 40 x 28	23.5	Ball	570	6.8	UL/CE	51.5	12"	14.95	13.49	11.95	10.95
1951254	Sunon	PMD1204PQBX-A(2)F	12	40 x 40 x 28	23.5	Ball	570	6.8	UL/CE	51.5	12" 1	14.95	13.49	11.95	10.95
1950753	Comair Rotron	CR4512MB-G70	12	45 x 45 x 10	6.9	Ball	70	0.8	UL/CUL/CE/TUV	21.6	12"	6.95	6.25	5.59	4.95
2095322	Adda	AD4512HX-G70	12	45 x 45 x 10	9.1	Hypro	90	1.08	UL/CUL/TUV/CE	27.4	11"	7.95	6.95	6.25	5.59
2100371	Adda	AD0512LX-G70LF	12	51 x 51 x 10	9.0	Hypro	60	0.72	UL/CSA/TUV/CE	20	11"	5.95	5.35	4.79	4.29
1918809	Jamicon	KF0510B1M	12	51 x 51 x 10	9.27	Ball	80	0.8	UL/CUL/TUV/CE	26.6	10.5"	5.95	5.35	4.79	4.29
2095331	Adda	AD0512HX-G70	12	51 x 51 x 10	10.5	Hypro	120	1.4	UL/CUL/TUV/CE	24	11"	5.95	5.35	4.79	4.29
2095349	Adda	AD0512MB-G76	12	51 x 51 x 10	10.5	Ball	120	1.4	UL/CUL/TUV/CE	24	11" 1	7.95	6.95	6.25	5.59
1950446	Sunon	KD1205PFB1(2)H	12	51 x 51 x 10	11.4	Ball	130	1.6	UL/TUV	34.7	12"	7.95	6.95	6.25	5.59
2100419	Adda	AD0512HB-G70-LF	12	51 x 51 x 10	11.8	Ball	90	1.08	UL/CSA/TUV/CE	27	11"	8.95	7.95	6.95	6.25
125006	Nidec	A33999-16	12	51 x 51 x 15	4.0	Ball	170	2.04	UL/CE	46	11"	8.95	7.95	6.95	6.25
139601	Adda	AD0512HS-D71	12	51 x 51 x 15	12	Sleeve	100	1.2	UL/CSA/CE	29	5"	5.95	5.35	4.79	3.95
139602	Adda	AD0512HS-D71-R	12	51 x 51 x 15	12	Sleeve	100	1.2	UL/CSA/CE	29	12"	9.95	8.95	7.95	6.95
2099534	Adda	AD5012MX-D71	12	51 x 51 x 15	12.6	Hypro	100	1.2	UL/CUL/TUV/CE	29	5.5"	7.95	6.95	6.25	5.59
1809813	Adda	GM1205PHV1-AR	12	51 x 51 x 15	17	Vapo	130	1.5	UL/CUL/TUV/CE	33	12" 2	7.95	6.95	6.25	5.59
2095357	Adda	AD0612HB-G70	12	60 x 60 x 10	14.5	Ball	150	1.8	UL/CUL/TUV/CE	32	11"	9.95	8.95	7.95	6.95
1946025	Evercool	EC6010M12CA	12	60 x 60 x 10	15.5	Ball	160	1.9	UL/CE/TUV	30	9" 1	8.95	7.95	6.95	6.25
2115522	Everflow	R126010DU	12	60 x 60 x 10	19.41	Ball	250	3	UL/CE/TUV	37	9" w/ conn 1	8.95	7.95	6.95	6.25
1928046	Adda	AD0612LX-D70GL	12	60 x 60 x 15	12	Hypro	90	1.08	UL/CUL/TUV/CE	27.2	8"	5.95	5.59	4.95	4.49
2078178	Delta	AFB0612MB	12	60 x 60 x 15	13.4	Ball	80	0.96	UL/CUL/TUV/CE	29	12"	7.95	6.95	6.25	5.59
195945	Adda	AD612MS-D71GL	12	60 x 60 x 15	14.2	Sleeve	110	1.32	UL/CSA/TUV/CE	28.8	6"	8.95	7.95	6.95	6.25
249069	Jamicon	JF0615B1H-000-243	12	60 x 60 x 15	15.7	Ball	170	2.04	UL/CUL/TUV/CE	34	12"	9.95	8.95	7.95	6.95
2121308	Adda	AD0612HB-D70GL	12	60 x 60 x 15	16.6	Ball	130	1.56	UL/CSA/TUV/CE	32.4	11" w/ conn	9.95	8.95	7.95	6.95
687771	Sunon	KDE1206PHS1	12	60 x 60 x 15	21	Sleeve	150	1.8	UL/CSA/TUV/CE	36	11"	6.95	6.25	5.59	4.95
1585400	Sunon	KDE1206PHB1	12	60 x 60 x 15	21	Ball	150	1.8	UL/CSA/CE	37.5	11"	10.95	9.95	8.95	7.95
144161	Adda	AD0612LB-C70GL	12	60 x 60 x 20	12.6	Ball	80	1.0	UL/CSA/TUV	22.7	6"	9.95	8.95	7.95	6.95
1928126	Adda	AD0612HB-C70GL	12	60 x 60 x 20	16.3	Ball	160	1.92	UL/CSA/TUV/CE	31	12"	9.95	8.95	7.95	6.95
189595	Sunon	KD1206PKS2	12	60 x 60 x 20	16.5	Sleeve	150	1.8	UL/CSA/TUV/CE	31	12"	7.95	6.95	6.25	5.59
119635	Delta/Fonsan	DFD0612H	12	60 x 60 x 20	17.7	Ball	150	1.3	UL/CE/CSA/VDE	30	12"	6.95	6.25	5.59	4.95
2120073	Sunon	KD1206PKB2(2)F.GN	12	60 x 60 x 20	19	Dual ball	88	1.1	UL/CUL/TUV	29	12" 1	7.95	6.95	6.25	5.59
114682	Delta	AFB0612VHD	12	60 x 60 x 20	30	Ball	270	2.4	UL/CE/CSA/VDE	39.5	12"	8.95	7.95	6.95	6.25
2120081	Sunon	KDE1206PTV3.13.MS.AF.GN	12	60 x 60 x 25	16	Vapo	110	0.7	UL/CSA/TUV	21	12" 1	7.95	6.95	6.25	5.59
1810101	Japan Servo	TUDC12Z4F-022	12	60 x 60 x 25	19	Ball	140	1.8	UL/CSA/TUV	32	5" w/ conn	5.95	5.39	4.79	4.29
2095197	Delta	DFB0612H	12	60 x 60 x 25	19.4	Ball	120	1.4	UL/CE/CSA/VDE	30	12"	7.95	6.95	6.25	5.59

1 3 leads; speed sensor 2 3 leads; locked rotor protection (These functions are optional, if needed) † Blower

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 199.



DC Brushless Tubeaxial Fans & Blowers

Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers (Continued)



* 12V Web Code: LBZ

		2099446		1810030						1928100		1809995			
Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
102947	Jamicon	JF0625S1H	12	60 x 60 x 25	20.5	Sleeve	230	2.7	UL/CUL/TUV	33.6	12"	\$6.95	\$6.25	\$5.59	\$4.95
150422	Jamicon	JF0625B1H	12	60 x 60 x 25	21.4	Ball	230	2.7	UL/CSA/TUV	30.5	10"	8.95	7.95	6.95	6.25
195911	Sunon	KD1206PTS1AGN	12	60 x 60 x 25	21.7	Sleeve	190	2.3	UL/CSA/TUV	34	12"	9.95	8.95	7.95	6.95
2099526	Adda	AD0612XB-A74GL	12	60 x 60 x 25	31.4	Ball	380	4.56	UL/CSA/TUV/CE	42.9	12" 1	9.95	8.95	7.95	6.95
123941	Nidec	D07R-12TL018	12	70 x 70 x 15	19.8	Ball	80	0.96	UL/CSA	27	23" 2	10.95	9.95	8.95	7.95
2125561	AVC	DE07015R12U	12	70 x 70 x 15	43	Hydro	700	8.4	UL/CE/TUV	46	8" w/ conn.	11.95	10.95	9.95	8.95
2099446	Adda	AD7512LB (2A)†	12	76 x 76 x 30	6.9	Ball	110	1.32	UL/CUL/TUV/CE	29	15" w/conn.2	9.95	8.95	7.95	6.95
132951	Shicoh	A0815-12HV	12	80 x 80 x 15	18.4	Ball/Sleeve	200	2.4	—	32	12" 1	6.95	6.25	5.59	4.95
2099462	Adda	AD0812LB-D70	12	80 x 80 x 15	20	Ball	120	1.44	UL/CSA/TUV/CE	19.6	6" w/conn.	6.95	6.25	5.59	4.95
401269	Delta	AFB0812LB	12	80 x 80 x 15	24.7	Ball	140	1.68	UL/CSA/TUV	27.5	10"	8.95	7.95	6.95	6.25
1950163	Sunon	KD1208PHB3H	12	80 x 80 x 15	25.5	Ball	120	1.4	CE	28	12"	8.95	7.95	6.95	6.25
109082	Adda	AD0812HS-D71	12	80 x 80 x 15	29	Sleeve	190	2.3	UL/CSA/TUV/CE	31.4	12"	9.95	8.95	7.95	6.95
1708570	Sunon	KD1208PHB1-AH	12	80 x 80 x 15	35	Ball	240	2.9	UL/CUL/TUV/CE	39.5	12"	10.95	9.95	8.95	7.95
2095365	Adda	AD0812XX-D71	12	80 x 80 x 15	39.4	Hypro	350	4.2	UL/CSA/TUV/CE	42	11"	10.95	9.95	8.95	7.95
141921	Adda	AD0812HB-C70	12	80 x 80 x 20	27.3	Ball	240	2.9	UL/CSA/CE	34	12"	10.95	9.95	8.95	7.95
2081748	Sunon	KDE1208PKV1.13.MS.A	12	80 x 80 x 20	36	Vapo	130	1.6	UL/CUL/TUV/CE	38	12"	10.95	9.95	8.95	7.95
688597	NMB	3110GL-B4W-B19	12	80 x 80 x 25	24.7	Ball	100	1.2	UL/CSA/TUV/CE	22	7" w/ conn.1	5.95	5.35	4.79	4.29
2125544	Cool Master	A8025-25BB-3BN-PI	12	80 x 80 x 25	30.8	Dual Ball	150	1.8	UL/CSA/TUV/CE	30.6	12" w/ conn.2	5.95	5.35	4.79	3.95
1952759	Max Flow	MF8025D1-LSPS	12	80 x 80 x 25	31.1	Sleeve	130	1.56	UL	29	7" w/ conn.	5.95	5.39	4.79	4.29
123530	Adda	AD0812MS-A70GL	12	80 x 80 x 25	32	Sleeve	150	1.8	UL/CSA/TUV	28.3	12"	7.95	6.95	6.25	5.59
2125552	Cool Master	BP802512M	12	80 x 80 x 25	33	Ball	160	1.92	UL/CE/UR	29	12" w/ conn.2	6.95	6.25	5.59	4.95
1955010	NMB	3110KL-04W-B40	12	80 x 80 x 25	35.3	Ball	200	2.40	UL/CSA/TUV/CE	31	13"	6.95	6.25	5.59	4.95
2125843	Vastech	RDH8025B	12	80 x 80 x 25	35.7	Ball	170	2.0	UL/CSA/CE	33	11"	6.95	6.25	5.59	4.95
1950147	Sunon	KD1208PTB2(2)HM	12	80 x 80 x 25	36	Ball	160	2.1	UL/CE/TUV	29	11" 1	7.95	6.95	6.25	5.59
1810030	Sanyo Denki	109R0812H4011	12	80 x 80 x 25	36.4	Ball	130	1.56	UL/CSA/TUV	29	12" 1	6.95	6.25	5.59	4.95
1537387	Sunon	KD1208PTB213.(2).GN	12	80 x 80 x 25	37	Ball	110	1.3	UL/CUL/TUV/CE	32	11.5" w/ conn.	7.95	6.95	6.25	5.59
1928038	Adda	AD0812HS-A70GL	12	80 x 80 x 25	38.6	Sleeve	250	3.0	UL/CSA/TUV/CE	34.4	12"	5.95	5.35	4.79	4.29
1928100	Adda	AD0812HX-A70GL	12	80 x 80 x 25	38.6	Hydro wave	250	3.0	UL/CSA/TUV/CE	34	12"	5.95	5.35	4.79	4.29
2078194	Adda	AD0812HS-A73	12	80 x 80 x 25	38.6	Sleeve	250	3.0	UL/CSA/TUV	34.3	12" 1	6.95	6.25	5.59	4.95
662661	NMB-MAT	FBA08A12H1BS	12	80 x 80 x 25	39.6	Hydro wave	173	2.1	UL/CSA/TUV	32	12" 2	5.95	5.35	4.79	3.95
2125835	Globe	B01138812H-3M	12	80 x 80 x 25	39.8	Ball	230	2.76	UL/CSA/TUV/CE	32.6	10" w/ conn.1	6.95	6.25	5.59	4.95
1585477	Sunon	KD1208PTS1-13	12	80 x 80 x 25	40	Sleeve	160	1.9	UL/CUL/TUV/CE	33	12"	5.95	5.35	4.79	4.49
1950569	Sunon	KD1208PTS1.H.M	12	80 x 80 x 25	40	Sleeve	160	2.6	UL/CE	33	12" 1	5.95	5.35	4.79	4.39
1708490	Sunon	KDE1208PTB1-13.MS(2)A	12	80 x 80 x 25	41	Dual Ball	150	1.8	UL/CUL/TUV/CE	35	12"	7.95	6.95	6.25	5.59
206181	Sunon	KDE1208PTS1-6	12	80 x 80 x 25	42	Sleeve	220	2.6	UL/CSA/TUV/CE	34	9"	7.95	6.95	6.25	5.59
355401	ReliaPro	RDH80025B1	12	80 x 80 x 25	42	Ball	230	2.8	UL/CUL/TUV/CE	28.6	12"	8.95	7.95	6.95	6.25
2081271	Sunon	KDE1208PTB1-6(OCM)	12	80 x 80 x 25	42.5	Ball	220	2.6	UL/CUL/TUV/CE	36.5	12" 1	5.95	5.35	4.76	4.29
102955	Sunon	KD1208PTB1-6(OC)	12	80 x 80 x 25	42.5	Ball	220	2.6	UL/CUL/TUV/CE	36.5	3.5"	6.95	6.25	5.59	4.95
249148	Sunon	KDE1208PTB1-6(OC)	12	80 x 80 x 25	42.5	Ball	220	2.6	UL/CUL/TUV/CE	36.5	12"	7.95	6.95	6.25	5.59
2120225	Y.S. Tech	FD128025HS	12	80 x 80 x 25	43.7	Sleeve	230	2.76	UL/CSA/TUV	33.5	13"	6.95	6.25	5.59	4.95
2100401	Adda	AD0812UB-A72GL	12	80 x 80 x 25	43.8	Ball	300	3.6	UL/CUL/TUV/CE	40	11" 2	8.95	7.95	6.95	6.25
1918729	Jamicon	JF0825S1SR	12	80 x 80 x 25	45.5	Sleeve	260	3.12	UL/CUL/TUV/CE	35.8	12" w/ conn.	7.95	6.95	6.25	5.59
421526	Panasonic	FBA08A12U-1AZ	12	80 x 80 x 25	47	Sleeve	360	4.32	UL/CSA	38.2	11"	7.95	6.95	6.25	5.59
1809995	Sunon	KDE1208PTB-6A(318)	12	80 x 80 x 25	50.6	Ball	360	4.3	UL/CUL/TUV/CE	40.5	12"	13.95	12.49	10.95	9.95
2081078	Jamicon	JF0825B1UR	12	80 x 80 x 25	52	Dual Ball	370	4.4	UL/CUL/TUV/CE	40	12"	11.95	10.95	9.95	8.95
2081692	Y.S. Tech	NFD128125BB-2F	12	80 x 80 x 25	59.2	Dual Ball	450	5.4	UL/CUL/TUV	44	20" w/ conn.1	12.95	11.49	10.49	9.49
695682	Comair Rotron	O30615/ST12B3	12	80 x 80 x 32	34	Ball	280	3.4	UL/CUL/TUV/CE	40.9	12"	19.95	17.95	16.25	14.49
107406	EBM Papst	8312GHL	12	80 x 80 x 32	39.4	Sleeve	330	4.0	UL/CE/CSA/VDE	43	12"	14.95	13.49	11.95	10.95
1951166	Nidec	TA350DC-M33416-16	12	92 x 92 x 25	28	Ball	110	1.32	UL/CSA	19.5	11"	7.95	6.95	6.25	5.59
1928089	Adda	AD0912LS-A70GL	12	92 x 92 x 25	32.4	Sleeve	130	1.6	UL/CUL/TUV/CE	23.5	12"	5.95	5.25	4.59	3.95
1952783	Nidec	TA350DC-M34138-34	12	92 x 92 x 25	35	Ball	160	1.92	UL/CSA	26.4	10" w/ conn.3	6.95	6.25	5.59	4.95
1952257	AVC	C9025S12L	12	92 x 92 x 25	37.2	Sleeve	150	1.8	UL/CUL/TUV/CE	26.2	5.5" 1	7.95	6.95	6.25	5.59
1928097	Adda	AD0912LX-A70GL	12	92 x 92 x 25	37.9	Hypro	120	1.44	UL/CUL/TUV/CE	26.5	12"	9.95	8.95	7.95	6.95
1928003	Adda	AD0912MB-A71GL	12	92 x 92 x 25	44.2	Ball	170	2.0	UL/CUL/TUV/CE	32.7	12"	9.95	8.95	7.95	6.95
1952880	Nidec	TA350DC-M33422-57G4	12	92 x 92 x 25	48	Ball	290	3.48	UL/CSA	35	10" w/ conn.4	6.95	6.25	5.59	4.95
154641	Nidec	TA350DC-M33422-16	12	92 x 92 x 25	48	Ball	290	3.5	UL/CSA	43	12"	9.95	8.95	7.95	6.95
1952935	Sunon	KD1209PTB2-6	12	92 x 92 x 25	48	Dual Ball	500	2.1	UL/CSA/TUV/CE	32	25" w/ conn.4	10.95	9.95	8.95	7.95
2115565	Sunon	KD1209PTS1.13.GN	12	92 x 92 x 25	49	Sleeve	160	1.9	UL/CUL/TUV/CE	34	11"	10.95	9.95	8.95	7.95
190984	Sunon	KD1209PTB1-6A	12	92 x 92 x 25	51	Ball	220	2.6	UL/CSA/TUV	34	12"	10.95	9.95	8.95	7.95
207061	AVC	C9025S12H	12	92 x 92 x 25	52	Sleeve	160	3.8	UL/CUL/TUV/CE	34	6" w/ conn.1	7.95	6.95	5.95	4.95
1952767	NMB	3610KL-04W-B56PS9	12	92 x 92 x 25	54.7	Ball	315	3.8	UL/CSA/TUV/CE	41	7" w/ conn.5	6.95	5.95	4.95	3.95

1 3 leads; speed sensor 2 3 leads; locked rotor protection 3 4 leads; wired for Dell proprietary PWM circuit control w/ tach (blue), lock rotor (yellow) & fan guard 4 Temperature sensor

5 5 leads; locked rotor with 2 separate ground if needed (These functions are optional, if needed) † Blower

Fans continued on next page

* For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above

4 LEVELS OF SAVINGS

Order by Phone 24/7 at 1-800-831-4242 or Online at www.Jameco.com

DC Brushless Tubeaxial Fans & Blowers

4 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS FACTORY OVERRUN DOLLAR SALE

Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers (Continued)

* 12V Web Code: LBZ



* 24V Web Code: QEF



644893



2082097



1537467



1951051

mm to Inches Conversion Chart

mm	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	76	80	92	95	97	120	127	150	172
Inches	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.99	3.15	3.63	3.74	3.82	4.69	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
1952951	NMB	3610KL-04W-B56PS6	12	92 x 92 x 25	55	Ball	315	3.8	UL/CSA/TUV/CE	41	9" w/ conn. ²	\$7.95	\$6.95	\$5.95	\$4.95
102963	Nidec	TA350DC-M33503-55	12	92 x 92 x 25	56	Ball	400	4.8	UL/CSA	45	8"	7.95	6.95	5.95	4.95
1951481	Delta/Dell	AFC0912DE-U4218	12	92 x 92 x 38	160	Dual Ball	2500	30	UL/CSA/TUV/CE	63	10" w/ conn. ³	12.95	11.49	9.95	8.95
644893	Evercool	EC9733M12S-B†	12	97 x 92 x 33	19.4	Sleeve	200	2.4	UL/CE/TUV	30	8" w/ conn.	10.95	9.95	8.95	7.95
2081297	Delta	BFB1012H†	12	97 x 94 x 33	25.4	Dual Ball	800	9.6	UL/CSA/VDE/CE	52	6"	12.95	11.49	9.95	8.95
2081641	Delta	BFB1012H†	12	97 x 94 x 33	25.4	Dual Ball	800	9.6	UL/CSA/VDE/CE	52	11"	12.95	11.49	9.95	8.95
207062	Sony	SFF22C†	12	100 x 104 x 35	21	Ball	900	10.8	UL/CSA	51	15" w/ conn. ¹	11.95	10.95	9.95	8.95
174140	Common Wealth	FP108MS3	12	120 x 120 x 25	54	Sleeve	140	1.7	UL/CSA/TUV/CE	25	12"	12.95	11.49	10.49	9.49
689231	Sunon	KDE1212PTS3-6A	12	120 x 120 x 25	67	Sleeve	200	2.4	UL/CUL/TUV/CE	35	12"	10.95	9.95	8.95	7.95
227901	Common Wealth	FP-108M-S1-B	12	120 x 120 x 25	80	Ball	330	4.0	UL/CSA/VDE/CE	42	12"	14.95	13.49	11.95	10.95
363848	Mechatronics	E1225H12B	12	120 x 120 x 25	82	Ball	385	4.62	UL/CUL/TUV	40	3.5"	9.95	8.95	7.95	6.95
1928020	Adda	AD1212HB-A71GL	12	120 x 120 x 25	85.2	Ball	370	4.5	UL/CUL/TUV/CE	39.1	12"	12.95	11.49	9.95	8.95
1952231	Turbofan	TA1225E12BS	12	120 x 120 x 25	93	Ball	580	7.0	UL/CSA/TUV	44	13"	10.95	9.95	8.95	7.95
1928011	Adda	AD1212US-A71GL	12	120 x 120 x 25	98.6	Sleeve	500	6.0	UL/CUL/TUV/CE	39.1	2" w/ conn.	5.95	5.39	4.79	3.95
2081705	T&T	1225H12B-PP1	12	120 x 120 x 25	119	Ball	800	9.6	UL/CUL/TUV/CE	47.5	21" w/ conn. ¹	11.95	10.95	9.95	8.95
2082097	Delta	BFB1212VH†	12	120 x 120 x 32	40	Ball	1250	15	UL/CSA/VDE/CE	57	13"	12.95	11.49	9.95	8.95
2082151	Comair Rotron	MC12B3QDN	12	120 x 120 x 32	102	Ball	660	7.9	UL/CSA/CE	47.8	12" ²	14.95	13.49	11.95	10.95
868109	Comair Rotron	MC12B7	12	120 x 120 x 32	102	Ball	660	7.9	UL/CUL/TUV/CE	47.9	12"	14.95	13.49	11.95	10.95
1580289	EBM Pabst	4212/2	12	120 x 120 x 38	97.1	Ball	360	4.3	UL/CSA/VDE/CE	45	12" ¹	39.95	37.95	35.95	33.95
1585389	Japan Servo	CNDC12B4C-016	12	120 x 120 x 38	99	Ball	380	4.6	UL/CSA/TUV	40	12"	9.95	8.95	7.95	6.95
94626	Sunon	KD1212PMB1-6A	12	120 x 120 x 38	108	Ball	570	6.8	UL/CUL/TUV/CE	42	12"	12.95	11.49	10.95	9.95
1954703	Mechatronics	F1238H12B2-FS	12	120 x 120 x 38	112	Ball	440	5.3	UL/TUV	41	10" w/ conn. ²	11.95	10.95	9.95	8.95
1952791	NMB	4715KL-04W-B46	12	120 x 120 x 38	118	Ball	900	8.4	UL/CSA/TUV/CE	47	6" w/ conn. ²	7.95	6.95	6.25	5.59
1955028	NMB	4715KL-04W-B49	12	120 x 120 x 38	118	Ball	700	8.4	UL/CSA/TUV/CE	46	12" w/ conn. ¹	9.95	8.95	7.95	6.95
2125860	Comair Rotron	MS12K3	12	120 x 120 x 38	127	Ball	920	11	UL/TUV/CE	53.4	12"	14.95	13.49	11.95	10.95
2120313	Comair Rotron	GDA1238-12BB	12	120 x 120 x 38	128	Ball	600	7.2	UL/TUV/CE	43.5	8" ¹	10.95	9.95	8.95	7.95
2099972	Delta	AJB1212SHE-4F1A	12	120 x 120 x 38	152	Ball	750	9.0	UL/CSA/VDE/CE	55.5	48" w/ conn. ⁶	9.95	8.95	7.95	6.95
1537467	Comair Rotron	QJ12B7X	12	172 x 150 x 51	235	Ball	2260	25.2	UL/CSA/TUV/CE	54.3	12" ²	22.95	19.95	17.95	15.95
1928281	Adda	AD0424HB-G70	24	40 x 40 x 10	6.7	Ball	90	2.16	UL/CUL/TUV/CE	25	7" w/ conn.	11.95	10.95	9.95	8.95
1951473	Delta	AFB0424MD	24	40 x 40 x 20	7.0	Ball	60	1.44	UL/CSA/TUV/CE	30	2" w/ conn.	7.95	6.95	6.25	5.59
100910	Sunon	KDE2404PKV2	24	40 x 40 x 20	7.7	Vapo	33	0.8	UL/CUL/TUV	21	12"	9.95	8.95	7.95	6.95
2100398	Adda	AD0424MB-C50LF	24	40 x 40 x 20	8.5	Ball	70	1.68	UL/CUL/TUV/CE	28.5	12"	9.95	8.95	7.95	6.95
1951502	Adda	AD0424HB-C56	24	40 x 40 x 20	10.1	Ball	90	2.16	UL/CUL/TUV/CE	31.9	12" ¹	10.95	9.95	8.95	7.95
1708422	Sunon	KDE2406PHS3	24	60 x 60 x 15	15	Sleeve	50	1.2	UL/CUL/TUV/CE	31	12"	7.95	6.95	6.25	5.59
687818	Sunon	KDE2406PHB2	24	60 x 60 x 15	18	Ball	56	1.3	UL/CUL/TUV/CE	31	11"	10.95	9.95	8.95	7.95
212612	Delta/Fonsan	DFD0624H	24	60 x 60 x 20	17.7	Ball	100	2.4	UL/CE/CSA/TUV	30	12"	6.95	6.25	5.59	4.95
140661	NMB	2408NL-05W-B60	24	60 x 60 x 20	18.4	Ball	100	2.4	UL/CSA/TUV/CE	31	2" w/ conn.	5.95	4.95	4.49	3.95
1951191	Sunon	KDE2406PKV2MS.AGN	24	60 x 60 x 20	18.5	Vapo	90	1.1	UL/CE	27.5	11"	7.95	6.95	6.25	5.59
1954922	NMB	2410ML-05W-B10	24	60 x 60 x 25	14	Ball	60	1.44	UL/CSA/TUV/CE	23	13"	7.95	6.95	5.59	4.95
189861	Jamicon	JF0625B2M	24	60 x 60 x 25	18	Ball	130	3.1	UL/CSA/TUV/CE	28.5	10"	8.95	7.95	6.95	6.25
1952177	Japan Servo	TUDC2424P-029	24	60 x 60 x 25	19	Ball	80	1.8	UL/CSA/TUV	32	12" ²	7.95	6.95	6.25	5.59
212628	Adda	AD0624HS-A70GL	24	60 x 60 x 25	23.2	Sleeve	150	3.6	UL/CSA/TUV/CE	32.3	17" w/ conn.	6.95	6.25	5.59	4.95
1928337	Adda	AD624HX-A70GL	24	60 x 60 x 25	23.2	Hypro	150	3.6	UL/CSA/TUV/CE	32.3	12"	6.95	6.25	5.59	4.95
2081799	Nidec	TA225DC-M33516-16	24	60 x 60 x 25	25	Ball	180	4.3	UL/CSA	37	12"	7.95	6.95	6.25	5.59
1928071	Adda	AD0624HB-A70GL	24	60 x 60 x 25	25	Ball	150	3.6	UL/CSA/TUV/CE	33.9	12"	8.95	7.95	6.95	6.25
1809848	Sunon	PMD2406PTB1-A	24	60 x 60 x 25	35.8	Ball	220	5.3	UL/CUL/TUV/CE	48.8	12"	9.95	8.95	7.95	6.95
1928345	Adda	AD0824HX-D71L	24	80 x 80 x 15	29	Hypro	130	3.12	UL/CUL/TUV/CE	33.5	12"	9.95	8.95	7.95	6.95
1809864	Sunon	PMD2408PMB1-A	24	80 x 80 x 25	24	Ball	400	9.6	UL/CUL/TUV	55.2	12"	7.95	6.95	6.25	5.59
290029	Jamicon	JF0825B2M	24	80 x 80 x 25	31.7	Ball	130	3.1	UL/CUL/TUV/CE	29.3	10"	9.95	8.95	7.95	6.95
136161	Jamicon	JF0825B2H	24	80 x 80 x 25	39.2	Ball	150	3.6	UL/CSA/TUV	31	12"	9.95	8.95	7.95	6.95
1809952	Sunon	KDE2408PTB1-6A	24	80 x 80 x 25	42.5	Ball	110	2.6	UL/CUL/TUV/CE	36.5	12"	9.95	8.95	7.95	6.95
1928388	Adda	AD0824UB-A72GL	24	80 x 80 x 25	50	Ball	260	6.24	UL/CUL/CE	41	12" ²	8.95	7.95	6.95	6.25
1580422	EBM Pabst	8314/12	24	80 x 80 x 32	31.8	Ball	245	2.5	UL/CUL/CSA/VDE	36	11" w/ conn. ¹	12.95	11.49	9.95	8.95
206965	Sunon	PMD2408PMB2-A	24	80 x 80 x 38	74.5	Ball	300	7.2	UL/CUL/CSA/VDE	52	12"	19.95	17.95	15.95	14.49
1951051	Mechatronics	E9225L24B1-FS	24	92 x 92 x 25	35	Ball	85	2.04	UL/CUL	27	12" ¹	7.95	6.95	6.25	5.59
1708502	Sunon	KDE2409PTS3-6	24	92 x 92 x 25	39	Sleeve	112	2.7	UL/CUL/TUV/CE	27	12"	8.95	7.95	6.95	6.25
1928329	Adda	AD0924HX-A70GL	24	92 x 92 x 25	50	Hypro	150	3.6	UL/CUL/TUV/CE	33.7	12"	9.95	8.95	7.95	6.95
695042	Sunon	KD2409PTB1-13AGN	24	92 x 92 x 25	51	Ball	140	3.4	UL/CE/TUV	37	12"	10.95	9.95	8.95	7.95

¹ 3 leads; speed sensor ² 3 leads; locked rotor protection ³ 4 leads; wired for Dell proprietary PWM circuit control w/ tach (blue), lock rotor (yellow) & fan guard

⁴ 4 leads; all black tach/speed w/ connector (These functions are optional, if needed) † Blower

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 199.



DC Brushless Tubeaxial Fans, Blowers, Power Cords, Guards & Filters

Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers (Continued)



153411



212661



1952960



1952775

* 24V Web Code: QEF



* 48V Web Code: MAJ

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
1928302	Adda	AD0924US-A71GL	24	92 x 92 x 25	57.8	Sleeve	210	5.04	UL/CUL/TUV/CE	38.6	12"	\$10.95	\$9.95	\$8.95	\$7.95
104890	EBM Pabst	3314/12	24	92 x 92 x 32	47.1	Ball	140	3.4	UL/CE/TUV	37	12" ¹	11.95	10.95	9.95	8.95
1951465	Delta	FFB0924VHE	24	92 x 92 x 38	85	Ball	280	6.7	UL/CSA/VDE/CE	47	12"	12.95	11.49	9.95	8.95
2115557	Sunon	KD2412PTB3-6A.GN	24	120 x 120 x 25	69	Ball	120	2.9	UL/CUL/TUV/CE	35.5	12"	12.95	11.49	9.95	8.95
1809881	Sunon	KD2412PTB1-6A	24	120 x 120 x 25	90	Ball	220	5.3	UL/CUL/TUV/CE	44.5	12"	13.95	12.49	10.95	9.95
1951115	Nidec	TA450DC-A34350-16	24	120 x 120 x 25	92	Ball	180	4.32	UL/CSA	40.4	10"	11.95	10.95	9.95	8.95
2120129	Sunon	PMD2412PTB3-A(2).GN	24	120 x 120 x 25	120	Dual ball	280	6.7	UL/CSA/TUV	48	12"	12.95	11.49	9.95	8.95
153411	Sunon	KD2412PMB2-6A	24	120 x 120 x 38	98	Ball	230	5.5	UL/CSA/TUV	36.5	12"	17.95	15.95	14.49	12.95
694444	Jamicon	JF1238S2MR-R	24	120 x 120 x 38	101.3	Sleeve	220	5.28	UL/CSA/TUV/CE	39.1	9"	13.95	12.49	10.95	9.95
694524	Jamicon	JF1238B2MR-R	24	120 x 120 x 38	101.3	Ball	220	5.28	UL/CSA/TUV/CE	39.1	9"	15.95	14.49	12.95	11.49
107394	EBM Pabst	4294GH	24	120 x 120 x 38	108	Sleeve	220	5.3	UL/CE/CSA/TUV	49	Terminals	14.95	13.49	11.95	10.95
694532	Jamicon	JF1238B2HR-R	24	120 x 120 x 38	118.7	Ball	310	7.44	UL/CSA/TUV/CE	43.8	9.5"	17.95	15.95	14.49	12.95
1809910	Sunon	KD2412PMSX-6A	24	120 x 120 x 38	119	Sleeve	300	7.2	UL/CUL/TUV/CE	45	12"	12.95	11.49	9.95	8.95
297959	Delta	BFB1224HE	24	125 x 126 x 34	27.2	Ball	340	8.1	UL/CE/CSA/TUV	50.5	12"	12.95	11.49	9.95	8.95
212662	EBM Pabst	6424/8-139	24	172 x 150 x 51	241	Ball	750	18	UL/CUL/TUV	57	24" ⁴	19.95	17.95	15.95	14.49
212661	EBM Pabst	6224N/8HT	24	172 Round x 51	241.3	Ball	750	18	UL/CE/CSA/VDE	55	12" ⁴	19.95	17.95	15.95	14.49
212644	Delta	AFB0948L	48	92 x 92 x 25	37	Ball	50	2.44	UL/CSA/TUV/CE	25	12"	14.95	13.49	11.95	10.95
2120137	Sunon	PMD4809PMB3-A(2).GN	48	92 x 92 x 38	91.7	Dual ball	120	5.8	UL/CSA/TUV	50.3	12"	15.95	14.49	12.95	11.49
212653	Delta	BFB1248HH	48	120 x 120 x 32	35.3	Ball	220	10.5	UL/CSA/CE/VDE	54	12"	12.95	11.49	9.95	8.95
1952960	Comair Rotron	MC48B6QDNX	48	120 x 120 x 32	102	Ball	180	8.4	UL/CSA/TUV/CE	48	11" w/ conn. ¹	12.95	11.49	9.95	8.95
1951450	Delta	EFB1248HHF	48	120 x 120 x 32	120	Ball	140	6.72	UL/CSA/TUV/CE	50.5	6" w/ conn.	14.95	13.49	11.95	10.95
1952775	Orion	OD1232-48HB	48	120 x 120 x 32	120	Ball	180	8.6	UL/TUV/CE	51	12" ³	15.95	14.49	12.95	11.49
2120145	Sunon	PMD4812PMB1-A(2).GN	48	120 x 120 x 38	190	Dual ball	400	19.2	UL/CSA/TUV	54	12"	17.95	15.95	14.95	12.95
1951422	Delta	FFB1248HE-R00	48	120 x 120 x 38	190	Ball	500	24	UL/CSA/TUV/CE	59	12" w/ conn. ²	17.95	15.95	14.49	12.95
689063	EBM Pabst	W2G115-AG75-85	48	127 x 127 x 38	155	Ball	310	15	UL/CUL	52	10" ¹	17.95	15.95	14.49	12.95
1954711	Delta	EFB1348HHE-SV06	48	127 x 127 x 38	185	Ball	360	17.28	UL/CSA/VDE/CE	55.5	26" ¹	17.95	15.95	14.95	12.95


¹ 3 leads; speed sensor ² 3 leads; locked rotor protection ³ 4 Leads wired for Dell proprietary PWM circuit control w/ tach (blue), lock rotor (yellow) & fan guard

⁴ 5 leads; locked rotor with 2 separate ground if needed (These functions are optional, if needed) † Blower

DC & AC Plug Fan Power Cords

* Web Code: GAE

For Fans w/ Terminal Connection

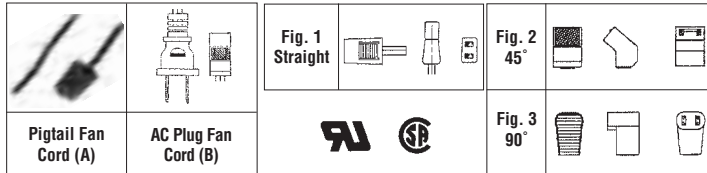

Part No.	Description	Fig.	Length	1	10	100	250
28564	Straight pigtail fan cord	1A	24"	\$1.49	\$1.25	\$0.99	\$0.89
2076658	Straight pigtail fan cord	1A	36"	1.49	1.25	.89	.79
1952548	45° pigtail fan cord	2A	24"	1.25	1.19	1.09	.99
104192	90° pigtail fan cord	3A	24"	1.25	1.19	1.09	.99
1952572	Straight AC plug fan cord	1B	72"	2.95	2.69	2.39	2.19
2117245	45° AC plug fan cord	2B	24"	11.95	10.95	9.95	8.95
1952581	45° AC plug fan cord	2B	72"	2.95	2.69	2.39	2.19


* Green cord, thermostatic controlled

Fan Guards & Aluminum Washable Filters

* Web Code: UAR

Guards and filters fit all fans. Please match by size dimension.
Example: P/N 300557 fan (80mm) matches P/N 31924 metal guard (80mm).

Part No.	mm	Description	Fig.	1	10	50	100	Part No.	mm	Description	Fig.	1	10	50	100
123502	40	Metal (chrome) guard	1	\$.59	\$.55	\$.49	\$.45	1952661	92	Plastic guard only	3	\$.89	\$.85	\$.75	\$.69
120038	60	Metal (chrome) guard	1	.65	.59	.55	.49	1952679	120	Plastic guard only	3	.99	.89	.79	.75
687666	60	Metal (black anodized) guard	2	.85	.79	.75	.69	1952687	150	Plastic guard only	3	1.29	1.19	1.09	.99
31924	80	Metal (chrome) guard	1	.69	.65	.59	.55	1952695	40	Plastic guard w/ mesh	4	1.29	1.19	1.09	.99
1928433	80	Metal (black anodized) guard	2	.79	.69	.65	.59	1952708	60	Plastic guard w/ mesh	4	1.95	1.79	1.59	1.39
123511	92	Metal (chrome) guard	1	.75	.69	.65	.59	138562	80	Plastic guard w/ mesh	4	1.65	1.49	1.39	1.29
25735	120	Metal (chrome) guard	1	.79	.75	.69	.65	229665	92	Plastic guard w/ mesh	4	1.95	1.75	1.49	1.35
695068	120	Metal (black anodized) guard	2	1.09	.99	.89	.79	196817	120	Plastic guard w/ mesh	4	2.19	2.09	1.95	1.79
695076	127	Metal (chrome) guard	1	1.25	1.09	.99	.89	1952716	172	Plastic guard w/ mesh	4	2.79	2.49	2.29	2.19
1811198	172	Metal (chrome) guard	1	1.25	1.09	.99	.89	1952724	60	Alum. washable filter	5	1.95	1.75	1.59	1.45
1952644	40	Plastic guard only	3	.55	.49	.45	.39	138580	80	Alum. washable filter	5	2.09	1.95	1.75	1.59
1952652	60	Plastic guard only	3	.65	.59	.55	.49	1952732	92	Alum. washable filter	5	2.25	1.95	1.75	1.59
1952290	80	Plastic guard only	3	.69	.59	.55	.49	130105	120	Alum. washable filter	5	2.95	2.75	2.49	2.25

 

* For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above



Order by Phone 24/7 at 1-800-831-4242 or Online at www.Jameco.com



212600



206309

115 & 220VAC Tubeaxial Fans



*Web Code: ABJ



275793



209365

mm to Inches Conversion Chart

mm	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	76	80	92	95	97	120	127	150	172
Inches	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.99	3.15	3.63	3.74	3.82	4.69	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VAC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection	Pricing			
												1	10	50	100
213867	Fulltech	UF60D11BWH	115	60 x 60 x 30	10.2	Ball	35	4	UL/CUL/VDE/CE	28	12' leads	\$17.95	\$15.95	\$14.49	\$12.95
2100267	Pelonis	PM8025HA1S	115	80 x 80 x 25	18.8	Sleeve	110	13.2	UL/CUL/CE	26.7	Terminals	12.95	11.49	9.95	8.95
146078	Common Wealth	FP108AX-S1-B (115)	115	80 x 80 x 25	23	Ball	180	14	UL/CE	29	12' leads	15.95	14.49	12.95	11.49
300557	Fulltech	UF80B11SWH	115	80 x 80 x 25	24	Sleeve	140	14	UL/CUL/TUV/CE	35	12' leads	12.95	11.49	9.95	8.95
300258	Fulltech	UF80B11BTH	115	80 x 80 x 25	24	Ball	140	14	UL/CUL/TUV/CE	35	Terminals	13.95	12.49	10.95	9.95
212645	Elina	EP083815-LBL	115	80 x 80 x 38	24	Ball	110	9	UL/CSA/TUV/CE	32	12' leads	13.95	12.49	10.95	9.95
300582	Fulltech	UF80A11SWL	115	80 x 80 x 38	25	Sleeve	110	12	UL/CUL/TUV/CE	32	12' leads	13.95	12.49	10.95	9.95
300303	Fulltech	UF80A11BWL	115	80 x 80 x 38	25	Ball	110	11	UL/CUL/TUV/CE	32	12' leads	15.95	14.49	12.95	11.49
300330	Fulltech	UF80A11BTL	115	80 x 80 x 38	25	Ball	110	12	UL/CUL/TUV/CE	32	Terminals	14.95	13.49	11.95	10.95
300600	Fulltech	UF80A11BWH	115	80 x 80 x 38	29	Ball	120	12	UL/CUL/TUV/CE	36	12' leads	15.95	14.49	12.95	11.49
1950155	Sunon	SF11580A-1083HSL-GN	115	80 x 80 x 38	30	Sleeve	150	13	UL/CE/TUV	33	24' leads	13.95	12.49	10.95	9.95
300389	Fulltech	UF80A11BTH	115	80 x 80 x 38	30	Ball	120	12	UL/CUL/TUV/CE	36	Terminals	15.95	14.49	12.95	11.49
75433	Sunon	SF11592A-1092HSL	115	92 x 92 x 25	36	Sleeve	130	12	UL/CSA/TUV/CE	39	12' leads	12.95	11.49	9.95	8.95
303467	Sunon	SF11592A-1092HBL	115	92 x 92 x 25	37	Ball	110	12	UL/CSA/TUV/CE	40	12' leads	14.95	13.49	11.95	10.95
75460	Sunon	SF11592A-1092HBT-R	115	92 x 92 x 25	37	Ball	110	12	UL/CSA/TUV/CE	40	Terminals	16.95	14.95	13.49	11.95
1819376	NMB	4710PS12TB30A00	115	120 x 120 x 25	70.6	Ball	190	11	UL/CSA/VDE/CE	38	Terminals	12.95	11.49	9.95	8.95
1810048	Sunon	SP101AT-1122HBL.GN	115	120 x 120 x 25	78	Ball	180	18	UL/CUL/TUV/CE	46	12' leads	16.95	14.95	13.49	11.95
124063	Sunon	SP101AT-1122HBT	115	120 x 120 x 25	78	Ball	180	18	CSA/TUV/CE	46	Terminals	16.95	14.95	13.49	11.95
303361	Fulltech	UF12A11BTL1	115	120 x 120 x 38	64	Ball	80	15	UL/CUL/TUV/CE	37	Terminals	14.95	13.49	11.95	10.95
1585371	Sunon	SP103A-1123LBL	115	120 x 120 x 38	78	Ball	130	11	UL/CSA/TUV	39	6' w/ conn.	11.95	10.95	9.95	8.95
1918796	Jamicon	KA1238L1B0A0-T	115	120 x 120 x 38	78	Dual Ball	200	12	UL/CUL/CE	38	Terminals	14.95	13.49	11.95	10.95
300792	Fulltech	UF12A11STL	115	120 x 120 x 38	81	Sleeve	150	15	UL/CUL/TUV/CE	38	Terminals	14.95	13.49	11.95	10.95
303483	Fulltech	UF12A11SWL	115	120 x 120 x 38	82	Sleeve	150	12	UL/CUL/TUV/CE	38	12' leads	12.95	11.49	10.49	9.49
2100427	Adda	AA1281HS-ATLF	115	120 x 120 x 38	83	Sleeve	250	16.3	UL/CSA/TUV/CE	42.2	Terminals	13.95	12.49	10.95	9.95
106586	Common Wealth	FP108-1-S1/T	115	120 x 120 x 38	105	Sleeve	180	12	UL/CSA/CE	47	Terminals	13.95	12.49	10.95	9.95
303415	Common Wealth	FP108-1-S1-B/W	115	120 x 120 x 38	105	Ball	200	17	UL/CSA/TUV/CE	47	12' leads	15.95	14.49	12.95	11.49
16935	Common Wealth	FP108-1-S1-B/T	115	120 x 120 x 38	105	Ball	200	17	UL/CSA/TUV/CE	47	Terminals	15.95	14.49	12.95	11.49
212600	Fulltech	UF12A11BWH	115	120 x 120 x 38	106	Ball	190	15	UL/CUL/TUV/CE	46	12' leads	15.95	14.49	12.95	11.49
1707163	Sunon	SP101A-1123HBL-GN	115	120 x 120 x 38	107	Ball	180	18	UL/CSA/TUV	50	12' leads	15.95	14.49	12.95	11.49
206309	Adda	AA1281UB-AT	115	120 x 120 x 38	107	Ball	230	24	UL/CUL/CE	48	Terminals	15.95	14.49	12.95	11.49
275793	Sunon	SP101A-1123HBT	115	120 x 120 x 38	107	Ball	180	18	UL/CUL/CE	50	Terminals	16.95	14.95	13.49	11.95
303408	Sunon	SP100A-1123XBL	115	120 x 120 x 38	117	Ball	240	20	UL/CSA/TUV/CE	47	12' leads	17.95	15.95	14.49	12.95
102884	Sunon	SP100A-1123XBT	115	120 x 120 x 38	117	Ball	240	20	UL/CUL/TUV/CE	50	Terminals	17.95	15.95	14.49	12.95
108725	Fulltech	UF15AC11BTH	115	172 x 150 x 38	211	Ball	230	28	UL/CUL/TUV/CE	58	Terminals	29.95	27.95	25.95	23.95
2099454	Adda	AA1751MB-AW	115	172 x 150 x 51	186	Ball	350	29.8	UL/CUL/TUV/CE	50.5	12' leads	29.95	26.95	23.95	21.49
189684	Fulltech	UF15PC12BTH	115	172 x 150 x 51	226	Ball	250	30	CSA	58	Terminals	34.95	32.95	29.95	26.95
212582	Fulltech	UF15PC11BWH	115	172 x 150 x 51	226	Ball	250	30	UL/CUL/TUV/CE	58	12' leads	36.95	34.95	32.95	29.95
1950956	Arctic	KEST-481BW	115	172 x 150 x 51	260	Ball	620	46	UL/CE/TUV	61	12' leads	34.95	32.95	29.95	26.95
1810128	Common Wealth	FP-108AX-S1-B (220)	220	80 x 80 x 25	21	Ball	120	13	UL/CSA/TUV/CE	29	13' leads	16.95	14.95	13.49	11.95
2099471	Adda	AA8382MX-AT	220	80 x 80 x 38	24	Hypro	50	6.8	UL/CUL/TUV/CE	25.3	Terminals	14.95	13.49	11.95	10.95
100918	Sunon	SF23080A/2083HSL	220	80 x 80 x 38	30	Sleeve	60	13.5	UL/CSA/TUV/CE	35	12' leads	16.95	14.95	13.49	11.95
355630	Fulltech	UF-80A23-BTH-R	220	80 x 80 x 38	30	Ball	60	12	UL/CSA/VDE/CE	36	Terminals	16.95	14.95	13.49	11.95
209365	Bi-Sonic	4C-230LB	220	120 x 120 x 38	63	Ball	60	9	TUV/CE	34	10' leads	12.95	11.49	9.95	8.95
302244	Comair Rotron	28023	220	120 x 120 x 38	88	Ball	130	28.6	UL/CSA	50.7	Terminals	12.95	11.49	9.95	8.95
1918753	Jamicon	KA1238H2B01	220	120 x 120 x 38	89	Dual Ball	200	23	UL/CUL/TUV/CE	42	Terminals	10.95	9.95	8.95	7.95
1918761	Jamicon	KA1238H2B12	220	120 x 120 x 38	110	Ball	200	24	UL/CUL/TUV/CE	45	Terminals	12.95	11.49	9.95	8.95
1585346	Sunon	A2123-HBL	220	120 x 120 x 38	117	Ball	120	20	UL/CUL/TUV	50	17' leads	14.95	13.49	11.95	10.95
303459	Sunon	DP200A-2123XBL	220	120 x 120 x 38	117	Ball	120	21	UL/CSA/TUV/CE	50	12' leads	15.95	14.49	12.95	11.49
1585338	Sunon	A2123-HBT	220	120 x 120 x 38	117	Ball	120	20	UL/CUL/TUV	50	Terminals	14.95	13.49	11.95	10.95
102892	Sunon	DP200A-2123XBT	220	120 x 120 x 38	117	Ball	120	21	UL/CSA/TUV/CE	50	Terminals	17.95	15.95	14.49	12.95
1809872	Sunon	A2175-HBT	220	172 x 150 x 51	239	Ball	110	25	UL/TUV/CE	51	Terminals	29.95	26.95	23.95	19.95
1950964	Arctic	KEST-482BW	220	172 x 150 x 51	256	Ball	400	58	UL/TUV/CE	58	12' leads	32.95	29.95	26.95	23.95

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 199.