


EMI Power Entry Filters (IEC Connector), Line Filters & AC Receptacles (IEC 320) Continued

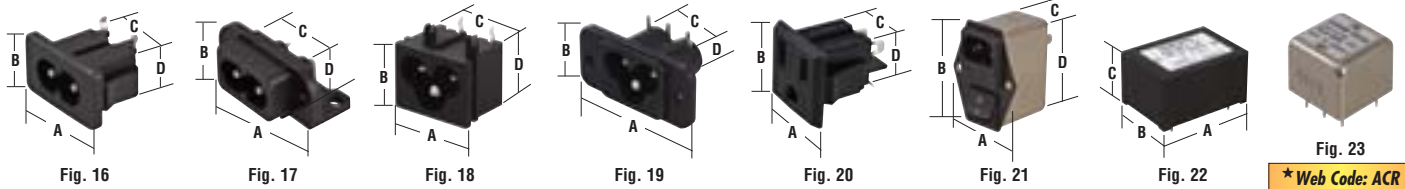

* Web Code: ACR

Part No.	Mfr.	Mfr. Part No.	Description	Fig.	Current (A)	Hipot (VDC)	Terminals	Terminal Size	Agency Approvals	Dimension (in.)				Pricing		
										A	B	C	D	1	10	100
2114052	Adam Tech	IEC-NA-4R	AC pwr inlet, mini, M RA (snap-in, PC mount)	16	15	250	Solder	0.098"	UL/CSA/VDE	1.102	0.63	1.748	0.492	\$.55	\$.45	\$.39
2114061	Adam Tech	IEC-ND-4R	AC pwr inlet, mini, M RA (scrw flngd, panel mnt)	17	15	250	Solder	0.098"	UL/CSA/VDE	1.378	0.571	0.811	0.401	2.49	2.29	1.95
2114079	Adam Tech	IEC-NH-4R	AC pwr inlet, mini, M RA (snap-in, PC mount)	18	15	250	Solder	0.059"	UL/CSA/VDE	0.886	0.689	0.787	0.61	.65	.55	.49
2114087	Adam Tech	IEC-NA-A-4R	AC pwr inlet, mini, M RA (scrw flngd, panel mnt)	19	15	250	Solder	0.071"	UL/CSA/VDE	1.543	0.717	0.787	0.61	.69	.59	.55
2114095	Adam Tech	NEMA-5-2R##	AC pwr outlet, NEMA receptacles (snap-in)	20	15	250	Fork	—	UL/CSA/VDE	1.063	1.063	0.70	0.866	.75	.65	.55
2114124	Adam Tech	PLF-6DZ2KR	Pwr entry filter, strght, fuse & sw. (scrw flngd)	21	15	250	Faston	0.250"	UL/CSA/VDE	1.968	2.559	2.394	1.154	9.95	8.95	7.95
2114108	Adam Tech	PLF-3PC4R	Line filter, plastic case (PC mount)	22	15	250	Solder	0.039"	UL/CSA/VDE	1.93	1.38	1.06	—	6.95	5.95	5.25
2114116	Adam Tech	PLF-3PC3R	Line filter, metal case (PC mount)	23	15	250	Solder	0.039"	UL/CSA/VDE	0.984	0.984	0.787	—	5.95	5.49	4.95

For 14-16 AWG wires

Open-Frame Linear AC-to-DC Power Supplies

- Load regulation: ±0.5%
- Line regulation: ±0.5%
- UL/CE/TUV certified

* Web Code: MSP



2077503

Part No.	Manufacturer	Mfr. Part No.	Output		Input (VAC @ Hz) *	Rip & Noise (mV p-p)	Size (L" x W" x H")	Pricing		
			Voltage@Current (min-max)	Power				1	5	25
2077503	Astec	ACV12N5	+12V @ 5.1A	61W	100-240 @ 47-63Hz	3.0	7.0 x 4.87 x 2.75	\$24.95	\$22.49	\$19.95
2077511	Astec	ACV15N4.5	+15V @ 4.5A	67.5W	100-240 @ 47-63Hz	3.0	7.0 x 4.87 x 2.75	24.95	22.49	19.95
2080454	Power One	HBB15-1.5A	+12V to 15V @ 1.7A/1.5A -12V to 15V @ 1.7A/1.5A	192W	100 or 240VAC @ 47-63Hz	5.0	7.0 x 4.88 x 2.50	59.95	53.95	47.95

* Jumperable between 100VAC to 240VAC

Open-Frame Medical Switching AC-to-DC Power Supplies



MPS-65

- Universal AC input/full range
- Soft-start circuit, limiting AC surge current
- Short-circuit, overload and overvoltage protection
- Load regulation: ±2.0%
- Volt. adjustment: 10%
- 100% full-load burn-in test
- Leakage current: 0.3mA @ 240V
- Isolation volt.: 4000VAC
- Working temp.: -10°C to +60°C
- Mating connector: P/N 104732, pg 77



* Web Code: JBK

Part No.	Manufacturer	Mfr. Part No.	Output		Input (VAC @ Hz)	Ripple & Noise (mV p-p) *	Certification	Pricing		
			Voltage @ Current (min-max)	Power				1	5	25
221058	Mean Well	MPS-45-7.5	+7.5V @ 0-5.4A	40.5W	90-264 @ 47-440	100	UL/CUL/TUV/CE	\$23.95	\$21.95	\$19.95
221146	Mean Well	MPS-65-7.5	+7.5V @ 0-8A	60.0W	90-264 @ 47-440	100	UL/CUL/TUV/CE	24.95	23.49	21.95
221066	Mean Well	MPS-45-12	+12V @ 0-3.7A	44.4W	90-264 @ 47-440	100	UL/CUL/TUV/CE	21.95	19.95	17.95
221154	Mean Well	MPS-65-12	+12V @ 0-5.2A	62.4W	90-264 @ 47-440	100	UL/CUL/TUV/CE	26.49	24.49	22.49
221162	Mean Well	MPS-65-13.5	+13.5V @ 0-4.7A	63.5W	90-264 @ 47-440	100	UL/CUL/TUV/CE	23.95	21.95	19.95
221189	Mean Well	MPS-65-24	+24V @ 0-2.7A	64.8W	90-264 @ 47-440	100	UL/CUL/TUV/CE	26.49	24.49	22.49
2081721	EOS	LFMVL780-4000	+5V @ 10A, +12V @ 2A, -5V @ .8A, -12V @ .8A	80.0W	90-240 @ 47-63	80	UL/CE	44.95	39.95	35.95

* Primary Output

Open-Frame Ultraminiature Switching AC-to-DC Power Supplies



OFM-0203

- 100% full-load burn-in test
- No load consumption
- Ultraminiature size and lightweight
- Short-circuit, overload, overvoltage, overtemperature protection
- Three-year warranty; except P/Ns 300433/300530: Two-year warranty
- Universal AC input/full range
- UL/CUL/TUV/CE



* Web Code: CCQ



NFM-05

Part No.	Manufacturer	Mfr. Part No.	Output		Size (L" x W" x H")	Load Regulation	Line Regulation	Ripple & Noise (mV p-p) *	Pricing		
			Voltage @ Current (min-max)	Power					1	10	50
694971	Mean Well	NFM-05-5	+5V @ 0-1A	5W	2.3 x 1.8 x 0.8	±1.5%	±1.0%	80	\$19.95	\$17.95	\$15.95
300281	Mean Well	OFM-5001	+5V @ 0-1A	5W	2.3 x 1.8 x 0.8	±2.0%	±0.5%	50	16.95	14.95	13.95
300433	Astrodyne	OFM-0101	+5V @ 0-2A	10W	2.6 x 1.8 x 0.8	±1.0%	±1.0%	80	17.95	15.95	13.95
695199	Mean Well	NFM-20-5	+5V @ 0-4.4A	22W	3.0 x 2.0 x 0.8	±1.0%	±1.5%	80	24.95	22.95	20.95
694989	Mean Well	NFM-05-12	+12V @ 0-0.42A	5.04W	2.3 x 1.8 x 0.8	±0.5%	±0.5%	150	19.95	17.95	15.95
695156	Mean Well	NFM-15-12	+12V @ 0-1.25A	15W	2.8 x 1.9 x 0.9	±0.5%	±0.5%	150	24.95	22.49	19.95
300484	Mean Well	OFM-1502	+12V @ 0-1.25A	15W	2.8 x 1.9 x 0.8	±1.0%	±0.3%	150	23.95	21.95	19.95
300417	Mean Well	OFM-5003	+15V @ 0-0.33A	5W	2.3 x 1.8 x 0.8	±1.0%	±0.3%	150	14.95	12.95	11.95
300530	Mean Well	OFM-0203	+15V @ 0-1.4A	20W	3.5 x 2.0 x 0.8	±1.0%	±0.3%	150	21.95	19.95	18.49

* Primary Output

Open-Frame Switching Power Supplies continued on pages 136 & 137

* For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above