

Pliers, Cutters, Drill Bits, Mini-Drill & Stand


4 LEVELS OF SAVINGS			
NAME BRANDS	HOUSE BRANDS	FACTORY OVERRUN	DOLLAR SALE

EXIMCORP

Pliers and Cutters

Diagonal, Needle Nose, Nipper, Square, Bent Nose, Sportsmen & Electrician Pliers

- General purpose for picking-up, cutting and wire forming
- Forged steel
- Heat treated
- Insulated grips
- Blister packaged

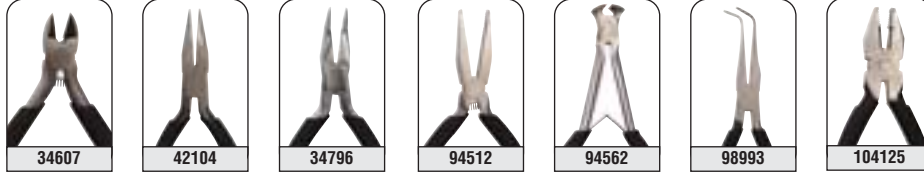

Diagonal Flush Cutters

Part No.	Description	1	5	25
34622	4.5" spring loaded	\$4.95	\$4.49	\$3.95
34607	5" spring loaded	4.95	4.49	3.95
34658*	5.25" heavy duty	5.49	4.95	4.49

Needle Oval Nose Pliers with Serrated Jaws

Part No.	Description	1	5	25
42104*	5.25" standard	\$5.95	\$5.49	\$4.95

Needle Oval Nose Cutters with Serrated Jaws

Part No.	Description	1	5	25
34691	4.75" spring loaded	\$4.95	\$4.49	\$3.95
34712*	5.25" spring loaded	5.49	4.95	4.49

Bent Oval Nose Pliers with Serrated Jaws

Part No.	Description	1	5	25
34796	5" standard bend	\$4.95	\$4.49	\$3.95
34826	6" slim spring loaded	4.95	4.49	3.95
34851*	7" standard bend	4.95	4.49	3.95

Bent Oval Nose Cutters with Serrated Jaws

Part No.	Description	1	5	25
34746	5.25" standard bend	\$3.95	\$3.69	\$3.39
34762*	7" standard bend	4.95	4.49	3.95

Square Nose Cutters with Serrated Jaws

Part No.	Description	1	5	25
94512	5.5" standard w/o cutter	\$4.95	\$4.49	\$3.95
94530	4.75" spring loaded w/ cutter	3.95	3.69	3.39
94546*	5.25" standard straight	4.95	4.49	3.95

Nipper Nose Pliers Spring Loaded

Part No.	Description	1	5	25
94554*	4.25" standard	\$3.95	\$3.69	\$3.39
94562	5.25" slim	5.95	5.49	4.95

Sportsmen's Square Straight & Bent Nose Pliers

Part No.	Description	1	5	25
98976	6.25" standard straight	\$4.95	\$4.49	\$3.95
104257*	8" standard straight	5.95	4.95	4.49
98985	5.25" standard bent	5.95	5.49	4.95
98993*	7.5" standard bent	6.95	6.25	5.59

Electricians Pliers with Serrated Jaws

Part No.	Description	1	5	25
104125*	6.25" standard with cutter	\$5.95	\$5.49	\$4.95
104249	8.25" standard with cutter	5.95	4.95	4.49

* Part of kit 2100161 on right

*** EXIMCORP Pliers & Cutters — Enter Web Code EXP**

Diagonal Wire Cutters

- Jaws are designed for flush cutting
- Cuts component wire up to 1.2mm thick
- 0.5" cutting blade
- Durable rubber handles
- Insulated handles



* Web Code: HAF

Part No.	Size	1	10	50
35482	4.3"L x 2.1"W	\$6.95	\$6.49	\$5.95
161411	5.0"L x 1.8"W	6.95	6.49	5.95

Pliers & Cutters Tool Kit

Ten (10) most popular tools in a kit. See (*) to the left

- 1 each



EXIMCORP

Part No.	Description	1	5	25
2100161	10 pliers and cutters	\$29.95	\$26.95	\$23.95

Variable High-Speed Rotary Tool Kit

- Speed: 6000-32000rpm
- Motor power: 130W
- Collet capacity: 3.2mm
- 28 pcs. sanding/grinding bit set
- Case included, 2.2 lbs.
- Variable speed selector



Part No.	Description	1	5
2118977	Variable high-speed rotary tool kit	\$39.95	\$36.95

High-Speed Steel Step Drill Bit

Drill multiple holes in thin material with the same bit, faster and easier. Each bit does the work of many drill bit sizes. You can drill holes in most materials such as plastic, metal, and wood up to 1/8" thick.



- Shank size: 3/8"
- 2.4" long

Part No.	Description	1	10	50
229657	3/16" - 7/8" 13-step	\$14.95	\$13.49	\$11.95

*** Drill Bits — Enter Web Code NEJ**

JAMECO BenchPro Pocket Screwdriver

Phillips & Flat head

* Web Code: CAQ

- Pen clip for pocket storage



Part No.	Description	1	10	100
127271	6" long pocket screwdriver	\$1.95	\$1.59	\$1.39

Impact Punch-Down Tools

- Reversible clip-in blade
- Adjustable (HI-LO) spring-loaded impact mechanism
- Storage bin on handle for spare blade

* Web Code: PBC

175071: Tool with blade

- For 66-type terminals
- Size: 5.2"L x 1.5"W x 1.0"H



324014: Tool with blade

- For 110-type terminals
- Size: 5.8"L x 1.7"W x 1.2"H



175089: Punch-down blade 110-type terminals

324021: Punch-down blade 66-type terminals

Part No.	Description	1	5
175071	Tool with 66 blade	\$29.95	\$27.95
324014	Tool with 110 blade	29.95	27.95
175089	Punch-down blade 110	9.95	8.95
324021	Punch-down blade 66	7.95	6.95

JAMECO BenchPro Mini-Drill and Stand

This Mini-Drill is excellent for drilling through circuit boards and protoboards. The drill comes with an array of drilling, grinding and sanding attachments. Drill stand is designed to function like a drill press.



2090 RPMs

Part No.	Description	Wt. (lbs.)	1	5	25
26702	GTT-103A drill	0.8	\$34.95	\$31.95	\$27.95
26711	GTT-104 stand	1.8	25.95	23.95	21.95

PC Board Drill Bits

- Shaft diameter: .125"
- Use for drilling holes in glass PC boards



Part No.	Size	Dia.	1	10	100
1919537	1/8	.125"	\$0.75	\$0.59	\$0.45
1919588	31	.120"	.75	.59	.45
1919300	32	.116"	.75	.59	.45
1919609	33	.113"	.75	.59	.45
1919553	35	.110"	.75	.59	.45
1919570	38	.102"	.75	.59	.45
1919502	45	.082"	.75	.59	.45
1919596	46	.081"	.75	.59	.45
1919561	48	.076"	.75	.59	.45
16580	59	.040"	1.75	1.49	.99
16619	75	.021"	1.75	1.49	.99

JAMECO BenchPro Mini-Drill Bit Kit

This kit is excellent for drilling through circuit and protoboards precisely.

- Mini drill (26702)
- Mini drill stand (26711)
- Drill bit sizes 48 & 59 (1919561/16580)



Part No.	Description	Price
2113252	Mini-Drill Bit kit	\$54.95

JAMECO BenchPro 34-Piece Security Bit Set

These bits match the security fasteners commonly used in today's electronic products.

- Includes:** Torx bits: #6, #8 and #10; Tri-wing bits: #1, #2, #3 and #4; Security hex bits: 5/64", 3/32", 7/64", 1/8", 9/64", 5/32" 3/16" and 1/4"; Security Torx bits: T8, T10, T15, T20, T25, T27, T30, T35 and T40; Spanner bits: 4, 6, 8 and 10mm; Phillips bits: #1, #2, #3 and #4; and 60mm magnetic bit extension that fits 1/4" hex driver



Part No.	Description	1	10
223829	32-piece security bit set	\$10.95	\$9.95

Our website offers thousands of data sheets and photos to assist you in finding the products you need.

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 199.