


Jameco carries the full line of Mean Well Power products. For additional products visit [www.Jameco.com/meanwellproducts](http://www.Jameco.com/meanwellproducts)



## Open-Frame Switching AC-to-DC Power Supplies (Cont.)

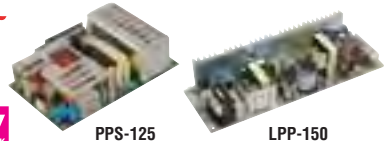

- Universal AC input/full range
- Two-year warranty
- Short-circuit, overload and overvoltage protection

\* Web Code: OSP

- † PFC Model: • Built-in active Power Factor Correction function, power factor >0.93
- Three-year warranty

NEW MARKED IN PINK

Complete specifications available online

Part No.	Manufacturer	Mfr. Part No.	Output		Input (VAC @ Hz)	Size (L"xW"xH")	Mounting Holes (L"xW"xDia.")	Ripple & Noise (mV p-p)*	Load Reg. (±%)*	Line Reg. (±%)*	EFF (%)§	Certification	Pricing	
			Voltage @ Current (min-max)	Power									1	10
<b>Single Output (Continued)</b>														
1919035	Mean Well	PS-35-24	+24V @ 0-1.5A	36W	85-264 @ 47-63	4.2x2.4x1.1	3.7x2.1x0.1	240	2.0	0.2	85	UL/CUL/TUV/CE	\$12.49	\$11.49
213720	Mean Well	PS-45-24	+24V @ 0-1.9A	45.6W	90-264 @ 47-440	4.0x2.0x0.9	3.8x1.8x0.1	200	0.5	0.5	78	UL/CUL/TUV/CE/CB	12.49	11.49
2164615	Mean Well	EPS-45-24-C	+24V @ 0-2.1A	45.6W	90-264 @ 47-63	4x2x1.1	3.75x1.75x0.13	150	1	0.5	89	UL/TUV/EN	16.49	14.95
148647	Mean Well	PS-65-24	+24V @ 0-2.7A	64.8W	90-264 @ 47-440	5.0x3.0x1.7	4.5x2.5x0.2	100	2.0	1.0	80	UL/CUL/TUV/CE	13.95	12.95
2164691	Mean Well	EPS-65-24	+24V @ 0-3A	65.04W	90-264 @ 47-63	4.0x2.0x1.1	3.75x1.75x0.13	240	1.0	0.5	88	UL/TUV/EN	13.95	12.49
173463	Mean Well†	LPS-100-24	+24V @ 0-4.2A	100.8W	88-264 @ 47-63	8.7x2.4x1.3	8.4x2.1x0.1	150	0.5	0.5	80	UL/CUL/TUV/CE	27.95	25.95
2129684	Eipac**	MSM7524	+24V @ 0-4.6A	110W	100-240 @ 50-60	5.7x3.4x1.6	5.2x3.4x1.5	240	3.0	1.0	80	UL/CUL/CE	12.95	11.95
2172412	Mean Well†	EPP-100-24	+24V @ 0-4.2A	100.8W	90-264 @ 47-63	4.0x2.0x1.1	2x1.75x0.129	240	1.0	0.5	92	UL/TUV/EN	39.95	35.95
301429	Mean Well†	PPS-125-24	+24V @ 0-5.2A	124.8W	90-264 @ 47-63	5.0x3.0x1.4	4.6x2.6x0.1	150	1.0	0.5	83	UL/CUL/TUV/CE	42.95	38.95
2172463	Mean Well†	EPP-150-24	+24V @ 0-6.25A	150W	90-264 @ 47-63	4.0x2.0 x 1.1	2x1.75x0.129	240	1.0	0.5	93	UL/TUV/EN	49.95	44.95
213672	Mean Well†	LPP-150-24	+24V @ 0-6.25A	150W	85-264 @ 47-63	8.7x2.4x1.6	8.3x2.6x0.2	150	0.5	0.5	83	UL/CUL/TUV/CE	34.95	31.95
2149458	Mean Well†	USP-150-24	+24V @ 0-6.3A	150W	90-295 @ 47-63	8.5x2.7x1.3	8.3x2.1x0.13	150	1	0.5	93	IEC/EN/UL	50.95	45.95
1773419	Astec†	LPS175	+24V @ 0-7.5AA	175W	85-264 @ 47-63	8.5x4.2x1.5	7.4x2.5x0.1	150	2.0	1.0	75	UL/CSA/CE	54.95	49.95
668730	Mean Well†	PPS-200-24	+24V @ 0-8.3A	199.2W	90-264 @ 47-63	5.0x3.0x1.4	3.7x7.8x0.14	150	1.0	0.5	89	UL/CUL/TUV/CE	54.95	49.95
2164279	Mean Well†	EPP-300-24	+24V @ 0-12.5A	200W	90-264 @ 47-63	5.0x3.0x1.4	3.0x2.6x0.137	150	1.0	0.5	92.5	UL/TUV/EN	64.95	58.95
236882	Mean Well	LPP-100-27	+27V @ 0-3.8A	102.6W	85-264 @ 47-63	8.7x2.4x1.3	8.4x2.4x1.3	150	0.5	0.5	83	UL/CUL/TUV/CE	14.95	—
2164551	Mean Well	EPS-45-48	+48V @ 0-1.1A	48W	90-264 @ 47-63	4x2x1.1	3.75x1.75x0.13	300	1	0.5	90	UL/TUV/EN	13.49	12.49
2164631	Mean Well	EPS-45-48-C	+48V @ 0-1.1A	52.8W	90-264 @ 47-63	4x2x1.1	3.75x1.75x0.13	300	1	0.5	90	UL/TUV/EN	16.49	14.95
2164711	Mean Well	EPS-65-48	+48V @ 0-1.36A	65W	90-264 @ 47-63	4x2x1.1	3.75x1.75x0.13	300	1	0.5	90	UL/TUV/EN	13.95	12.49
201954	Mean Well	PS-65-48	+48V @ 0-1.5A	64.8W	90-264 @ 47-440	5.0x3.0x1.7	4.6x2.6x0.16	100	2.0	1.0	80	UL/CUL/TUV/CE/CB	13.49	12.49
2172439	Mean Well†	EPP-100-48	+48V @ 0-1.6A	76.8W	90-264 @ 47-63	4x2x1.1	3.75x1.75x0.13	300	1	0.5	92.5	UL/TUV/EN	39.95	35.95
2172480	Mean Well†	EPP-150-48	+48V @ 0-2.1A	100.8W	90-264 @ 47-63	4x2x1.1	3.75x1.75x0.13	300	1	0.5	92	UL/TUV/EN	49.95	44.95
2149474	Mean Well†	USP-150-48	+48V @ 0-3.2A	150W	90-295 @ 47-63	8.5x2.7x1.3	8.3x2.1x0.13	250	1	0.5	93	IEC/EN/UL	50.95	45.95
2164295	Mean Well†	EPP-300-48	+48V @ 0-6.25A	300W	90-264 @ 47-63	5x3x1.4	4.6x2.6x0.13	250	1	0.5	93	UL/TUV/EN	64.95	58.95
<b>Double Output</b>														
2188617	Powdec	CML0522	+5V @ 0-1.5A; +12V @ 0-0.6A	15W	100-240 @ 50-60	3.5x2.3x1.1	3.1x2.0x0.1	50	4.0	2.0	65	UL/CSA/TUV/CE	\$9.95	\$8.95
212338	Mean Well	PD-25A	+5V @ 0.2-2.5A; +12V @ 0.1-1.5A	25W	85-264 @ 47-63	4.2x2.4x1.1	3.7x2.08x0.1	50;150	1.0	0.5	71	UL/CUL/TUV/CE	13.95	12.49
212330	Mean Well	PD-25B	+5V @ 0.2-2A; +24V @ 0.1-1A	25.2W	85-264 @ 47-63	4.2x2.4x1.1	3.7x2.1x0.1	50;200	1.0	0.5	77	UL/CUL/TUV/CE	13.95	12.49
2215697	Artesyn	NLP40-7629J	+5V @ 4A; +12V @ 0-2A	40W	90-264 @ 47-63	4.2x2.5x1.1	4.0x2.2x0.1	50;120	3.0	1.0	75	UL/CSA/CE	12.95	11.95
194862	Mean Well	PD-45A	+5V @ 0.4-3.2A; +12V @ 0.2-2	40W	90-264 @ 47-440	5.0x2.5x1.5	4.5x2.5x0.2	50;120	3.0	1.0	77	UL/CSA	14.95	13.49
2197741	Skynet	SNP-N563	+5V @ 1.0-8A; +3.3V @ 0.5-6A	60W	85-264 @ 47-63	5.0x3.0x1.1	4.6x2.6x0.2	50	3.0	1.0	70	UL	11.95	10.95
194889	Mean Well	PD-65A	+5V @ 0.4-7A; +12V @ 0.2-3.2A	61.1W	90-264 @ 47-440	5.0x3.0x1.7	4.5x2.5x0.2	50;120	3.0	1.0	78	UL/CUL/TUV/CE	14.49	13.49
692377	Autec	UPS65-1002	+5V @ 0.5-3.5A; +12V @ 0.1-4A	65W	90-260 @ 47-63	6.0x3.5x1.5	4.8x3.2x0.2	50	2.0	0.5	65	UL/CSA/TUV	13.95	11.95
194897	Mean Well	PD-65B	+5V @ 0.4-3.5A; +24V @ 0.2-2A	65.5W	90-264 @ 47-440	5.0x3.0x1.7	4.5x2.5x0.2	50;150	3.0	1.0	81	UL/CUL/TUV/CE	14.49	13.49
148690	Mean Well	PD-2512	+12V @ 0.1-1.2A; -12V @ 0.1-1A	24W	85-264 @ 47-63	4.2x2.4x1.1	3.7x2.1x0.1	50	3.0	0.5	74	UL/CUL/TUV/CE	13.95	12.49
2100857	Mean Well	PD-25-15	+15V @ 0-1A, -5V @ 0-1A	25W	85-264 @ 47-63	4.2x2.4x1.1	3.7x2.1x0.1	50	3.0	0.5	75	UL/CUL/TUV/CE	13.95	12.49
<b>Triple Output</b>														
2129676	Eipac**	MSM40D	+5.1V @ 0-4A; +24V @ 0-1A; -12V @ 0.4A	40W	100-240 @ 50-60	5.0x3.0x1.1	4.6x2.5x0.2	50	5.0	5.0	70	UL/CUL/CSA/CE	\$9.95	\$8.95
2210757	Phihong	PSS-40-304	+5V @ 0-4.5A; +15V @ 0-2A; -15V @ 0.5A	40W	100-240 @ 50-60	4.2x2.5x1.2	4.0x2.2x0.1	50; 150;150	3.0	3.0	70	CUL/CE/NEMKO	16.95	15.49
229122	Phihong	PSA4531	+5V @ 0-4A; +12V @ 0-1.5A; -12V @ 0-0.5A	44W	90-264 @ 47-63	5.0x3.0x1.2	4.6x2.6x0.2	50; 120;120	2.0	1.0	70	UL/CSA/TUV/CE	35.95	33.95
88402	Mean Well	PT-45B	+5V @ 0.4-3A; +12V @ 0.2-2A; -12V @ 0-0.3A	45W	90-264 @ 47-440	5.0x3.0x1.1	4.6x2.6x0.2	50; 120;100	3.0	1.0	75	UL/CUL/TUV/CE	16.95	14.95
2106108	Mean Well	PT-65A	+5V @ 0-5.5A; 12V @ 2.5A; -5V @ 0.5A	60W	90-264 @ 47-440	5.0x3.0x1.7	2.9x2.5x0.149	50;120;50	3;4;1	1;2;1	76	EN/TUV/UL	15.95	14.49
216734	Mean Well	PT-65B	+5V @ 0.4-5.5A; +12V @ 0.2-2.5A; -12V @ 0-0.5A	63.5W	90-264 @ 47-440	5.0x3.0x1.7	4.6x2.6x0.2	50; 120;100	3.0	1.0	77	UL/CUL/TUV/CE	15.95	14.49
216726	Mean Well	PT-65C	+5V @ 0.4-5.5A; +15V @ 0.2-2A; -15V @ 0-0.5A	65W	90-264 @ 47-440	5.0x3.0x1.7	4.6x2.6x0.2	50; 120;100	3.0	1.0	77	UL/CUL/TUV/CE	15.95	14.49
215707	Mean Well	PT-65D	+5V @ 0.5-5A; +12V @ 0.2-4A; +24V @ 0.2-1.3A	68W	90-264 @ 47-440	5.0x3.0x1.7	4.6x2.6x0.2	50; 100;200	2.0	1.0	79	UL/CUL/TUV/CE	15.95	14.49

\* Primary output      \*\* Medical rated      § Efficiency

\* For additional products, availability and specifications visit [Jameco.com](http://Jameco.com) and enter the Web Code in the product search box

3 LEVELS OF SAVINGS  
**NAME BRANDS**    **HOUSE BRANDS**    **SPECIAL BUY**

Order by Phone at 1-800-831-4242 or Online at [www.Jameco.com](http://www.Jameco.com)