

Enclosed Switching AC-to-DC Power Supplies

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **SPECIAL BUY**



Enclosed Switching AC-to-DC Power Supplies

- 100% full-load burn-in test
- Wide AC input range
- Manufacturer warranty varies



* Web Code: EPS

Complete specifications available online



SP-150



HRPG-150




HRP-300



RSP-1500



NES-75

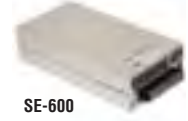

SE-600

Part No.	Manufacturer	Mfr. Part No.	Output		Size (L" x W" x H")	Ripple & Noise (mV p-p)*	Load Reg. (±%)*	Line Reg. (±%)*	EFF (%)§	PFC	Certification	Pricing		
			Voltage @ Current (min-max)	Power								1	10	
Single Output														
2106685	Mean Well	RS-15-3.3	+3.3V @ 0-3A	9.9W	2.5 x 2.0 x 1.1	80	2.0	0.5	72	—	UL/CUL/TUV/CE/CB	\$8.95	\$7.95	
693193	Mean Well	RS-25-3.3	+3.3V @ 0-6A	19.8W	3.0 x 2.0 x 1.1	80	2.0	0.5	72	—	UL/CUL/TUV/CE/CB	11.49	10.49	
1954906	Mean Well**	PM-05-5	+5V @ 0-1A	5W	2.5 x 2.0 x 0.8	80	1.0	1.0	71	—	EN/IEC/TUV/UL	10.49	9.49	
1919043	Mean Well	RS-15-5	+5V @ 0-3A	15W	2.5 x 2.0 x 1.1	80	1.5	0.5	77	—	UL/CUL/TUV/CE/CB	8.95	7.95	
323282	Mean Well	RS-25-5	+5V @ 0-5A	25W	3.1 x 2.0 x 1.1	80	1.0	0.5	77	—	UL/CUL/TUV/CE/CB	11.49	10.49	
123290	Mean Well	S-40-5	+5V @ 0-8A	40W	5.1 x 3.9 x 1.5	75	1.0	0.5	72	—	UL/CUL/TUV/CE/CB	21.95	19.95	
323388	Mean Well	RS-50-5	+5V @ 0-10A	50W	3.9 x 3.8 x 1.4	80	1.0	0.5	78	—	UL/CUL/TUV/CE/CB	13.95	12.95	
323708	Mean Well	RS-100-5	+5V @ 0-16A	80W	6.3 x 3.8 x 1.5	80	1.0	0.5	77	—	UL/CUL/TUV/CE/CB	22.95	20.95	
194791	Mean Well	SP-100-5	+5V @ 0-20A	100W	7.0 x 3.9 x 1.8	100	1.0	0.5	76	✓	UL/CUL/TUV/CE/CB	39.95	35.95	
323821	Mean Well	RS-150-5	+5V @ 0-26A	130W	7.8 x 3.9 x 1.5	80	1.0	0.5	78	—	UL/CUL/TUV/CE/CB	23.95	21.95	
123394	Mean Well	S-150-5	+5V @ 0-30A	150W	7.0 x 4.3 x 2.0	150	0.5	0.5	78	—	UL/CUL/TUV/CE/CB	34.95	31.95	
201912	Mean Well	SP-150-5	+5V @ 0-30A	150W	7.0 x 3.9 x 2.0	100	1.0	0.5	75	✓	UL/CUL/TUV/CE/CB	42.95	38.95	
202042	Mean Well	SP-200-5	+5V @ 0-40A	200W	7.0 x 3.9 x 2.0	100	1.0	0.5	71	✓	UL/CUL/TUV/CE/CB	49.95	44.95	
244735	Mean Well	SP-320-5	+5V @ 0-55A at 230VAC; 0-44A at 115VAC	275W	8.5 x 4.5 x 2.0	150	1.0	0.5	79	✓	UL/CUL/TUV/CE/CB	61.95	55.95	
2172068	Mean Well	RSP-320-5	+5V @ 0-60A	300W	8.5 x 4.5 x 1.2	150	1.0	0.5	85	✓	UL/CUL/TUV/CB/CE	69.95	63.95	
2149562	Mean Well	SE-350-5	+5V @ 0-60A	300W	8.5 x 4.5 x 2.0	150	2.0	0.5	78	—	UL/CUL	43.95	39.95	
693644	Mean Well	SP-480-5	+5V @ 0-85A	425W	10.9 x 5.0 x 1.7	80	1.0	0.5	79	✓	UL/CUL/TUV/CE/CB	134.95	119.95	
374002	Mean Well	SE-600-5	+5V @ 0-100A	500W	9.7 x 5.0 x 2.5	150	2.0	0.5	78	—	UL/CUL	84.95	77.95	
693661	Mean Well	SP-750-5	+5V @ 0-120A	600W	10.9 x 5.0 x 2.5	120	2.0	0.5	80	✓	UL/CUL/TUV/CE/CB	199.95	179.95	
394215	Mean Well	SP-320-7.5	+7.5V @ 0-40A	300W	8.5 x 4.5 x 2.0	150	1.0	0.5	83	✓	UL/CUL/TUV/CE/CB	61.95	55.95	
2193141	Mean Well	IRM-05-12	+12V @ 0-0.42A	5.04W	1.8 x 1.0 x 0.85	200	0.5	0.3	75	—	UL/CUL/TUV/CB/CE	7.49	6.75	
1954551	Mean Well**	PM-10-12	+12V @ 0-0.85A	10.2W	2.8 x 2.0 x 0.9	150	1.0	0.5	78	—	EN/IEC/TUV/UL	11.95	10.95	
1919051	Mean Well	RS-15-12	+12V @ 0-1.3A	15.6W	2.5 x 2.0 x 1.1	120	0.5	0.5	81	—	UL/CUL/TUV/CE/CB	8.95	7.95	
323300	Mean Well	RS-25-12	+12V @ 0-2.1A	25.2W	3.0 x 2.0 x 1.1	120	0.5	0.5	79	—	UL/CUL/TUV/CE/CB	11.49	10.49	
123255	Mean Well	S-25-12	+12V @ 0-2.1A	25.2W	3.9 x 3.8 x 1.4	100	0.5	0.5	76	—	UL/TUV/CE	18.95	16.95	
323337	Mean Well	RS-35-12	+12V @ 0-3A	36W	3.9 x 3.2 x 1.4	120	0.5	0.5	81	—	UL/CUL/TUV/CE/CB	12.49	11.49	
123298	Mean Well	S-40-12	+12V @ 0-3.5A	42W	5.1 x 3.9 x 1.5	100	0.5	0.5	76	—	UL/CUL/TUV/CE/CB	21.95	19.95	
323396	Mean Well	RS-50-12	+12V @ 0-4.2A	50.4W	3.9 x 3.8 x 1.4	120	0.5	0.5	81	—	UL/CUL/TUV/CE/CB	13.95	12.95	
123335	Mean Well	S-60-12	+12V @ 0-5A	60W	6.3 x 3.8 x 1.5	120	0.5	0.5	76	—	UL/CUL/TUV/CE/CB	24.95	22.49	
323599	Mean Well	RS-75-12	+12V @ 0-6A	72W	5.1 x 3.9 x 1.5	120	0.5	0.5	81	—	UL/CUL/TUV/CE/CB	16.95	15.49	
194838	Mean Well	SP-75-12	+12V @ 0-6.3A	75.6W	7.0 x 3.9 x 1.3	80	0.5	0.5	77	✓	UL/CUL/TUV/CE/CB	32.95	29.95	
2105017	Mean Well	NES-100-12	+12V @ 0-8.5A	102W	6.3 x 3.8 x 1.5	120	0.5	0.5	83	—	UL/CUL/CE/CB	21.95	19.49	
123386	Mean Well	S-100F-12	+12V @ 0-8.5A	102W	7.8 x 3.9 x 1.5	125	0.5	0.5	80	—	UL/TUV/CE/CB	29.95	27.95	
323716	Mean Well	RS-100-12	+12V @ 0-8.5A	102W	6.3 x 3.8 x 1.5	120	0.5	0.5	81	✓	UL/CUL/TUV/CE/CB	22.95	20.95	
194803	Mean Well	SP-100-12	+12V @ 0-8.5A	102W	7.0 x 3.9 x 1.8	100	0.5	0.5	80	✓	UL/CUL/TUV/CE/CB	39.95	35.95	
2172244	Mean Well**	MSP-100-12	+12V @ 0-8.5A	102W	6.3 x 3.8 x 1.5	120	0.8	0.3	87.5	✓	ANSI/AAMI/IEC	55.95	49.95	
123423	Mean Well	S-150-12	+12V @ 0-12.5A	150W	7.0 x 4.3 x 2.0	180	0.3	0.3	82	—	UL/CUL/TUV/CE/CB	34.95	31.95	
323839	Mean Well	RS-150-12	+12V @ 0-12.5A	150W	7.8 x 3.9 x 1.5	120	0.5	0.5	83	—	UL/CUL/TUV/CE/CB	23.95	21.95	
2189118	Mean Well	RSP-150-12	+12V @ 0-12.5A	150W	7.8 x 3.9 x 1.2	100	0.5	0.5	90	✓	UL/CUL/CE	49.95	44.95	
173421	Mean Well	SP-150-12	+12V @ 0-12.5A	150W	7.0 x 3.9 x 2.0	100	0.5	0.5	80	✓	UL/CUL/TUV/CE/CB	42.95	38.95	
2138839	Globe Tek	SP-200-12GL(R)	+12V @ 0-16.7A	200.4W	7.8 x 3.9 x 2.0	100	1.0	0.5	79	✓	UL/CUL/TUV/CE	19.95	17.95	
194774	Mean Well	SP-200-12	+12V @ 0-16.7A	200.4W	7.0 x 3.9 x 2.0	100	0.5	0.5	79	✓	UL/CUL/TUV/CE/CB	49.95	44.95	
2101497	Mean Well	SP-240-12	+12V @ 0-20A	240W	7.5 x 3.7 x 2.0	150	0.5	0.3	86	✓	UL/CUL/TUV/CE/CB	49.95	44.95	
2122706	Mean Well	SPV-300-12	+12V @ 0-25A	300W	8.5 x 4.5 x 1.9	150	0.5	0.3	83.5	—	EN/TUV/UL	99.95	89.95	
207204	Mean Well	S-320-12	+12V @ 0-25A	300W	8.5 x 4.5 x 2.0	150	0.5	0.5	82	✓	UL/CUL	59.95	54.95	
244743	Mean Well	SP-320-12	+12V @ 0-25A at 230VAC; 0-20A @ 115VAC	300W	8.5 x 4.5 x 2.0	150	0.5	0.3	86	✓	UL/CUL/TUV/CE/CB	61.95	55.95	
2102203	Mean Well	HRP-300-12	+12V @ 0-27A	324W	7.8 x 4.1 x 1.6	120	0.5	0.3	88	✓	UL/CUL/TUV/CE/CB	76.95	69.95	
2094872	Mean Well	HRPG-300-12	+12V @ 0-27A	324W	7.8 x 4.1 x 1.6	120	0.5	0.3	88	✓	UL/CUL/TUV/CE/CB	89.95	79.95	
2166039	Mean Well**	MSP-300-12	+12V @ 0-27A	324W	7.8 x 4.1 x 1.6	120	0.5	0.3	88	✓	ANSI/AAMI/IEC	104.95	94.95	
2149503	Mean Well	SE-350-12	+12V @ 0-29A	348W	8.5 x 4.5 x 2.0	150	1.0	0.5	83	—	UL/CUL	43.95	39.95	
2094928	Mean Well	SE-450-12	+12V @ 0-37.5A	450W	8.9 x 4.9 x 2.0	200	1.0	0.5	83	✓	UL/CUL	64.95	58.95	
2122319	Mean Well	HRP-450-12	+12V @ 0-37.5A	450W	8.6 x 4.1 x 1.6	120	0.5	0.3	88	✓	UL/CUL/TUV/CE/CB	114.95	104.95	
2193352	Mean Well**	MSP-450-12	+12V @ 0-37.5A	450W	8.6 x 4.1 x 1.6	120	0.5	0.3	88	✓	UL/CUL/CB/CE	149.95	134.95	
301373	Mean Well	SP-480-12	+12V @ 0-40A at 230VAC; 0-36A @ 115VAC	480W	10.9 x 5.0 x 1.7	120	0.5	0.3	85	✓	UL/CUL/TUV/CE/CB	134.95	119.95	
190693	Mean Well	SP-500-12	+12V @ 0-40A at 230VAC; 0-34A @ 115VAC	480W	6.7 x 4.7 x 3.7	240	0.5	0.5	84	✓	UL/CUL/TUV/CE/CB	149.95	134.95	

* Primary output

** Medical rated

§ Efficiency