

 

# AC-to-DC Regulated Switching Table-Top Power Supplies

Jameco carries the full line of Mean Well Power products. For additional products visit [www.Jameco.com/meanwellproducts](http://www.Jameco.com/meanwellproducts)



## AC-to-DC Regulated Switching Table-Top Power Supplies

We are happy to change the power plug on any listed table-top power supply to a connector of your choice (see pg 99) for just \$2.50 ea. Overmolding also available @ \$4.00 ea. A 100 pc. minimum order applies.

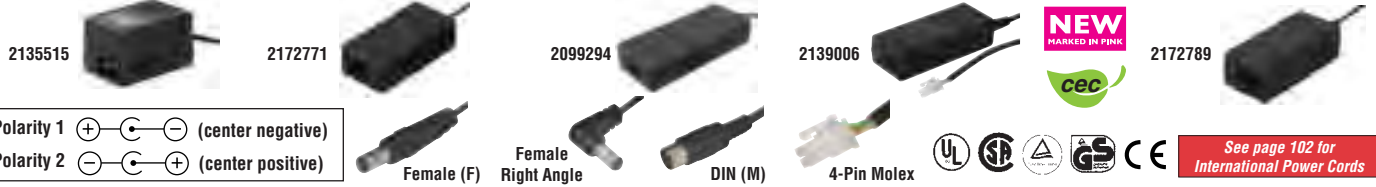

Female (F) Right Angle DIN (M) 4-Pin Molex



See page 102 for International Power Cords

Part No.	Manufacturer	Product No.	Output Volts (VDC)/ Current (A)	Output Connector ID x OD/F = female; M = male; Polarity ◆	Input VAC@Hz	Output Power (W)	LED Ind.	Size (L" x W" x H")	Cords* (DC/AC)	Wt. (lbs.)	Agency Approvals	Pricing		
												1	10	
<b>3-Wire AC Input – Regulated Switching Table-Top – Single Output (Continued)</b>													<b>* Web Code: DDZ</b>	
1940635	Mean Well	GS25A24-P1J	+24/1.04	2.1mm x 5.5mm F 2	100-240@50-60	25	Yes	3.7 x 2.1 x 1.4	6/6'	0.5	UL/CUL/TUV/CE	\$13.95	\$12.95	
2214029	Mean Well	GSM25B24-P1J	+24/1.04	2.1mm x 5.5mm F 2	80-264@47-63	25	Yes	3.1 x 2.1 x 1.3	6/1'	0.4	UL/CUL/CE/FCC/TUV/CB	13.49	11.95	
380577	Mean Well	GS25A24-P1MU	+24/1.04	2.5mm x 5.5mm F 2	100-240@50-60	25	Yes	3.7 x 2.1 x 1.4	6/6'	0.6	UL/CUL/TUV/CE	19.95	17.95	
2172789	ReliaPro	EA1030D1	+24/1.25	2.1mm x 5.5mm F 2	100-240@50-60	30	Yes	3.8 x 1.7 x 1.2	6/6'	0.4	UL/CUL/TUV/CE	12.95	11.95	
2214109	Mean Well	GSM36B24-P1J	+24/1.5	2.1mm x 5.5mm F 2	80-264@47-63	36	Yes	3.1 x 2.1 x 1.3	6/1'	0.5	UL/CUL/CE/FCC/TUV/CB	14.49	12.95	
1952353	Mean Well	GS40A24-P1J	+24/1.67	2.1mm x 5.5mm F 2	90-264@47-63	40	Yes	4.9 x 2.0 x 1.2	6/2'	0.7	UL/CUL/TUV/CE	15.95	14.49	
2214184	Mean Well	GSM40B24-P1J	+24/1.67	2.1mm x 5.5mm F 2	80-264@47-63	40	Yes	1.3 x 1.9 x 5.0	5/1'	0.63	UL/CUL/CE/FCC/TUV/CB	18.95	17.49	
1537256	ReliaPro	OH-1048A2401700U-U	+24/1.7	2.5mm x 5.5mm F 2	90-264@47-63	40	Yes	4.5 x 2.0 x 1.3	6/2'	0.5	UL/CUL/CE	15.95	14.49	
1942788	ReliaPro	EA1050B-240	+24/2.5	2.1mm x 5.5mm F 2	100-240@50-60	60	Yes	4.8 x 2.4 x 1.4	6/2'	1.8	UL/CUL/TUV/CE	17.49	15.49	
1952214	Mean Well	GS60A24-P1J	+24/2.5	2.1mm x 5.5mm F 2	90-264@47-63	60	Yes	4.9 x 2.0 x 1.3	6/2'	0.7	UL/CUL/TUV/CE	17.95	15.95	
1950913	ReliaPro	EA1050B-240	+24/2.5	2.5mm x 5.5mm F 2	100-240@50-60	60	Yes	4.8 x 2.4 x 1.4	6/2'	1.8	UL/CUL/TUV/CE	19.95	18.95	
2214264	Mean Well	GSM60B24-P1J	+24/2.5	2.1mm x 5.5mm F 2	80-264@47-63	60	Yes	1.3 x 1.9 x 5.0	5/1'	0.7	UL/CUL/CE/FCC/TUV/CB	21.95	19.95	
2172797	ReliaPro	EA11001D-240	+24/3.75	2.5mm x 5.5mm F 2	100-240@50-60	90	Yes	5.4 x 2.3 x 0.4	4/2'	0.9	UL/CUL/TUV/CE	26.95	24.95	
2078338	Mean Well	GS90A24-P1M	+24/3.75	2.5mm x 5.5mm F 2	100-240@50-60	90	Yes	5.9 x 2.3 x 1.2	4/2'	0.9	UL/CUL/TUV/CE	28.95	25.95	
2210491	Mean Well	GSM90B24-P1M	+24/3.75	2.5mm x 5.5mm F 2	80-264@47-63	90	Yes	5.7 x 2.4 x 1.3	4/1'	0.99	UL/CUL/CE/FCC/TUV	31.95	28.95	
2135208	Mean Well	GS120A24-P1M	+24/5.0	2.5mm x 5.5mm F 2	85-264@47-63	120	Yes	6.6 x 2.6 x 1.4	4/2'	1.4	UL/CUL/TUV/CE	42.95	38.95	
2214310	Mean Well	GSM120B24-R7B	+24/5.0	4-pin DIN M	80-264@113-370	120	Yes	6.6 x 2.7 x 1.4	4/1'	1.3	UL/CUL/CE/FCC/TUV/CB	49.95	44.95	
2122212	Mean Well	GS160A24-R7B	+24/6.67	4-pin DIN M	85-264@47-63	160	Yes	6.9 x 2.8 x 1.4	4/2'	1.5	UL/CUL/TUV/CE	50.95	45.95	
2099286	Mean Well	GS220A24-R7B	+24/9.2	4-pin DIN M	90-264@47-63	220	Yes	8.3 x 3.4 x 1.8	3.3/2'	2.4	UL/CUL/TUV/CE	74.95	67.95	
2188191	Mean Well	GS280A24-C4P	+24/11.7	4-pin rectangular	90-264@47-63	280	Yes	8.7 x 3.7 x 1.8	3/2'	2.75	† See below	89.95	79.95	
1940643	Mean Well	GS25A28-P1J	+28/0.89	2.1mm x 5.5mm F 2	100-240@50-60	25	Yes	3.7 x 2.1 x 1.4	6/6'	0.7	UL/CUL/TUV/CE	11.95	10.95	
1940651	Mean Well	GS25A48-P1J	+48/0.52	2.1mm x 5.5mm F 2	100-240@50-60	25	Yes	3.7 x 2.1 x 1.4	6/2'	0.5	UL/CUL/TUV/CE	11.95	10.95	
172065	Mean Well	SPU50-9U	+48/1.25	2.1mm x 5.5mm F 2	100-240@50-60	60	Yes	5.6 x 2.9 x 1.7	6/6'	1.3	UL/CUL/TUV/CE	14.95	13.95	
1952396	Mean Well	GS60A48-P1JU	+48/1.25	2.1mm x 5.5mm F 2	90-264@47-63	60	Yes	4.9 x 2.0 x 1.2	6/6'	0.7	UL/CUL/TUV/CE	19.95	17.95	
2210503	Mean Well	GSM90B48-P1M	+48/1.87	2.5mm x 5.5mm F 2	80-264@47-63	90	Yes	5.7 x 2.4 x 1.2	4/1'	0.99	UL/CUL/CE/FCC/TUV	31.95	28.95	
2122221	Mean Well	GS160A48-R7B	+48/3.34	4-pin DIN M	85-264@47-63	160	Yes	6.9 x 2.8 x 1.4	4'	0.94	UL/TUV/BSMI/CCC	50.95	45.95	
2100945	Mean Well	GS220A48-R7B	+48/4.6	4-pin DIN M	90-264@47-63	221	Yes	8.3 x 3.3 x 1.8	3'	0.94	CE/CUL/TUV/UL	74.95	67.95	
<b>3-Wire AC Input – Regulated Switching Table-Top – Double &amp; Triple Output</b>													<b>* Web Code: TDO</b>	
228988	Phihong	PSA18U-120	Din +12/1.5	3-pin DIN M	100-240@50-60	18	No	3.8 x 2.2 x 1.2	5/2'	1.1	UL/CUL/TUV	\$19.95	\$17.95	
196270	ReliaPro	PSU25A13	+5/2.5, +12/1.0	4-pin mini DIN M	100-240@47-63	25	No	4.2 x 2.6 x 1.4	6/4'	1.2	UL/CUL/TUV/CE	34.95	31.49	
221720	Mean Well	P25A14E-R1BU	+5/2.5, +15/0.3	5-pin DIN M	100-240@50-60	25	Yes	4.3 x 2.6 x 1.4	6/6'	0.8	UL/CUL/TUV/CE	26.95	24.95	
190960	Mean Well	P25A13D-R1B	+5/2.5, +12/0.8	5-pin DIN M	100-240@50-60	26	Yes	4.1 x 2.6 x 1.4	6/2'	1.1	CUL/TUV/CE	29.95	26.95	
237367	Mean Well	P50A14E-R1B	+5/3.5, +15/1.2	5-pin DIN M	100-240@47-63	42	Yes	5.8 x 3.0 x 1.7	4/2'	1.2	UL/CUL/TUV/CE	44.95	39.95	
2217844	ReliaPro	T40-9312A	+5/5.0, +12/1.2	6-pin DIN M	100-240@50-60	43	No	6.0 x 3.3 x 1.9	4/2'	1.2	UL/CUL/TUV/CE	39.95	34.95	
221702	Mean Well	P50A13D-R1BU	+5/4.0, +12/2.0	5-pin DIN M	100-240@50-60	50	Yes	5.7 x 3.0 x 1.7	4/6'	1.5	UL/CUL/TUV/CE	49.95	44.95	

\* See accessory table-top power cord chart on page 94 when AC cord needed; refer to 1, 2 or 3 in "Cord (DC/AC)" column above for correct power cord

\*\*Medical (2-wire)

◆ CEC † UL/CUL/PSE/TUV/BSMI/CCC/CB/FCC/CE

## REGULATED SWITCHING TABLE TOP POWER SUPPLIES — BEST SELLERS

Part No.	Voltage	Current	Page	Price	Part No.	Voltage	Current	Page	Price
196218	5VDC	2A	95	\$15.95	2205165	12VDC	10A	96	\$39.95
1940408	9VDC	2A	95	11.95	1940619	15VDC	1.66A	96	11.95
1940264	12VDC	3.5A	96	14.49	1942788	24VDC	2.5A	97	17.49
1952370	12VDC	5A	96	17.95	2172797	24VDC	3.75A	97	26.95

\* For additional products, availability and specifications visit [Jameco.com](http://Jameco.com) and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at [www.Jameco.com](http://www.Jameco.com)