

DC Brushless Tubeaxial Fans



Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers

NEW MARKED IN PINK



695050



2134125



2131944



* 5V Web Code: TAS

* 12V Web Code: LBZ

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Fans

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2134088	Adda	AD2005LX-K70	5	20 x 20 x 6	0.6	Hypro	60	0.3	TUV/CE	12	5.5"	\$10.95	\$9.95	\$8.95	\$7.95
2095277	Adda	AD2005LX-G70	5	20 x 20 x 10	0.6	Hypro	80	0.4	UL/CSA/TUV/CE	20	5.5"	11.95	10.95	9.95	8.95
2131872	Adda	AD0205MX-K53-LF	5	25 x 25 x 6	2.4	Hypro	120	0.6	CE	29	6"	8.95	7.95	6.95	5.95
131247	Adda	AD0205LX-G50-LF	5	25 x 25 x 10	1.8	Hypro	100	0.5	UL/CSA/CE	15.6	5.5"	7.95	6.95	6.25	5.95
2132197	Adda	AD0205MB-G50GL	5	25 x 25 x 10	2.2	Ball	120	0.6	UL/CUL/TUV/CE	23	5.5"	8.95	7.95	6.95	6.25
695050	Sunon	MC25100V2-000-A99	5	25 x 25 x 10	3.0	Vapo	80	0.4	UL/CUL	16	5.5"	9.95	8.95	7.95	6.95
1928311	Adda	AD0305LB-K70	5	30 x 30 x 6	2.5	Ball	70	0.35	UL/CUL/TUV/CE	18.5	6"	4.95	4.49	3.95	3.59
2099497	Adda	AD0305LX-K70(X)	5	30 x 30 x 6	2.5	Hypro	90	0.45	UL/CUL/TUV/CE	20	5.5"	7.95	6.95	6.25	5.59
2188924	Adda	AD0305HX-K70(TX)	5	30 x 30 x 6	3.5	Hypro	180	0.9	UL/CUL/TUV/CE	32	5.5"	6.95	5.95	5.49	4.95
2234695	Sunon	MC30060V1-0000-A99	5	30 x 30 x 6	4.9	Vapo	112	0.56	UL/CUL/TUV	28	6"	9.95	8.95	7.95	6.95
2131899	Adda	AD3505LX-G50(TX)	5	30 x 30 x 10	3.2	Hypro	120	0.6	UL/CUL/TUV/CE	20	5.5"	10.95	9.95	8.95	7.95
2203354	Adda	AB3505LB-QB0†	5	35 x 35 x 7	0.9	Ball	100	0.5	UL/CUL/TUV/CE	19	12"	6.95	5.95	4.95	3.95
2235292	Adda	AP3505LB-J70(S)§	5	35 x 35 x 8	2.5	Ball	90	0.45	UL/CUL/CE	20	5.5"	6.95	6.25	5.59	4.95
2235250	Adda	AB3505LB-GA0†	5	35 x 35 x 10	0.9	Ball	90	0.45	UL/CUL/TUV/CE	23	5.5"	7.95	6.95	6.25	5.59
2134096	Adda	AD3505MX-G53	5	35 x 35 x 10	6.0	Hypro	130	0.65	UL/CUL/TUV/CE	30	12"	4.95	4.49	3.95	3.49
2167242	Adda	AD0405LB-K90(S)-LF	5	40 x 40 x 6.8	4.5	Ball/Sleeve	50	0.25	UL/CUL/TUV/CE	19.9	5.4"	7.95	6.95	6.25	5.95
2220200	Adda	AD0405MB-K90	5	40 x 40 x 6.8	5.2	Ball	90	0.45	UL/CUL/TUV/CE	23.8	5.5"	7.95	6.95	6.25	5.59
2220162	Adda	AD0405HX-J70	5	40 x 40 x 8	4.9	Hypro	80	0.65	CE	35	5.5"	9.95	8.95	7.95	6.95
1928370	Adda	AD0405DB-G70(T)	5	40 x 40 x 10	3.3	Ball	50	0.25	CE	14	12"	9.95	8.95	7.95	6.95
2133886	Adda	AD0405LX-G70	5	40 x 40 x 10	4.7	Hypro	80	0.4	UL/CUL/TUV/CE	21	11"	5.95	5.39	4.79	4.39
2231742	Adda	AD0405LB-G70	5	40 x 40 x 10	4.7	Ball	80	0.4	UL/CUL/TUV/CE	21	11"	5.95	5.46	4.95	4.49
2258814	Adda	AD0405MB-G76	5	40 x 40 x 10	5.0	Ball	110	0.55	UL/CUL/TUV/CE	22	4" w/ conn†	4.95	4.49	3.95	3.49
2131928	Adda	AD0405MX-G76-LF	5	40 x 40 x 10	5.7	Hypro	110	0.55	UL/CUL/TUV/CE	15.9	11"†	4.95	4.49	3.95	3.49
2220091	Adda	AD0405MX-G70	5	40 x 40 x 10	5.7	Hypro	110	0.55	UL/CUL/TUV/CE	15.9	4"	5.95	5.39	4.79	4.29
2138628	Adda	AD0405MB-G70-LF	5	40 x 40 x 10	5.7	Ball	110	0.55	UL/CUL/TUV/CE	22	12"	7.95	6.95	5.95	4.95
1928353	Adda	AD0405HX-G70	5	40 x 40 x 10	6.7	Hypro	190	0.95	UL/CUL/TUV/CE	30	11"	6.95	6.25	5.59	4.95
2229933	Sunon	EE40100S1-0000-999	5	40 x 40 x 10	8.0	Sleeve	271	1.36	UL/CUL/TUV	32	12"	7.95	6.95	6.25	5.95
2132189	Adda	AD0405HB-G70	5	40 x 40 x 10	8.7	Ball	100	0.8	UL/CUL/TUV/CE	25	12" w/ conn	4.95	4.49	3.95	3.49
2230993	Delta	FBK04F05L	5	40 x 40 x 20	3.9	Ball	120	0.6	UL/UR	24	10"	6.95	6.25	5.59	4.95
1928361	Adda	AD0405DS-C50(T1)	5	40 x 40 x 20	4.5	Sleeve	90	0.45	UL/CUL/TUV/CE	17.5	5.5"	6.95	6.25	5.59	4.95
2203371	Adda	AD0405HX-G73	5	40 x 40 x 20	6.7	Hypro	190	0.95	UL/CUL/TUV/CE	25	11"†	8.95	7.95	6.95	6.25
2121295	Adda	AD0405HB-C50	5	40 x 40 x 20	8.9	Ball	290	1.45	UL/CUL/TUV/CE	31.9	3" w/ conn	10.95	9.95	8.95	7.95
2233300	Adda	AB4505LX-QA0†	5	45 x 45 x 7	1.5	Hypro	70	0.35	CE	23.3	5"	14.95	13.49	11.95	10.95
2121471	Adda	AB4505MX-QA0†	5	45 x 45 x 7	1.7	Hypro	110	0.55	CE	28	5"	14.95	13.49	11.95	10.95
2235305	Adda	AP4505LX-J90§	5	45 x 45 x 8	4.2	Hypro	70	0.35	UL/CUL/CE	19.5	5"	8.95	7.95	6.95	6.25
2134133	Adda	AP4505HB-J90§	5	45 x 45 x 8	6.0	Hypro	120	0.6	UL/CUL/TUV/CE	31	5"	9.95	8.95	7.95	6.95
2233326	Adda	AB4505MB-GD3†	5	45 x 45 x 10	2.31	Ball	150	0.75	UL/CUL/TUV/CE	31.1	2"†	12.95	11.49	9.95	8.95
2233318	Adda	AD4505MX-G70	5	45 x 45 x 10	7.01	Hypro	180	0.9	UL/CUL/TUV/CE	22	12"	9.95	8.95	7.95	6.95
2235284	Adda	AP0505MX-J90-4P§	5	50 x 50 x 8	7.1	Hypro	120	0.6	UL/CUL/CE	25.5	3.5" w/ conn	7.95	6.95	6.25	5.59
2134125	Adda	AP0505HB-J90§	5	50 x 50 x 8	9.5	Ball	140	0.7	UL/CUL/CE	33	5"	3.95	3.49	2.95	2.49
136494	Delta	AFB0505LA	5	50 x 50 x 10	7.4	Ball	120	0.4	UL/CE/CSA/VDE	26	11"	5.95	4.95	3.95	3.49
2121324	Adda	AD0505MB-G76LF	5	50 x 50 x 10	10.5	Ball	180	0.9	UL/CUL/TUV/CE	24	11"†	7.95	6.95	5.95	4.95
2150774	Adda	AD0505MB-G70-LF	5	50 x 50 x 10	10.5	Ball	180	0.9	UL/CUL/TUV/CE	24	12"	9.95	8.95	8.49	7.95
2186241	Sunon	KDE0505PFV1.11.MSA.GN	5	50 x 50 x 10	13	Vapo	270	1.4	UL/CUL/VDE	30	16" w/ conn	8.95	7.95	6.95	5.95
2132138	Adda	AD0605HS-D71GL	5	60 x 60 x 15	16.6	Sleeve	370	1.85	UL/CUL/TUV/CE	32.4	5"	12.95	11.49	9.95	8.95
2132120	Adda	AD0605LB-A72GL	5	60 x 60 x 25	13.8	Ball	150	0.75	UL/CUL/TUV/CE	20.3	12" 2	5.95	5.39	4.79	4.29
2131944	Adda	AD0605HB-A71-LF	5	60 x 60 x 25	23.2	Ball	450	2.25	UL/CUL/TUV/CE	32	11"	6.95	6.25	5.59	4.95
2131952	Adda	AD0605HB-A72GL	5	60 x 60 x 25	24.3	Ball	450	2.25	UL/CUL/TUV/CE	36	12" 2	6.95	6.25	5.59	4.95
2233211	Adda	AD0805HS-D71	5	80 x 80 x 15	29.9	Sleeve	430	2.15	UL/CUL/TUV/CE	33.4	12"	8.95	7.95	6.95	6.25
2258671	Adda	AD0805HB-D71	5	80 x 80 x 15	29.9	Ball	430	2.1	UL/CUL/TUV/CE	33	12"	10.95	9.95	8.95	7.95
2227170	Mechanics	E9225M05BS	5	92 x 92 x 25	44	Ball	50	0.56	UL/CUL/TUV	32	13" 2	9.95	8.95	7.95	6.95
2095269	Adda	AD2012LX-G70(X)	12	20 x 20 x 10	0.6	Hypro	60	0.84	UL/CUL/CE	20	5.5"	7.95	6.95	5.95	4.95
2227655	Adda	AD0212MX-K50	12	25 x 25 x 6	2.4	Hypro	60	0.72	UL/CUL/TUV/CE	29	5.5"	11.95	10.95	9.95	8.95

† 3 leads; speed sensor (FG) 2 3 leads; alarm (RD) (All fans operate to their specs with or without the additional optional wire functions) § DC chip cooler † Blower


For case mounting screws, P/Ns 2188481 or 2188490, page 78

DC Brushless Tubeaxial Fans



Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers (Continued)

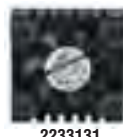

2233131

2205384

2233166

* 12V Web Code: LBZ

NEW MARKED IN PINK

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2232198	Adda	AD0212MX-K53	12	25 x 25 x 6	2.4	Hypro	90	1.08	CE	29	5.5" ¹	\$12.95	\$11.49	\$9.95	\$8.95
2232180	Adda	AD0212MB-K50	12	25 x 25 x 6	2.4	Ball	70	0.84	UL/CUL/TUV/CE	26.9	5.5"	14.95	13.49	11.95	10.95
1951641	Adda	AD0212MB-G50GL	12	25 x 25 x 10	2.0	Ball	80	0.4	UL/CUL/TUV/CE	23.1	5" w/ conn	9.95	8.95	7.95	6.95
2179454	Jamicon	KF0210S1H	12	25 x 25 x 10	2.57	Sleeve	120	1.44	UL/TUV/CE	27.4	12"	3.95	3.49	2.95	2.49
2224198	Adda	AD0312LX-K73	12	30 x 30 x 6	2.5	Hypro	60	0.72	UL/CUL/TUV/CE	20	12" ¹	11.95	10.95	9.95	8.95
2133860	Adda	AD0312MB-G50	12	30 x 30 x 10	3.8	Ball	120	0.6	CE	28	5.5"	12.95	11.49	9.95	8.95
2131901	Adda	AD0312HB-G53	12	30 x 30 x 10	4.5	Ball	130	0.55	UL/CUL/TUV/CE	31	12" ¹	14.95	13.49	11.95	10.95
2233131	Adda	AP3512LB-J70(S)§	12	35 x 35 x 8	2.5	Ball	60	0.72	UL/CUL/TUV/CE	20	5"	9.95	8.95	7.95	6.95
212741	Sunon	KDE1235PFB2-8	12	35 x 35 x 10	4.5	Ball	60	0.8	UL/CUL/TUV/CE/VDE	21	3" w/ conn	6.95	6.25	5.59	4.95
2179411	Sunon	MF3510V1-10000-A99	12	35 x 35 x 10	7.2	Vapo	60	0.72	UL/CUR/TUV/CE	28	5.5"	11.95	10.95	9.95	8.95
2186224	Delta	FFB03812VHN-F00	12	38 x 38 x 28	20.2	Ball	650	7.8	UL/CSA/VDE/CE	58.5	13" ¹	5.95	4.95	4.49	3.95
2215435	Adda	AD0412HX-K96 (X)	12	40 x 40 x 6	5.4	Hypro	140	0.96	UL/CUL/TUV/CE	30.5	5.5" ¹	8.95	7.95	6.95	6.25
2132162	Adda	AD0412LS-G70(T)	12	40 x 40 x 10	4.7	Sleeve	70	0.84	UL/CUL/TUV/CE	14	12"	4.95	4.49	3.95	3.49
2095314	Adda	AD0412LX-G70	12	40 x 40 x 10	4.7	Hypro	70	0.84	UL/CUL/TUV	14	11"	5.95	5.39	4.79	4.39
2224180	Adda	AD0412LX-G76	12	40 x 40 x 10	4.7	Hypro	70	0.84	UL/CUL/TUV	14	12" ¹	5.95	5.49	4.95	4.49
2132154	Adda	AP0412MX-G70§	12	40 x 40 x 10	4.7	Hypro	80	0.96	CE	28	5.5"	9.95	8.95	7.95	6.95
2232307	Adda	AD0412LB-G71	12	40 x 40 x 10	5.0	Ball	60	0.72	UL/CUL/TUV/CE	21	12"	6.95	6.25	5.59	4.95
2167630	Sunon	HA4010V4-0000-999	12	40 x 40 x 10	5.3	Vapo	65	0.8	UL/TUV/CE	18.2	12"	6.95	6.25	5.59	4.95
2231777	Adda	AD0412HB-G70	12	40 x 40 x 10	6.7	Ball	100	1.2	UL/CE	25	6" w/ conn	8.95	7.95	6.95	6.25
2205384	Adda	AD0412HB-G70(T)	12	40 x 40 x 10	6.7	Ball	100	1.2	UL/CUL/TUV/CE	25	12"	9.95	8.95	7.95	6.95
311968	Adda	AD0412HB-G73	12	40 x 40 x 10	6.7	Ball	90	1.08	UL/CUL/TUV/CE	26	12" ¹	9.98	8.95	7.95	6.95
2167234	Sunon	ME4010V1-0000-A99	12	40 x 40 x 10	8.0	Vapo	90	1.08	UL/CUL/TUV	32	12"	9.95	8.95	7.95	6.95
1708473	Sunon	KDE1204PFVX11.MS.A	12	40 x 40 x 10	9.5	Vapo	150	1.8	UL/CUL/TUV	39	12"	8.95	7.95	6.95	6.25
2231793	Adda	AD0412LB-D50	12	40 x 40 x 15	6.8	Ball	80	0.96	UL/TUV/CE	30.3	11"	5.95	4.95	4.49	3.95
2231769	Adda	AD0412HB-D50	12	40 x 40 x 15	9.2	Ball	120	1.4	UL/CUL/CE	39.3	12"	5.95	4.95	4.49	3.95
2228181	Delta	AFB0412LD	12	40 x 40 x 20	3.88	Ball	50	0.6	UL/CE/CSA/TUV	25	13"	3.95	3.59	3.29	2.95
2133835	Adda	AD0412DX-C50	12	40 x 40 x 20	4.9	Hypro	50	0.6	UL/CUL/TUV/CE	10	11"	4.95	4.49	3.95	3.59
2234863	Sunon	MB4020V3-0000-G99	12	40 x 40 x 20	6.3	Vapo	40	0.48	UL/CUL/TUV	18	6" w/ conn ¹	7.95	6.95	6.25	5.95
195899	Sunon	KDE1204PKS2	12	40 x 40 x 20	6.5	Sleeve	70	0.9	UL/CSA/TUV	25.5	12"	4.95	4.49	3.95	3.59
2134176	Adda	AD0412LB-C50	12	40 x 40 x 20	7.0	Ball	70	0.84	UL/CUL/TUV/CE	25	11"	5.95	5.39	4.79	4.29
2151021	Sanyo Denki	109P0412H601	12	40 x 40 x 20	8.0	Ball	110	1.3	UL/CSA	33	7" w/ conn ¹	4.95	4.49	3.95	3.59
2233166	Adda	AD0412MB-C71GP	12	40 x 40 x 20	8.0	Ball	80	0.96	UL/CUL/TUV/CE	28.5	11"	7.95	6.95	6.25	5.59
2133907	Adda	AD0412MB-C50	12	40 x 40 x 20	8.5	Ball	80	0.96	UL/CUL/TUV/CE	28.5	11"	4.95	4.49	3.95	3.49
2220218	Adda	AD0412HB-C50(G)	12	40 x 40 x 20	8.8	Ball	100	1.2	UL/CUL/TUV/CE	36	10" w/conn	6.95	6.25	5.59	4.95
249375	Adda	AD0412HB-C71GD	12	40 x 40 x 20	8.97	Ball	160	1.1	UL/CUL/TUV/CE	39.3	12"	6.95	6.25	5.59	4.95
136178	Adda	AD0412HB-C56	12	40 x 40 x 20	9.0	Ball	100	1.2	UL/CUL/TUV/CE	32	12" ¹	7.95	6.95	6.25	5.59
2230969	Delta	EFB0412HHD	12	40 x 40 x 20	9.5	Ball	100	1.2	UL/CUL/CSA/TUV	30.5	12"	6.95	6.25	5.59	4.95
2231785	Adda	AD0412HX-C56	12	40 x 40 x 20	9.6	Hypro	110	1.3	UL/TUV/CE	31	11" ¹	7.95	6.95	5.95	5.49
1928118	Adda	AD0412HB-C50	12	40 x 40 x 20	10.5	Ball	110	1.2	UL/CUL/TUV/CE	31.9	12"	8.95	7.95	6.95	6.25
2135380	Adda	AD0412UB-C72GP(P)	12	40 x 40 x 20	10.6	Ball	200	2.4	UL/CUL/TUV/CE	34	12" ²	9.95	8.95	7.95	6.95
2233924	Sunon	MF4020VX-10000-G99	12	40 x 40 x 20	10.8	Vapo	80	1.06	UL/TUV/CUL	27.5	12" ¹	10.95	9.95	8.95	7.95
2227330	Elina	HDF4020L-12HNB-4	12	40 x 40 x 20	10.9	Ball	165	1.98	UL/CUL/TUV	34	18" w/ conn	7.95	6.95	5.95	4.95
2186232	Delta	FFB0412HM-5T20	12	40 x 40 x 28	10.6	Ball	110	0.84	UL/CSA/TUV	36	3.5" w/ conn ¹	3.95	3.49	2.95	2.49
2082089	Sanyo Denki	109P0412H302	12	40 x 40 x 28	11.3	Ball	195	2.3	UL/CSA/TUV	37	3.75"	5.95	4.95	4.49	3.95
2235356	Adda	AD0412HB-B32-380MM	12	40 x 40 x 28	12.1	Ball	200	2.6	UL/CUL/TUV/CE	38.8	14" w/ conn ²	6.95	6.25	5.59	4.95
2231751	Adda	AD0412HB-B32	12	40 x 40 x 28	12.1	Ball	220	2.6	UL/CUL	38.8	11" ²	7.95	6.95	6.25	5.59
2233158	Adda	AD0412HB-B33	12	40 x 40 x 28	12.13	Ball	220	2.64	UL/CUL/TUV/CE	38.8	11" ¹	12.95	11.49	9.95	8.95
209518	Adda	AD0412UB-B33	12	40 x 40 x 28	16.6	Ball	200	2.4	UL/CUL/TUV/CE	32.8	12" ¹	12.95	11.49	10.49	9.49
2235348	Adda	AD04012UB285300(LAP)	12	40 x 40 x 28	20.7	Ball	60	7.2	UL/CUL/TUV/CE	50.8	12" w/ conn ³	13.95	12.49	10.95	9.95
2095500	Adda	AD0412VB-B53GP	12	40 x 40 x 28	21	Ball	800	9.6	UL/CUL/TUV/CE	53	12" ¹	14.95	13.49	11.95	10.95
2228800	Delta	GFB0412EMS-D	12	40 x 40 x 56	31.2	Ball	135	16.2	UL/CUL/VDE	64	3" w/ conn	11.95	10.95	9.95	8.95
2233123	Adda	AP4512HX-G90§	12	45 x 45 x 10	6.0	Ball	50	0.6	UL/CUL/CE	30	5"	14.95	13.49	11.95	10.95
2095322	Adda	AD4512MX-G76	12	45 x 45 x 10	6.7	Hypro	70	0.84	UL/CUL/TUV/CE	22	11" ¹	9.95	8.95	7.95	6.95
2232219	Adda	AD4512HX-G70	12	45 x 45 x 10	9.1	Hypro	90	1.08	UL/CUL/TUV/CE	27.4	11"	12.95	11.49	9.95	8.95

¹ 3 leads; speed sensor (FG) ² 3 leads; alarm (RD) ³ 4 leads; PWM & tach (FG) & alarm (RD) (All fans operate to their specs with or without the additional optional wire functions) § DC chip cooler
For case mounting screws, P/Ns 2188481 or 2188490, page 78

*For additional products, availability and specifications visit [Jameco.com](http://www.Jameco.com) and enter the Web Code in the product search box



DC Brushless Tubeaxial Fans

3 LEVELS OF SAVINGS		
NAME BRANDS	HOUSE BRANDS	SPECIAL BUY

Call for additional OEM PRICING – we carry major manufacturers.


NEW
MARKED IN PINK

DC Brushless Tubeaxial Fans & Blowers (Continued)



* 12V Web Code: LBZ

* 24V Web Code: QEF

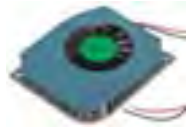

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Fans

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2131936	Adda	AD0512LB-G70(T)	12	50 x 50 x 10	8.0	Ball	80	0.96	UL/CUL/TUV/CE	20	12"	\$6.95	\$6.25	\$5.59	\$4.95
2100419	Adda	AD0512HB-G70LF	12	50 x 50 x 10	11.8	Ball	150	1.8	UL/CUL/TUV/CE	26	11"	6.95	6.25	5.95	5.49
2202992	Sunon	ME50101V1-000U-A99	12	50 x 50 x 10	13.8	Vapo	110	1.3	UL/CUL/TUV	31	12"	7.95	6.95	6.25	5.95
2099534	Adda	AD0512HB-D70	12	50 x 50 x 15	14.2	Ball	100	1.3	UL/CUL/TUV/CE	29	5.5"	6.95	6.25	5.59	4.95
2203493	Adda	AD5012HB-D76	12	50 x 50 x 15	14.2	Ball	110	1.32	UL/CUL/TUV/CE	30.2	5" 1	9.95	8.95	7.95	6.95
2258451	Sunon	KDE1205PHV1	12	50 x 50 x 15	17	Vapo	87	1.0	UL/CUL/TUV/CE	33	12" 1	6.95	6.25	5.59	4.95
2203004	Sunon	MB50151V1-000U-A99	12	50 x 50 x 15	17	Vapo	87	1.05	UL/CE/TUV/CUL	33	12"	8.95	7.95	6.95	6.25
2133843	Adda	AB5012MB-C03†	12	51 x 51 x 20	4.6	Ball	120	1.44	UL/CUL/TUV/CE	31	12" 1	13.95	12.49	10.95	9.95
2220082	Adda	AP5212MX-E70(8)§	12	52 x 52 x 12	10.5	Hypro	80	0.84	UL/CUL/TUV/CE	24	5.5"	17.95	15.95	14.49	12.95
2228261	NMB	2106KL-04W-B39	12	52 x 52 x 15	9.9	Ball	70	0.84	UL/CSA/CE/TUV	21	12" 1	6.95	6.25	5.59	4.95
139601	Adda	AD0512HS-D71	12	52 x 52 x 15	12	Sleeve	100	1.2	UL/CSA/CE	29	5"	5.95	5.39	4.79	4.29
2233473	Adda	AD0512HB-D71	12	52 x 52 x 15	12	Ball	100	1.2	UL/CUL/TUV/CE	46.2	5"	9.95	8.95	7.95	6.95
2121332	Adda	AD0612LX-G76(T)	12	60 x 60 x 10	10	Hypro	110	1.32	UL/CUL/TUV/CE	26	11" 1	6.95	6.25	5.59	4.95
2233609	Adda	AD0612LS-G70(T)	12	60 x 60 x 10	11.7	Sleeve	110	1.32	UL/CUL/TUV/CE	23	12"	8.95	7.95	6.95	6.25
144160	Adda	AD0612LB-G76	12	60 x 60 x 10	11.7	Ball	110	1.32	UL/CUL/TUV/CE	23	12" 1	11.95	10.95	9.95	8.95
2205499	Adda	AD0612HB-G90	12	60 x 60 x 10	14.5	Ball	140	1.6	UL/TUV/CE	32.8	4.5" w/ conn	4.95	4.49	3.95	3.49
2095357	Adda	AD0612HB-G70	12	60 x 60 x 10	14.5	Ball	150	1.8	UL/CUL/TUV/CE	32	11"	7.95	6.95	6.25	5.95
1928126	Adda	AD0612HX-G76(T)	12	60 x 60 x 10	14.5	Hypro	150	1.8	UL/CUL/TUV/CE	32	12" 1	11.95	10.95	9.95	8.95
1946025	Evercool	EC6010M12CA	12	60 x 60 x 10	15.5	Ball	160	1.9	UL/CE/TUV	30	9" 1	8.95	7.95	6.95	6.25
2217959	Thermactive	RDM6010B1	12	60 x 60 x 10	15.9	Ball	170	2.04	UL/CUL/TUV/CE	31	12"	6.95	5.95	5.49	4.49
2134205	Adda	AD0612HB-GA6	12	60 x 60 x 10	21	Ball	250	3.0	UL/CUL/TUV/CE	35.8	11" 1	9.95	8.95	7.95	6.95
2121439	Adda	AD0612DX-D70GL(T)	12	60 x 60 x 15	10.8	Hypro	60	0.72	UL/CUL/TUV/CE	21.3	5.5"	6.95	6.25	5.59	4.95
2210909	Delta	AFB0612LB-TXNS	12	60 x 60 x 15	11.55	Ball	100	0.84	UL/CSA/CE	24	6" w/ conn 2	5.95	4.95	4.49	3.95
2233174	Adda	AD0612LB-D9B	12	60 x 60 x 15	12.62	Ball	90	1.08	UL/CUL/TUV/CE	25.3	5" 4	14.95	13.49	11.95	10.95
1928046	Adda	AD0612MS-D70GL	12	60 x 60 x 15	14	Sleeve	110	1.32	UL/CUL/TUV/CE	29	5"	5.95	5.39	4.79	4.29
2231814	Adda	AD0612MB-D71GL	12	60 x 60 x 15	14.3	Ball	80	0.9	UL/TUV/CE	28.8	5"	5.95	4.95	4.49	3.95
2167568	Sunon	ME60151V1-0000-A99	12	60 x 60 x 15	25.2	Vapo	160	1.92	UL/TUV/CE	36.2	12"	6.95	5.95	5.49	4.95
144161	Adda	AD0612LB-C70GL	12	60 x 60 x 20	12.6	Ball	80	1.0	UL/CSA/TUV	22.7	12"	5.95	4.95	4.49	3.95
2133982	Adda	AD0612LX-C70GL(T)	12	60 x 60 x 20	13.3	Hypro	80	0.96	UL/CUL/TUV/CE	21.6	12"	6.95	6.25	5.59	4.95
2134011	Adda	AD0612MX-C70GL	12	60 x 60 x 20	14.5	Hypro	130	1.56	UL/CUL/TUV/CE	25.7	12"	4.95	4.49	3.95	3.49
2203389	Adda	AD0612MB-C73GL	12	60 x 60 x 20	14.75	Ball	60	0.72	UL/CUL/TUV/CE	25.2	12" 1	6.95	6.25	5.59	4.95
2233051	Adda	AQ0612LB-A70GL *	12	60 x 60 x 25	13.2	Ball	70	0.84	UL/CUL/TUV/CE	18.1	12"	10.95	9.95	8.95	7.95
2227276	YS Tech	NYW060250125BL	12	60 x 60 x 25	15.8	Ball	80	0.96	UL/CUL/TUV	23.5	7" w/ conn	4.95	4.49	3.95	3.59
2162847	NMB	2410ML-04W-B30	12	60 x 60 x 25	19	Ball	117	1.4	UL/CSA/VDE/CE	29	12"	8.95	7.95	6.95	6.25
2205149	Sunon	MB60251V2-000U-G99	12	60 x 60 x 25	19.3	Vapo	74	0.8	UL/CUL/CE/TUV	29	12" 1	9.95	8.95	7.95	6.95
2217941	Thermactive	RDH6025B-FG	12	60 x 60 x 25	20.3	Ball	140	1.68	UL/CUL/TUV/CE	29	12" 1	6.95	6.25	5.95	5.49
2230766	Thermactive	RDH6025B	12	60 x 60 x 25	20.3	Ball	140	1.68	UL/CUL/TUV/CE	29	12" 4	7.95	6.95	5.95	5.49
2228818	Mitsubishi	MMF-06D12DL	12	60 x 60 x 25	21.6	Ball	70	0.84	UL/CSA	23	8" w/ conn	6.95	6.25	5.59	4.95
2233078	Adda	AD0612HB-A70GL4	12	60 x 60 x 25	24.8	Ball	230	2.76	UL/CUL/TUV/CE	35.2	3" w/ conn	5.95	5.39	4.79	4.29
2150766	Adda	AD0612HB-A72GL	12	60 x 60 x 25	24.8	Ball	230	2.7	UL/CUL/TUV/CE	35.2	12" 2	7.95	6.95	5.95	4.95
2227719	Adda	AD0612HB-A70GL	12	60 x 60 x 25	24.8	Ball	230	2.76	UL/CUL/TUV/CE	35.2	12"	9.95	8.95	7.95	6.95
2233115	Adda	AQ0612HB-A70GL *	12	60 x 60 x 25	24.8	Ball	160	1.92	CE	35.2	12"	10.95	9.95	8.95	7.95
2133974	Adda	AD0612XB-A72GL(P)	12	60 x 60 x 25	31.7	Ball	280	3.6	UL/CUL/TUV/CE	44	12" 2	11.95	10.95	9.95	8.95
2158311	Delta	AFB0612EH-BF00	12	60 x 60 x 25	38.35	Ball	480	5.76	UL/CSA/CE	46.5	8" w/ conn 1	11.95	10.95	9.95	8.95
2233393	Adda	AB6812MX-GC0†	12	68 x 68 x 10	3.4	Hypro	90	1.08	CE	33.6	5"	9.95	8.95	7.95	6.95
2235276	Adda	AD0712LX-DA6	12	70 x 70 x 15	29.2	Hypro	140	1.68	UL/CUL/TUV/CE	34.5	12" 1	6.95	6.25	5.59	4.95
2232930	Adda	AD0712HS-D73	12	70 x 70 x 15	32.1	Sleeve	190	2.28	UL/CUL/TUV/CE	35.5	12" 1	6.95	6.25	5.49	4.95
2233203	Adda	AD0712HS-D71	12	70 x 70 x 15	34	Sleeve	270	3.24	UL/CUL/TUV/CE	39.4	5"	7.95	6.95	6.25	5.59
2125561	AVC	DE07015R12U	12	70 x 70 x 15	43	Hydraulic	700	8.4	UL/CE/TUV	46	8" w/ conn	5.95	4.95	3.95	2.95
2227647	JMC	7025-12LS	12	70 x 70 x 25	22	Sleeve	100	1.2	UL/CUL/TUV	24.3	6" w/ conn	6.95	6.25	5.59	4.95

1 3 leads; speed sensor (FG) 2 3 leads; alarm (RD) 4 4 leads with speed sensor, PWM control

(All fans operate to their specs with or without the additional optional wire functions)

§ DC chip cooler * Waterproof and dust proof † Blower

For case mounting screws, P/Ns 2188481 or 2188490, page 78

DC Brushless Tubeaxial Fans



Call for additional OEM PRICING – we carry major manufacturers.

NEW
MARKED IN PINK

DC Brushless Tubeaxial Fans & Blowers (Continued)



2099446

2134213

2228172

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2099446	Adda	AD7512LB (2A)†	12	75 x 75 x 30	6.9	Ball	110	1.32	UL/CUL/TUV/CE	29	15" w/ conn ²	\$6.95	\$6.25	\$5.59	\$4.95
2233035	Adda	AD7512MS†	12	75 x 75 x 30	7.78	Sleeve	150	1.8	UL/CUL/CE	34.9	15"	6.95	6.25	5.59	4.95
2233140	Adda	AD7512HX(3)†	12	75 x 75 x 30	10.3	Hypro	240	2.88	UL/CUL/CE	38.5	12" ¹	7.95	6.95	6.25	5.59
2192561	Adda	AD0812LB-D70(T)	12	80 x 80 x 15	20	Ball	90	1.08	UL/CSA/TUV/CE	19.6	12"	7.95	6.95	5.95	5.49
2232948	Adda	AD0812MX-D71	12	80 x 80 x 15	22.4	Hypro	150	1.8	UL/CUL/TUV/CE	26	12"	8.95	7.95	6.95	6.25
109081	Adda	AD0812HB-D73(N)	12	80 x 80 x 15	29.9	Ball	190	2.16	UL/CUL/TUV/CE	33.4	12" ¹	9.95	8.95	7.95	6.95
2132007	Adda	AD0812HS-D70-LF	12	80 x 80 x 15	38.6	Sleeve	250	3.0	UL/CSA/TUV/CE	33	12"	5.95	5.49	4.95	4.49
2095365	Adda	AD0812XX-D71	12	80 x 80 x 15	39.4	Hypro	350	4.2	UL/CSA/TUV/CE	42	11"	10.95	9.95	8.95	7.95
2230985	Delta	EEF0812DF	12	80 x 80 x 15	49	Ball	330	3.9	UL/CSA/TUV/CE	45	12" ⁴	9.95	8.95	7.95	6.95
141921	Adda	AD0812HB-C70	12	80 x 80 x 20	27.3	Ball	240	2.9	UL/CSA/CE	34	12"	10.95	9.95	8.95	7.95
2232112	Adda	AD0812UB-C7B	12	80 x 80 x 20	32.5	Ball	140	1.68	UL/CUL/TUV/CE	37.5	12" ⁴	12.95	11.49	9.95	8.95
2228121	NMB	3110GL-B4W-B14	12	80 x 80 x 25	24.7	Ball	100	1.2	UL/CSA/VDE/CE	22	10"	6.95	6.25	5.59	4.95
2228148	Mechatronics	F8025S12B	12	80 x 80 x 25	26	Ball	75	1.2	UL/CSA/TUV	22	10"	6.95	6.25	5.59	4.95
2078194	Adda	AD0812UB-A71GP	12	80 x 80 x 25	26.2	Ball	450	5.4	UL/CUL/TUV/CE	41	12"	8.95	7.95	6.95	5.95
2228113	Nidec	D08A-12TL	12	80 x 80 x 25	27.7	Ball	120	0.7	UL	19	8" w/ conn	6.95	6.25	5.59	4.95
123530	Adda	AD0812MS-A70GL	12	80 x 80 x 25	32	Sleeve	150	1.8	UL/CSA/TUV	28.3	12"	6.95	5.95	4.95	4.59
2234450	Sunon	EE80251B3-0000-G99	12	80 x 80 x 25	33	2 Ball	88	1.1	UL/CUL/TUV/CE	28	12" ¹	8.95	7.95	6.95	6.25
234895	Adda	AD0812HB-A73GL	12	80 x 80 x 25	38.6	Ball	250	3.0	UL/CUL/TUV/CE	34.4	12" ¹	9.95	8.95	7.95	6.95
2135697	Panaflo	FBM-08A12H	12	80 x 80 x 25	39.6	Sleeve	220	2.1	UL/CSA	32	12" w/ conn	3.95	3.49	2.95	2.49
2210984	Sunon	EE80251B1-0000-A99	12	80 x 80 x 25	41	Ball	145	1.7	UL/CUL/TUV/CE	33	12"	7.95	7.49	6.95	6.25
2233220	Adda	AD0812UB-A70GL	12	80 x 80 x 25	48.8	Ball	450	5.4	UL/CUL/TUV/CE	41	12"	9.95	8.95	7.95	6.95
2233238	Adda	AD0812UX-A73GL	12	80 x 80 x 25	48.8	Hypro	450	5.4	UL/CUL/TUV/CE	41	12" ¹	10.95	9.95	8.95	7.95
2081078	Jamicon	JF0825B1UR	12	80 x 80 x 25	52	Dual Ball	370	4.4	UL/CUL/TUV/CE	40	12"	9.95	8.95	7.95	7.49
2210933	Sunon	PF80251V1-0000-A99	12	80 x 80 x 25	60	Vapo	341	4.1	UL/CUL/TUV	46.5	12"	10.95	9.95	8.95	7.95
2209001	Sanyo Denki	9GV0812P4K03	12	80 x 80 x 25	74.8	Ball	870	10.4	UL/CUL/TUV	52	12" ⁴	7.95	6.95	6.25	5.95
2228164	EBM Papst	8312	12	80 x 80 x 32	31.8	Ball	220	2.2	UL/CSA/TUV	36	12"	12.95	11.49	9.95	8.95
107406	EBM Papst	8312GHL	12	80 x 80 x 32	39.4	Sleeve	330	4.0	UL/CE/CSA/VDE	43	12"	6.95	5.95	4.95	4.49
2134213	Adda	AD0812MB-Y51	12	80 x 80 x 32	44.6	Ball	160	1.92	UL/CUL/TUV/CE	37	11"	14.95	13.49	11.95	10.95
2230758	Thermactive	RGM8038B1	12	80 x 80 x 38	83.4	Ball	850	11.7	UL/CUL/TUV/CE	57	12" ⁴	10.95	9.95	8.95	7.95
1928100	Adda	AD0812XB-F71DS	12	80 x 80 x 38	99	Ball	1500	18.0	UL/CSA/TUV/CE	57	12"	9.95	8.95	7.95	6.95
1928097	Adda	AD0912LX-A76GL(T)	12	92 x 92 x 25	32.8	Hypro	130	1.56	UL/CUL/TUV/CE	23.5	12" ¹	9.95	8.95	7.95	6.95
1952783	Nidec	TA350DC-M34138-34	12	92 x 92 x 25	35	Ball	160	1.92	UL/CSA	26.4	10" w/ conn ³	3.95	3.49	2.95	2.49
2232981	Adda	AD0912LB-A72GL	12	92 x 92 x 25	37.7	Ball	120	1.44	UL/CUL/TUV/CE	29.8	12" ²	9.95	8.95	7.95	6.95
2233094	Adda	AQ0912LB-A70GL *	12	92 x 92 x 25	40.7	Ball	100	1.2	UL/CUL/TUV/CE	29.2	12"	14.95	13.49	11.95	10.95
1928003	Adda	AD0912MS-A70GL	12	92 x 92 x 25	43	Sleeve	170	2.04	UL/CUL/TUV/CE	31	12"	13.95	12.49	10.95	9.95
154641	Nidec	TA350DC-M33422-16	12	92 x 92 x 25	48	Ball	290	3.5	UL/CSA	35	12"	9.95	8.95	7.95	6.95
2228236	Sunon	1209PTB1-6	12	92 x 92 x 25	49	Ball	170	2.8	UL/CUL/CE/TUV	35	12"	9.95	8.95	7.95	6.95
2193942	Orion	DPF92B012	12	92 x 92 x 25	50	Ball	290	3.48	UL/CUL	33	12"	7.95	6.95	6.25	5.59
1928089	Adda	AD0912HS-A76GL(T)	12	92 x 92 x 25	50	Sleeve	250	3.0	UL/CUL/TUV/CE	33.7	12" ¹	9.95	8.95	7.95	6.95
2228201	Mechatronics	E9225H12B2	12	92 x 92 x 25	51	Ball	360	4.3	UL/CUL/TUV	36	14"	9.95	8.95	7.95	6.95
1928302	Adda	AD0912HS-A70GL	12	92 x 92 x 25	52.5	Sleeve	250	3.0	UL/CUL/TUV/CE	35	12"	9.95	8.95	7.95	6.95
2099796	Adda	AD0912HB-A73GL(N)	12	92 x 92 x 25	52.5	Ball	250	3.0	UL/CUL/TUV/CE	35	12" ¹	9.95	8.95	7.95	6.95
2232972	Adda	AD0912UB-A72GL	12	92 x 92 x 25	57	Ball	390	4.68	UL/CUL/TUV/CE	39.4	12" ²	10.95	9.95	8.95	7.95
2134248	Adda	AD0912US-A70GL	12	92 x 92 x 25	60	Sleeve	390	4.68	UL/CUL/TUV/CE	39.4	12"	12.95	11.49	9.95	8.95
2234871	Sunon	PMD1209PTB3-A(2).F.GN	12	92 x 92 x 25	65	Ball	300	3.6	UL/CUL/TUV/CE	43	12" ¹	12.95	11.49	9.95	8.95
2172711	Mechatronics	MC9238X12B-FS	12	92 x 92 x 38	80.5	Ball	720	8.6	UL/CUL/TUV	47.5	12"	6.95	5.95	5.49	4.95
174140	Common Wealth	FP108M33	12	120 x 120 x 25	62	Sleeve	140	1.7	UL/CSA/TUV/CE	25	12"	8.95	7.95	7.25	6.49
2228156	NMB	4710KL-04W-B19	12	120 x 120 x 25	63.5	Ball	120	1.44	UL/CE/CSA/TUV	27	8" ²	9.95	8.95	7.95	6.95
2233019	Adda	AD1212LX-A71GL	12	120 x 120 x 25	72	Hypro	240	2.88	UL/CUL/TUV/CE	34.4	12"	9.95	8.95	7.95	6.95
2233246	Adda	AD1212LS-A71GL	12	120 x 120 x 25	72	Sleeve	240	2.88	UL/CUL/TUV/CE	34.4	12"	10.95	9.95	8.95	7.95
2228172	AVC	F1225B12L	12	120 x 120 x 25	75.2	Ball	270	3.24	UL/CSA/CUL	39.5	8" w/conn ²	9.95	8.95	7.95	6.95
2134053	Adda	AD1212HB-A72GL(N)	12	120 x 120 x 25	85.2	Ball	370	4.44	UL/CUL/CE	39.1	12" ²	10.95	9.95	8.95	7.95
2134264	Adda	AD1212HX-A71GL(N)	12	120 x 120 x 25	85.2	Hypro	440	5.28	UL/CUL/TUV/CE	39.1	12"	12.95	11.49	10.95	9.95
1928011	Adda	AD2512MS-600MM†	12	120 x 120 x 32	23.7	Sleeve	600	7.2	TUV/CE	51.1	24"	8.95	7.95	6.95	6.25

¹ 3 leads; speed sensor (FG) ² 3 leads; alarm (RD) ³ 4 leads; PWM & tach (FG) & alarm (RD) ⁴ 4 leads; PWM & speed sensor (FG)

(All fans operate to their specs with or without the additional optional wire functions) * Waterproof and dust proof † Blower

For case mounting screws, P/Ns 2188481 or 2188490, page 78

*For additional products, availability and specifications visit [Jameco.com](http://www.Jameco.com) and enter the Web Code in the product search box

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **SPECIAL BUY**

Order by Phone at 1-800-831-4242 or Online at www.Jameco.com

DC Brushless Tubeaxial Fans

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **SPECIAL BUY**



Call for additional OEM PRICING – we carry major manufacturers.

NEW MARKED IN PINK

DC Brushless Tubeaxial Fans & Blowers (Continued)



2233060

2211012

1784644

*12V Web Code: LBZ

*24V Web Code: QEF

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2228130	Delta	WFB1212H-BF05	12	120 x 120 x 25	86.5	Ball	360	4.32	UL/CSA/TUV/CE	37.6	13" ¹	\$9.95	\$8.95	\$7.95	\$6.95
2227866	YSTech	FD121225MB	12	120 x 120 x 25	87.8	Ball	290	3.48	UL/CUL/TUV	40.5	12"	12.95	11.95	10.95	9.95
2233060	Adda	AQ1212HB-A71GL *	12	120 x 120 x 25	87.9	Ball	290	3.48	UL/CUL/TUV/CE	39.1	12"	14.95	13.49	11.95	10.95
2170927	Adda	AD1212US-A71GL-LF	12	120 x 120 x 25	98.6	Sleeve	500	6.0	UL/CUL/TUV/CE	43.3	11"	8.95	7.95	7.25	6.49
2235321	Adda	AS12012LB25A100	12	120 x 120 x 25	126	Ball	660	7.92	UL/CUL/TUV/CE	51	12"	10.95	9.95	8.95	7.95
2203346	Adda	AB1212MB-Y01†	12	120 x 120 x 32	28	Sleeve	560	100	UL/CUL/TUV/CE	49	12"	9.95	8.95	7.95	6.95
1928020	Adda	AD1212MB-Y51	12	120 x 120 x 32	99	Ball	260	3.1	UL/CUL/TUV/CE	41	11"	10.95	9.95	8.95	7.95
2233254	Adda	AD1212UB-Y51	12	120 x 120 x 32	130	Ball	580	6.96	UL/CUL/TUV/CE	48.4	12"	19.95	17.95	15.95	13.95
2211012	EBM Papst	4112GX	12	120 x 120 x 38	94	Sleeve	290	3.5	UL/CSA/CE	44	Terminals	9.95	8.95	7.95	6.95
2231697	Nidec	TA450DC-A31276-10A	12	120 x 120 x 38	104	Ball	440	5.2	UL/CUL/TUV/CE	52	Terminals	11.95	10.95	9.95	8.95
2173079	Sunon	EEC0381B2-0000-A99	12	120 x 120 x 38	116	Ball	425	5.1	UL/CUL/TUV/CE	44	12"	14.95	13.95	12.95	11.95
2231478	Adda	AD1212UB-F52	12	120 x 120 x 38	120	Ball	620	7.4	UL/CUL/TUV/CE	48	11" ²	12.95	11.95	10.95	9.95
2203426	Adda	AD1312UB-F51(CU)	12	127 x 127 x 38	193	Ball	1220	14.6	UL/CUL/CE	56	12"	9.95	8.95	7.95	6.95
2228295	Sanyo	109E1712K502	12	172 x 51	300	Ball	2900	34.8	CSA/UL/TUV	55	12"	39.95	35.95	32.95	29.95
2167605	Adda	AD0424HB-G70-LF	24	40 x 40 x 10	6.2	Ball	90	2.16	UL/CUL/TUV/CE	26	12"	9.95	8.95	7.95	6.95
2133931	Adda	AD0424HB-G73	24	40 x 40 x 10	6.7	Ball	90	2.16	UL/CUL/TUV/CE	25	12" ¹	10.95	9.95	8.95	7.95
2231806	Adda	AD0424LB-C50	24	40 x 40 x 20	7.0	Ball	60	1.4	UL/TUV/CE	25	12"	7.95	6.95	6.25	5.95
2158514	Sunon	MB40202V2-0000-A99	24	40 x 40 x 20	7.7	Vapo	33	2.16	UL/CUL/TUV/CE	21	12"	9.95	8.95	7.95	6.95
2121421	Adda	AD0424MS-C50(T1)	24	40 x 40 x 20	7.7	Sleeve	60	1.4	UL/CUL/TUV/CE	33	12"	9.95	8.95	7.95	6.95
2133940	Adda	AD0424UB-C56	24	40 x 40 x 20	9.6	Ball	90	2.16	CE	37	11" ²	7.95	6.95	5.95	4.95
2233027	Adda	AD4524HB-G70	24	45 x 45 x 10	7.0	Ball	90	2.16	UL/CUL/TUV/CE	27.4	12"	7.95	6.95	6.25	5.59
2235268	Adda	AD0524HS-G70	24	52 x 52 x 10	11.2	Sleeve	90	2.6	UL/CUL/TUV/CE	26	12"	12.95	11.49	9.95	8.95
2233377	Adda	AD0524HB-D71	24	52 x 52 x 15	12	Ball	80	1.92	CE	28.7	12"	12.95	11.49	9.95	8.95
1708422	Sunon	KDE2406PHS3	24	60 x 60 x 15	15	Sleeve	50	1.2	UL/CUL/TUV/CE	31	12"	7.95	6.95	6.25	5.59
2132111	Adda	AD0624HB-D71GL	24	60 x 60 x 15	15.8	Ball	90	2.16	UL/CUL/TUV/CE	33.3	5"	12.95	11.49	9.95	8.95
2188588	Sunon	ME60152V2-0000-A99	24	60 x 60 x 15	21.9	Vapo	85	2.04	UL/CUL/TUV	32.5	12"	8.95	7.95	6.95	6.25
2235313	Adda	AQ0624HB-70GL(T) *	24	60 x 60 x 15	24.5	Ball	120	2.88	UL/CUL/CE	35.2	12"	11.95	10.95	9.95	8.95
2134029	Adda	AD0624MB-C70GL	24	60 x 60 x 20	14.5	Ball	80	1.92	UL/CUL/CE	28	12"	8.95	7.95	6.95	6.25
2233191	Adda	AD0624HX-C70GL	24	60 x 60 x 20	16.3	Hypro	90	2.16	UL/CUL/TUV/CE	31	12"	9.95	8.95	7.95	6.95
2236391	Sunon	MB60202V1-0000-A99	24	60 x 60 x 20	23	Vapo	84	2.09	UL/CUL/TUV/CE	33.5	12" w/ conn	10.95	9.95	8.95	7.95
2232235	Panasonic	ASF62112104	24	60 x 60 x 25	15.5	Ball	70	1.44	CE	22.5	12"	7.95	6.95	6.25	5.59
2231831	Adda	AD0624LB-A70GL	24	60 x 60 x 25	17	Ball	80	1.9	UL/TUV/CE	18.1	12"	6.95	6.25	5.95	5.49
2121391	Adda	AD06024MB257100	24	60 x 60 x 25	17.3	Ball	0.5	1.2	UL/CUL/TUV/CE	27	12"	7.95	6.95	6.25	5.59
2224219	Adda	AD0624MS-A70GL	24	60 x 60 x 25	18	Sleeve	80	1.92	UL/CUL/TUV	27	12"	5.95	5.49	4.95	4.49
189861	Jamicon	JF0625B2M-005-065R	24	60 x 60 x 25	19	Ball	130	3.1	UL/TUV/CE	31.3	10"	8.95	7.95	6.95	6.25
2234492	Adda	AD06024HB257002	24	60 x 60 x 25	23.3	Ball	120	2.8	UL/CUL/TUV/CE	33	12"	9.95	8.95	7.95	6.95
2228244	Frilec	2406PTB1	24	60 x 60 x 25	23.5	Ball	60	1.4	UL/CSA/CE	33	12"	6.95	6.25	5.95	5.49
212628	Adda	AD0624UB-A71GL	24	60 x 60 x 25	26.9	Ball	160	3.84	UL/CUL/CE	37.9	13"	7.95	6.95	5.95	5.49
2132058	Adda	AQ0624UB-A71GT(T) *	24	60 x 60 x 25	28.3	Ball	140	3.36	UL/CUL/CE	40	12"	10.95	9.95	8.95	7.95
1784644	Adda	AD7524LB(3)†	24	75 x 75 x 30	6.9	Ball	120	2.88	UL/CUL/TUV/CE	29	12" ¹	6.95	6.25	5.59	4.95
2132066	Adda	AD7524HB†	24	75 x 75 x 30	9.1	Ball	160	3.84	UL/CUL/TUV/CE	38.5	12"	7.95	6.95	6.25	5.59
290029	Jamicon	JF0825B2M	24	80 x 80 x 25	32.52	Dual Ball	130	3.1	UL/CUL/TUV/CE	27.8	10"	9.95	8.95	7.95	6.95
136161	Jamicon	JF0825B2H	24	80 x 80 x 25	38.74	Dual Ball	150	3.6	UL/CSA/TUV	31	10"	9.95	8.95	7.95	6.95
2158565	Sunon	EE80252B1-0000-A99	24	80 x 80 x 25	41	Ball	75	1.8	UL/CUL/TUV/CE	33	12"	9.95	8.95	7.95	6.95
2134150	Adda	AQ0824UB-A71GL *	24	80 x 80 x 25	50	Ball	260	6.24	CE	41	12"	11.95	10.95	9.95	8.95
2234847	Adda	AD0824UB-A73GL(LN)	24	80 x 80 x 25	52.4	Ball	150	3.6	UL/CUL/TUV/CE	40.8	12" ¹	11.95	10.95	9.95	8.95
2211160	IMC Boxer	3113PLOS5WB30	24	80 x 80 x 32	28	Ball	130	3.1	UL/CUL	31	12"	5.95	5.49	4.95	4.49
2220171	Adda	AD0824UB-Y51	24	80 x 80 x 32	55.3	Ball	180	4.3	UL/CUL/TUV/CE	43.8	12"	9.95	8.95	7.95	6.95
2232964	Adda	AD0824UB-F73DS	24	80 x 80 x 38	88	Ball	440	10.6	UL/CUL/CE/TUV	55	12" ¹	8.95	7.95	6.95	6.25
1951051	Mechatronics	E9225L24B1-FS	24	92 x 92 x 25	35	Ball	85	2.04	UL/CUL	27	12" ¹	4.95	3.95	2.95	2.49
2203071	NMB	3610PLOS5W-B30	24	92 x 92 x 25	41	Ball	87	2.1	UL	33	11"	5.95	4.95	4.49	3.95
2232999	Adda	AD0924LB-A71GL	24	92 x 92 x 25	41.6	Ball	80	1.92	UL/CUL/CE/TUV	29.8	12"	9.95	8.95	7.95	6.95
2203080	Nidec	TA350DC-A31394-55	24	92 x 92 x 25	42	Ball	140	3.12	UL/CSA	40	3" w/ conn	2.95	2.75	2.49	2.25

¹ 3 leads; speed sensor (FG) ² 3 leads; alarm (RD) (All fans operate to their specs with or without the additional optional wire functions) * Waterproof & dust proof † Blower
 For case mounting screws, P/Ns 2188481 or 2188490, page 78

DC Brushless Tubeaxial Fans, Fan Guards & Filters

Call for additional OEM PRICING – we carry major manufacturers.

NEW
MARKED IN PINK

DC Brushless Tubeaxial Fans & Blowers (Continued)



2155065

2218046

2134352

*24V Web Code: QEF

*48V Web Code: MAJ

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2215751	NMB/IMC	3610PL-05W-B20-100	24	92 x 92 x 25	43	Ball	90	2.2	UL/CUL/TUV	39	12"	\$4.95	\$4.49	\$3.95	\$3.49
2233001	Adda	AD0924MX-A70GL	24	92 x 92 x 25	47.2	Hypro	120	2.9	UL/CUL/CE/TUV	32.7	12"	8.95	7.95	6.95	6.25
2132082	Adda	AD0924HX-A72GL	24	92 x 92 x 25	50	Hypro	150	3.6	UL/CUL/TUV/CE	33.7	12" 2	11.95	10.95	9.95	8.95
2155065	Delta	AFB0924H-R00	24	92 x 92 x 25	51.2	Ball	200	4.8	UL/CSA/CE	34	12" 2	8.95	7.95	6.95	5.95
2158303	Sunon	EE92252B1-0000-A99	24	92 x 92 x 25	51.5	Dual Ball	87	2.1	UL/TUV/CE	34	12"	10.95	9.95	8.95	7.95
1928329	Adda	AD0924XB-A71GL	24	92 x 92 x 25	67	Ball	250	6.0	UL/CUL/TUV/CE	42	12"	9.95	8.95	7.95	6.95
2230977	Delta	AFB0924VH	24	92 x 92 x 25	68	Ball	220	5.2	UL/CSA/VDE/CE	45	12"	9.95	8.95	7.95	6.95
2228199	Sunon	KDE2412PTB2-6A	24	120 x 120 x 25	80	Ball	230	5.5	UL/CUL/CE/TUV	36.5	12"	11.95	10.95	9.95	8.95
2121527	Adda	AD1224MB-A71GL	24	120 x 120 x 25	80.5	Ball	170	4.08	UL/CUL/TUV/CE	38	12"	11.95	10.95	9.95	8.95
2218046	Adda	AD1224UB-A70GL	24	120 x 120 x 25	99	Ball	250	6.0	UL/CUL/TUV/CE	43.3	11"	12.95	11.95	10.95	9.95
2197556	Coolmax	1225M24B-ZD1	24	120 x 120 x 25	103.8	Dual Ball	300	7.2	UL/TUV	42.5	6" w/ conn	8.95	7.95	6.95	6.25
2235330	Adda	AD12024LB25A100	24	120 x 120 x 25	126	Ball	280	6.72	UL/CUL/TUV/CE	51	12"	13.95	12.49	10.95	9.95
2233334	Adda	AD1224UB-Y51(IP52)	24	120 x 120 x 32	133	Ball	320	7.68	UL/CUL/TUV/CE	48.4	12"	14.95	13.49	11.95	10.95
2232104	Adda	AD1224UB-Y5B	24	120 x 120 x 32	133	Ball	320	7.68	UL/CUL/TUV/CE	48.4	12" 4	16.95	14.95	13.49	11.95
2134070	Adda	AD1224LB-F52(9TN)	24	120 x 120 x 38	72.3	Ball	140	3.36	UL/CUL/TUV/CE	32.9	12" 2	9.95	8.95	7.95	6.95
2211021	EBM Papst	4124GX	24	120 x 120 x 38	87	Sleeve	138	3.3	UL/CSA/CE	43	Terminals	9.95	8.95	7.95	6.95
694524	Jamicon	JF1238B2MR-R	24	120 x 120 x 38	101.3	Ball	230	5.28	UL/CSA/TUV/CE	39.1	9"	15.95	14.95	13.95	12.49
2134061	Adda	AD1224HS-F51	24	120 x 120 x 38	104.8	Sleeve	500	6.0	UL/CUL/TUV/CE	42.8	10"	10.95	9.95	8.95	7.95
2215478	Conair Rotron	MD24B2	24	120 x 120 x 38	110	Ball	250	6.0	UL/CSA/TUV/CE	50	Terminals	10.95	9.95	8.95	7.95
1809910	Sunon	KD2412PMSX-6A	24	120 x 120 x 38	119	Sleeve	300	7.2	UL/CUL/TUV/CE	45	12"	7.95	6.95	6.25	5.59
2236404	Sunon	MEC0382V1-0000-A99	24	120 x 120 x 38	138	Vapo	415	10	UL/CUL/TUV/CE	48	12"	12.95	11.95	10.95	9.95
2197433	EBM Pabst	4214NHHR	24	120 x 120 x 38	120.7	Ball	313	7.5	UL/CSA/CE	49	12"	9.95	8.95	7.95	6.95
2234919	Adda	AD1324VB-F51	24	127 x 127 x 38	242.1	Ball	1100	26.4	UL/CUL/TUV/CE	64.5	12"	34.95	31.49	27.95	24.95
2135371	Adda	AD0948MB-F91DS(M)	48	92 x 92 x 38	93.5	Dual Ball	160	7.6	CE	48.5	12"	9.95	8.95	7.95	6.95
2203400	Adda	AD1248HB-A71GL	48	120 x 120 x 25	87.8	Ball	100	4.8	UL/CUL/CE/TUV	39.1	12"	10.95	9.95	8.95	7.95
2132023	Adda	AD1248HB-Y51	48	120 x 120 x 32	108	Ball	150	720	UL/CUL/TUV/CE	43.3	10"	9.95	8.95	7.95	6.95
2134192	Adda	AD1248UB-Y51	48	120 x 120 x 32	131	Ball	210	10.08	UL/CUL/TUV/CE	48.4	11"	10.95	9.95	8.95	7.95
2231646	Adda	AD1248HB-F5B(N)	48	120 x 120 x 38	105	Ball	180	8.6	UL/CUL/TUV/CE	46.7	11" 4	14.95	13.49	11.95	10.95
2233107	Adda	AD1248UB-F51(FNCU)	48	120 x 120 x 38	120.1	Ball	230	11.04	UL/CUL/CE/TUV	48	12"	9.95	8.95	7.95	6.95
2203418	Adda	AD1248UB-F51	48	120 x 120 x 38	120.1	Ball	230	11.04	UL/CUL/TUV/CE	48	Terminal	10.95	9.95	8.95	7.95
2233043	Adda	AD1248HB-F92GP	48	120 x 120 x 38	199.7	Ball	200	9.6	UL/CUL/CE/TUV	42.8	15" 2	14.95	13.49	11.95	10.95
2134352	Adda	AD1348HB-F53	48	127 x 127 x 38	161	Ball	230	11	UL/CUL/TUV/CE	53	11" 1	17.95	15.95	14.49	12.95
1954711	Delta	EPB1348HHE-SV06	48	127 x 127 x 38	168	Ball	360	20	UL/CSA/VDE/CE	52	26" 1	19.95	17.95	15.95	14.49

1 3 leads; speed sensor (FG) 2 3 leads; alarm (RD) 4 4 leads; PWM & speed sensor (FG) (All fans operate to their specs with or without the additional optional wire functions)
For case mounting screws, P/Ns 2188481 or 2188490, page 78

Fan Guards, Screws & Aluminum Washable Filters

* Web Code: UAR

• Guards and filters fit all fans. Please match by size dimension.

P/N 300557 fan (80mm) matches P/N 31924 metal guard (80mm)

2100064

2188481/
2188490

Fig. 1

Fig. 2

Fig. 3

* Order in multiples of 10

Part No.	mm	Description	Fig.	1	10	50	100
2100064	—	Rubber fan mount (.06" x .01")	—	*	\$0.05	\$0.03	\$0.19
2188481	5x10	Fan frame screw, chrome	—	*	.15	.09	.07
2188490	5x10	Fan frame screw, black anodize	—	*	.15	.10	.08
123502	40	Metal (chrome) guard	1	.59	.55	.49	.45
120038	60	Metal (chrome) guard	1	.65	.59	.55	.49
687666	60	Metal (black anodized) guard	2	.85	.79	.75	.69
31924	80	Metal (chrome) guard	1	.69	.65	.59	.55
1928433	80	Metal (black anodized) guard	2	.79	.69	.65	.59
123511	92	Metal (chrome) guard	1	.75	.69	.65	.59
2135689	92	Metal (black anodized) guard	2	.89	.79	.69	.59
2172877	92	Metal (gold plated) guard	2	.65	.55	.45	.39
25735	120	Metal (chrome) guard	1	.79	.75	.69	.65

Part No.	mm	Description	Fig.	1	10	50	100
695068	120	Metal (black anodized) guard	2	\$1.09	\$.99	\$.89	\$.79
695076	127	Metal (chrome) guard	1	.79	.69	.59	.49
1811198	172	Metal (chrome) guard	1	.89	.79	.69	.59
1952290	80	Plastic guard only	3	.49	.45	.39	.35
1952695	40	Plastic guard w/ mesh	4	1.59	1.49	1.35	1.25
1952708	60	Plastic guard w/ mesh	5	1.65	1.49	1.39	1.29
2158135	80	Plastic guard w/ mesh	4	1.65	1.49	1.39	1.29
138562	80	Plastic guard w/ mesh (clip)	5	1.79	1.69	1.59	1.45
229665	92	Plastic guard w/ mesh	4	1.39	1.29	1.19	1.05
196817	120	Plastic guard w/ mesh	4	2.19	2.09	1.95	1.79
138580	80	Alum. washable filter	6	2.25	1.95	1.79	1.59
130105	120	Alum. washable filter	6	3.49	3.15	2.75	2.49

Fig. 4

Fig. 5

Fig. 6

* For additional products, availability and specifications visit [Jameco.com](http://www.Jameco.com) and enter the Web Code in the product search box

3 LEVELS OF SAVINGS		
NAME BRANDS	HOUSE BRANDS	SPECIAL BUY

Order by Phone at 1-800-831-4242 or Online at www.Jameco.com 87A

Fans

AC Tubeaxial Fans & Power Cords

3 LEVELS OF SAVINGS		
NAME BRANDS	HOUSE BRANDS	SPECIAL BUY

Call for additional OEM PRICING - we carry major manufacturers.



120 & 220VAC Tubeaxial Fans

NEW MARKED IN PINK

COMMONWEALTH™



* Web Code: ABJ



2126096



2205405



102892



2228287

Part No.	Manufacturer	Mfr. Part No.	Voltage (VAC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection	Pricing			
												1	10	50	100
213867	Fulltech	UF60D11BWH	120	60 x 60 x 30	10.2	Ball	35	4	UL/CUL/VDE/CE	28	12" leads	\$17.95	\$16.49	\$15.95	\$14.49
2231734	ADDa	AA8251HB-AT	120	80 x 80 x 25	21	Ball	70	5.8	UL/CUL/TUV/CE	27	Terminals	12.95	11.95	10.95	9.95
2230660	Thermocool	G8025HAS	120	80 x 80 x 25	23	Sleeve	130	13	UL/CUL/TUV/CE	30	12" leads	10.95	9.95	8.95	7.95
146078	Common Wealth	FP108AX-S1-B	120	80 x 80 x 25	23	Ball	180	14	UL/CE	29	12" leads	15.95	14.49	12.95	11.95
300557	Fulltech	UF80B11SWH	120	80 x 80 x 25	24	Sleeve	140	14	UL/CUL/TUV/CE	35	12" leads	13.95	12.95	11.95	10.95
2133819	Adda	AA8381MS-AT	120	80 x 80 x 38	24	Sleeve	80	9.2	UL/CSA/TUV/CE	26.2	Terminals	13.95	12.49	10.95	9.95
2228279	Mechatronics	UF80A12BWL	120	80 x 80 x 38	25	Ball	110	9	UL/CSA	32	11" leads	14.95	13.49	11.95	10.95
300600	Fulltech	UF80A11BWH	120	80 x 80 x 38	29	Ball	120	12	UL/CUL/TUV/CE	36	12" leads	15.95	14.49	12.95	11.49
300389	Fulltech	UF80A11BTH	120	80 x 80 x 38	30	Ball	120	12	UL/CUL/TUV/CE	36	Terminals	15.95	14.49	12.95	11.49
2126096	Common Wealth	FP-108B **	120	92 x 92 x 25	22	Ball	60	8	UL/CSA	24	15" leads	9.95	8.95	7.95	6.95
2234169	NMB	3610PS-12T-B20	120	92 x 92 x 25	28	Ball	90	6	CSA	35	Terminals	8.95	7.95	6.95	6.25
2230678	Thermocool	G9225HAS	120	92 x 92 x 25	34	Sleeve	140	13	UL/CUL/TUV/CE	40	Terminals	10.95	9.95	8.95	7.95
303467	Sunon	SP11592A-1092HBL.GN	120	92 x 92 x 25	37	Ball	110	12	UL/CSA/TUV/CE	40	12" leads	12.95	11.95	10.95	9.95
2135275	Common Wealth	FP-108JC	120	92 x 92 x 38	45	Sleeve	150	10	UL/CSA/CE	37	12" leads	13.95	12.49	10.95	9.95
2131830	Adda	AA1251MB-AW	120	120 x 120 x 25	65	Ball	240	22.3	UL/CSA/TUV/CE	39	12" leads	15.95	14.49	12.95	11.49
1810048	Sunon	SP101AT-1122HBL.GN	120	120 x 120 x 25	78	Ball	180	18	UL/CUL/TUV/CE	46	12" leads	16.95	15.49	13.95	12.49
124063	Sunon	SP101AT-1122HBT.GN	120	120 x 120 x 25	78	Ball	180	18	CSA/TUV/CE	46	Terminals	16.95	15.49	13.95	12.49
2230379	EBM PABST	4800N	120	120 x 120 x 38	57.1	Sleeve	78	9	UL/CSA/CE	32	Terminals	14.95	13.49	11.95	10.95
303361	Fulltech	UF12A11BTL1	120	120 x 120 x 38	64	Ball	80	15	UL/CUL/TUV/CE	37	Terminals	14.95	13.49	11.95	10.95
2205392	Adda	AA1281MB-AW	120	120 x 120 x 38	80	Ball	140	16.1	UL/CUL/TUV/CE	40	12" leads	12.95	11.49	9.95	8.95
2205405	Adda	AA1281MB-AT(CF)	120	120 x 120 x 38	80	Ball	250	16	UL/CUL/TUV/CE	40	Terminals	13.95	12.49	10.95	9.95
2230694	Thermocool	G12038MAB	120	120 x 120 x 38	85	Ball	220	19	UL/CUL/TUV/CE	44	Terminals	12.95	11.95	10.95	9.95
2231718	Sunon	SP102A-1123MBL.GN	120	120 x 120 x 38	88	Ball	160	15	UL/CUR/TUV/CE	40	12" leads	14.95	13.49	11.95	10.95
2100427	Adda	AA1281HS-AW	120	120 x 120 x 38	91	Sleeve	250	16	UL/CUL/TUV/CE	43	12" leads	11.95	10.95	9.95	8.95
2230686	Thermocool	G12038HAS	120	120 x 120 x 38	95	Sleeve	280	21	UL/CUL/TUV/CE	48	Terminals	11.95	10.95	9.95	8.95
106586	Common Wealth	FP108-1-S1/T	120	120 x 120 x 38	105	Sleeve	180	12	UL/CSA/CE	47	Terminals	12.95	11.95	10.95	9.95
16935	Common Wealth	FP108-1-S1-B/T	120	120 x 120 x 38	105	Ball	200	17	UL/CSA/TUV/CE	47	Terminals	13.95	12.49	11.95	10.49
1707163	Sunon	SP101A-1123HBL.GN	120	120 x 120 x 38	107	Ball	180	18	UL/CSA/TUV	50	12" leads	15.95	14.49	12.95	11.49
2125931	Common Wealth	FP108-1	120	120 x 120 x 38	112	Ball	250	19	UL/CUL/TUV/CE	45	Terminals	13.95	12.49	11.49	9.95
102884	Sunon	SP100A-1123XBT.GN	120	120 x 120 x 38	117	Ball	240	20	UL/CUL/TUV/CE	50	Terminals	14.95	13.95	12.95	11.95
2231726	Sunon	SP100A-1123XBL.GN	120	120 x 120 x 38	117	Ball	240	20	UL/CUR/TUV/CE	50	12" leads	17.95	16.49	14.95	13.49
2230141	Fulltech	UF13A11BTH	120	127 x 127 x 38	120	Ball	160	12	UL/CUL/TUV/CE	50	Terminals	19.95	17.95	15.95	14.49
2230707	Thermocool	G13538HAS	120	135 x 135 x 38	122	Sleeve	340	25	UL/CUL/TUV/CE	53	12" leads	13.95	12.49	11.25	10.49
2230715	Thermocool	G15050HAS	120	150 x 150 x 50	198	Sleeve	400	38	UL/CUL/TUV/CE	59	12" leads	20.95	18.95	16.95	15.49
2227701	ETRI	148VE0282030	120	172 x 150 x 38	122	Ball	100	11	UL/CSA/CE	36	Terminals	29.95	26.95	24.95	21.95
2230723	Thermocool	G17050HASB	120	172 x 172 x 51	198	Ball	400	38	UL/CUL/TUV/CE	59	Terminals	20.95	18.95	16.95	15.49
189684	Fulltech	UF15PC11BTH	120	172 x 150 x 51	226	Ball	250	30	UL/CUL/TUV/CE	58	Terminals	32.95	29.95	26.49	23.95
212582	Fulltech	UF15PC11BWH	120	172 x 150 x 51	226	Ball	250	30	UL/CUL/TUV/CE	58	12" leads	32.95	29.95	26.49	23.95
2230117	ADDa	AA8252HB-AT	220	80 x 80 x 25	21	Ball	60	13.8	UL/CUL/TUV/CE	27.8	Terminals	12.95	11.95	10.95	9.95
2235241	Adda	AA8382HX-AT	220	80 x 80 x 38	24	Hypro	70	8.8	UL/CUL/TUV/CE	25	Terminals	11.95	10.95	9.95	8.95
355630	Fulltech	UF-80A23-BTH-R	220	80 x 80 x 38	30	Ball	60	12	UL/CSA/VDE/CE	36	Terminals	12.95	11.49	10.25	9.49
100918	EG&G Rotron	SP23080A/2083HSL.GN	220	80 x 80 x 38	30	Sleeve	60	13.5	UL/CSA/TUV/CE	35	12" leads	15.95	13.95	12.49	10.95
2210837	EG&G Rotron	SU3G1	220	80 x 80 x 38	32	Sleeve	70	10	UL/CSA	39	12" leads	8.95	7.95	6.95	6.25
2234177	NMB	3115FS-23T-B10-A00	230	80 x 80 x 38	33	Ball	87	6	UL/CSA	36	Terminals	10.95	9.95	8.95	7.95
2234636	NMB	3610FS-23T-B10-A00	230	92 x 92 x 25	28	Ball	50	7	UL/CSA	35	Terminals	12.95	11.95	10.95	9.95
2231566	ADDa	AA1252MB-AT	220	120 x 120 x 25	65	Ball	100	21.6	UL/CUL/TUV/CE	38	Terminals	14.95	13.49	11.95	10.95
2258419	Fulltech	UF12A1223BWH*	115/230	120 x 120 x 38	92/106	Ball	260/120	23	UL/CUL/TUV/CE	42/46	12" leads	15.95	14.49	12.95	11.59
2231996	Adda	AA1282HB-AT	220	120 x 120 x 38	96.1	Ball	130	16	UL/CUL/TUV/CE	42.2	Terminals	16.95	14.95	13.49	11.95
2133801	Adda	AA1282UB-AT	220	120 x 120 x 38	103	Ball	120	21	UL/CUL/TUV/CE	46	Terminals	17.95	15.95	14.49	12.95
303459	Sunon	DP200A-2123XBL.GN	220	120 x 120 x 38	117	Ball	120	21	UL/CSA/TUV/CE	50	12" leads	15.95	14.95	13.95	12.95
102892	Sunon	DP200A-2123XBT.GN	220	120 x 120 x 38	117	Ball	120	21	UL/CSA/TUV/CE	50	Terminals	17.95	15.95	14.49	12.95
2228287	Papst	RER125-19/56	230	138 x 40	61.2	Ball	120	19	UL/CSA/TUV/CE	65	15" leads	39.95	35.95	32.95	29.95
2230424	Commonwealth	FP-108EX (S-1)	220	172 x 150 x 51	210	Ball	220	32	UL/CSA/TUV/CE	50	Terminals	29.95	26.49	23.95	21.49

* 4 wire leads, dual voltage ** 24 AWG quick disconnect terminals For case mounting screws, P/Ns 2188481 or 2188490, page 78

JAMECO ValuePro

DC & AC Plug Fan Power Cords

For Fans with Terminal Connection

* Web Code: GAE

Pigtail Fan Cord (A)	AC Plug Fan Cord (B)			

Part No.	Description	Fig.	Length	1	10	100	250
28564	Straight pigtail fan cord	1A	24"	\$1.49	\$1.25	\$.99	\$.89
2076658	Straight pigtail fan cord	1A	36"	1.59	1.45	1.29	1.15
1952548	45° pigtail fan cord	2A	24"	1.59	1.35	1.09	.99
104192	90° pigtail fan cord	3A	24"	1.59	1.35	1.09	.99
1952572	Straight AC plug fan cord	1B	72"	3.95	3.59	3.19	2.49
1952581	45° AC plug fan cord	2B	72"	4.95	4.59	3.95	3.49