


Batteries & Rechargeable Battery Pack

3 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS SPECIAL BUY

Lithium, NiCd, NiMH, Li-Ion & LiFePO4 Batteries

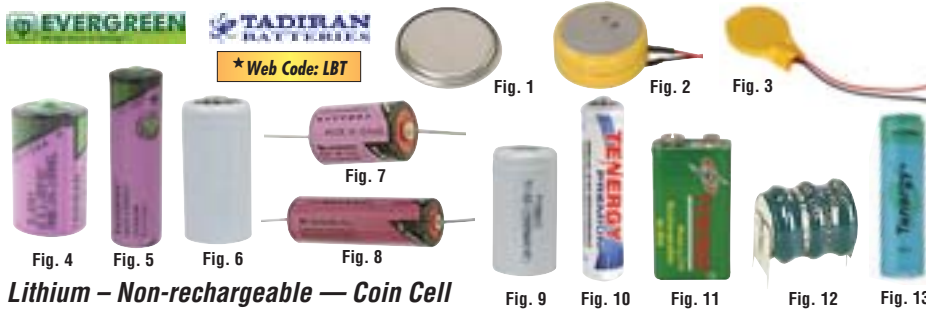

Lithium - Non-rechargeable - Coin Cell

Part No.	Product No.	Mfr.	Fig.	Size	Volts	mAh	Dimensions	1	10	25
2123784	CR1220	Evergreen	1	CR1220	3	40	0.49" Dia. x 0.77" Thick	\$.69	\$.59	\$.49
2210010	CR1220-LEADS	ReliaPro	2	CR1220	3	40	0.49" Dia. x 0.77" Thick	.89	.79	.69
2119865	CR1632	Evergreen	1	CR1632	3	120	0.63" Dia. x 0.13" Thick	.99	.89	.79
2238362	CR2025-LEADS	ReliaPro	3	CR2025	3	160	0.79" Dia. x 0.10" Thick	1.29	1.15	.99
2167509	CR2025-2*	Evergreen	1	CR2025	3	162	0.79" Dia. x 0.10" Thick	1.95	1.75	1.49
14162	CR2032	Renata	1	CR2032	3	180	0.79" Dia. x 0.13" Thick	.89	.79	.69
2223443	CR2032-LEADS	ReliaPro	3	CR2032	3	180	0.79" Dia. x 0.13" Thick	1.49	1.29	1.19
11789	CR2325	ReliaPro	1	CR2325	3	165	0.91" Dia. x 0.13" Thick	1.19	1.09	.99
2229571	CR2354	Panasonic	1	CR2354	3	560	0.91" Dia. x 0.21" Thick	1.49	1.35	1.19
2119216	CR2450	Evergreen	1	CR2450	3	550	0.95" Dia. x 0.20" Thick	1.19	1.09	.99
2238371	CR2450-LEADS	ReliaPro	3	CR2450	3	550	0.95" Dia. x 0.20" Thick	1.35	1.19	1.09
2258822	CR2477BN	Panasonic	1	CR2477	3	1000	0.96" Dia. x 0.30" Thick	1.95	1.75	1.49
2158231	CR927	ReliaPro	1	CR927	3	30	0.37" Dia. x 0.10" Thick	.59	.49	.39

*Sold in multiple of 2 \$2 wire leads

Lithium - Non-rechargeable - Pressure Fit

Part No.	Product No.	Mfr.	Fig.	Size	Volts	mAh	Dimensions	1	10	25
2188561	LS14250	Saft	4	1/2 AA	3.6	1200	1.00"L x 0.56" Dia.	\$3.95	\$3.59	\$3.29
146114	TL-5104/S	Tadiran	5	AA	3.6	2100	1.91"L x 0.56" Dia.	6.95	6.25	5.59
240258	CR123A	Evergreen	6	CR123A	3	1300	1.36"L x 0.65" Dia.	2.49	2.25	1.95

Lithium - Non-rechargeable - Axial Leads

Part No.	Product No.	Mfr.	Fig.	Size	Volts	mAh	Dimensions	1	10	25
33371	TL-5101P	Tadiran	7	1/2 AA	3.6	950	0.93"L x 0.56" Dia.	\$5.95	\$5.39	\$4.79
263898	ER14250	ReliaPro	7	1/2 AA	3.6	1000	1.00"L x 0.55" Dia.	4.49	3.95	3.75
33398	TL-5104/P	Tadiran	8	AA	3.6	2100	1.88"L x 0.56" Dia.	7.29	6.59	5.95

NiCd - Rechargeable - Pressure Fit

*Web Code: GCF

Part No.	Product No.	Mfr.	Fig.	Size	Volts	mAh	Dimensions	1	10	25
261657	AA-700-CT	ReliaPro	5	AA	1.2	700	1.90"L x 0.55" Dia.	\$1.75	\$1.49	\$1.25
244515	AA-1000-CT	ReliaPro	5	AA	1.2	1000	1.90"L x 0.55" Dia.	2.49	2.25	1.95
244574	SC-1500	ReliaPro	9	Sub-C	1.5	1500	1.70"L x 0.89" Dia.	2.95	2.59	2.29

NiMH - Rechargeable

*Web Code: GCF

Part No.	Product No.	Mfr.	Fig.	Size	Volts	mAh	Dimensions	1	10	25
231095	10405	Tenergy	10	AAA	1.2	1000	1.70"L x 0.40" Dia.	\$2.75	\$2.49	\$2.25
231087	AA-1800NM	Dantona	5	AA	1.2	1800	1.90"L x 0.55" Dia.	3.49	2.95	2.59
2197492	AA-2300-2*	ReliaPro	5	AA	1.2	2300	1.90"L x 0.55" Dia. (2 pk)	4.95	4.49	3.95
2127777	AA-2500CT	Tenergy	5	AA	1.2	2500	1.90"L x 0.55" Dia.	3.95	3.59	3.29
244620	10005	Tenergy	11	9V	8.4	200	1.94"L x 0.65" Dia.	7.95	6.95	6.25

*Pack of 2

PC Pin (2 & 3 pin)

Part No.	Product No.	Mfr.	Fig.	Size	Volts	mAh	Dimensions	1	10	25
2137473	NHB60H3A2H	Evergreen	12	2 pin	3.6	80	0.72"L x 0.61" Dia.	\$4.95	\$4.49	\$3.95
2129342	COMP-16-3NMH	Dantona	12	3 pin	3.6	80	0.72"L x 0.61" Dia.	6.95	6.25	5.59

TENERGY Li-Ion - Rechargeable - Pressure Fit

*Web Code: LII

Part No.	Product No.	Mfr.	Fig.	Cell Size	Volts	mAh	Dimensions	1	10	25
2140349	30006	Tenergy	13	18650	3.7	2600	2.56"L x 0.72" Dia.	\$11.95	\$10.95	\$9.95

TENERGY LiFePO4 - Rechargeable - Pressure Fit

*Web Code: LIF

Part No.	Product No.	Mfr.	Fig.	Cell Size	Volts	mAh	Dimensions	1	10	25
2144227	30225	Tenergy	5	14500 (AA)	3.2	400	1.91"L x 0.56" Dia.	\$2.49	\$2.25	\$1.95

me 12V Lithium-Ion Rechargeable Battery Pack

High-powered, ultra-compact, covert battery pack with charger. Provides the same power as larger batteries at a fraction of the size and weight.

- Charging adapter included
- On/Off switch
- LED indicators
- 18" power cord
- Input: 110-230VAC 50/60Hz
- Output: 12.6VDC, 350mA
- Connection: 2.1mm female output, 2.1mm male input
- Size: 3.0"L x 2.0"W x 0.75"H
- 4500 mAh
- Weight: 0.58 lbs.



Part No.	Description	1	10
2129351	LBP-124500	\$49.95	\$44.95

JAMECO ReliaPro Lithium-Ion Power Bank Rechargeable Battery Pack

- 4000mAh (4Ah)
- Output: dual USB output 5VDC, one with 1A output and one with 2A output
- Input: one micro B USB port (5VDC, 1A)
- Convenient battery test button
- 1 foot USB male to micro B male cable included



Part No.	Mfr. Part No.	1	10	25
2228527	Q57251	\$19.95	\$18.95	\$17.95

adafruit USB Li-Ion/LiPoly Charger

- Assembled. Includes bonus 2-pin JST cable
- For 3.7/4.2V (not compatible with 3.6/4.1V cells)
- Connect via USB mini-B
- 500mA default fast-charge current
- Battery and USB cable sold separately
- 0.1" breakouts for battery, DC and status LEDs
- Size: 1.3"L x 1.4"W x 0.3"H



Part No.	Mfr. Part No.	1	5
2144366	259	\$13.95	\$12.95

adafruit 3.7V 2500mAh Li-Poly Battery Pack

- Lithium-ion polymer battery pack
- 3.7V (as high as 4.2V on full charge)
- 3.75" wires with 2-pin JST connector
- Recharge rate should be ≤1200 mA (1/2C)
- Size: 2"L x 2.55"W x 0.3"H



Part No.	Mfr. Part No.	1	5
2240139	328	\$18.95	\$17.95

Wall Type NiMH/NiCd Battery Charger

- Input voltage: 120VAC @ 60Hz
- Output power: 1.2VA
- 2 individual charging channels
- Retractable AC prongs
- LED indicator and reverse polarity protection



Part No.	Mfr. P/N	Description	1	10	100
2197505	KN-101	AA/AAA/9V charger	\$1.95	\$1.75	\$1.49

*Battery Chargers & Packs - Enter Web Code LAC