


Toggle Switches, Switch Covers & Rocker Switches



Standard Toggle Switches

- Mounting hole diameter: 1/2"
- Shaft thread: M12 x 0.75
- Waterproof boot seals (below)

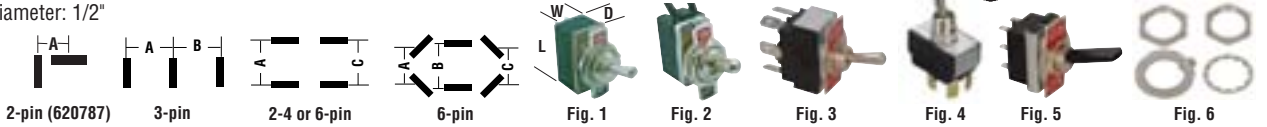

Part No.	Manufacturer	Product No.	Fig.	Pins	Contact Form	Contact Rating (A @ VAC)	Dimensions (L" x W" x D")	Lead Spacing			Terminal Type	Lever Type	Pricing		
								A"	B"	C"			1	10	100
76241	ValuePro	SWM128	1	2	SPST on-off	4 @ 125 & 2 @ 250	1.00 x .56 x .52	.23	—	—	Solder lugs	Round	\$1.95	\$1.75	\$1.49
76232	ValuePro	SWM125	2	2	SPST on-off	6 @ 125 & 3 @ 250	1.00 x .53 x .51	.23	—	—	6" lead wire	Round	1.95	1.75	1.55
317825	ValuePro	R13-25A2-01	3	2	SPST on-off	10 @ 125 & 6 @ 250	1.14 x .59 x .62	.38	—	—	.250" quick connect	Round	2.55	2.29	1.99
318027	ValuePro	R13-28A-06	3	2	SPST on-off	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.46	—	M3 screw	Round	2.75	2.55	2.25
318002	ValuePro	R13-28A-01	3	2	SPST on-off	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.57	—	.250" quick connect	Round	3.25	2.95	2.75
621499	GC Electronics	35-3005*	4	2	SPST on-off	20 @ 125 & 10 @ 250	.92 x .64 x .40	.47	—	.96	.250" quick connect	Round	4.49	4.25	3.95
158060	ValuePro	JKN32†	1	4	SPDT on-off	4 @ 125 & 2 @ 250	1.00 x .56 x .52	.23	.65	.23	Solder lugs	Round	1.25	1.09	.99
318123	ValuePro	R13-28D-01	3	3	SPDT on-off-on	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.65	.45	.250" quick connect	Round	2.49	2.25	1.95
2229749	Arndt	DPDT-C-OFE	3	6	DPDT on-off	10 @ 125 & 20 @ 125	1.31 x .75 x .75	.45	.44	.45	M3 screw	Round	3.25	2.95	2.65
317850	ValuePro	R13-25B1-05	5	6	DPDT on-on	10 @ 125 & 6 @ 250	1.14 x .79 x .62	.40	.38	.40	Solder lugs	Flat	2.25	2.09	1.79
158078	ValuePro	JKN3CC	1	6	DPDT on-on	15 @ 125 & 10 @ 250	1.19 x .76 x .73	.44	.59	1.0	Screw lugs	Round	1.55	1.29	1.15
318043	ValuePro	R13-28B-01	3	6	DPDT on-on	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.61	2.5	.250" quick connect	Round	3.29	2.95	2.75
317972	ValuePro	R13-25E1-05	5	6	DPDT on-off-on	10 @ 125 & 6 @ 250	1.14 x .59 x .62	.38	.38	.38	Solder lugs	Flat	3.25	2.95	2.65
567761	ValuePro	T-1224	3	6	DPDT on-off-on	10 @ 125 & 5 @ 250	1.18 x .77 x .75	.40	.60	2.64	M3 screw	Round	3.95	3.59	3.29
2182733	ValuePro	M12HDWR	6	Additional M12 hardware (2 hex nuts, 1 internal lock washer, 1 key lock washer)									.99	.89	.79

* Shaft thread: 15/32-32 use 2182506 (pg 78) for additional panel mounting hardware † alternate action



Protective and Waterproof Boot Seal Switch Covers

- Full protection from water, oil, sand, dust, dirt, humidity, moisture and other contaminants
- Applications: aerospace, automotive, computer and electronic equipment • IP68 rated

* Web Code: SBS



2150192

2192683

Part No.	Manufacturer	Product No.	Description	Dimensions	1	10	100
2150192	Zago	TH 606-GY	Toggle switch boot seal, gray, 15/32-32, fits standard toggle switches (above)	0.625" OD x 0.209" ID x 0.890"H	\$1.49	\$1.35	\$1.19
2192683	Zago	TH609-BLK	Toggle switch boot seal, black, 15/32-32, fits standard toggle switches (above)	0.324" OD x 0.226" ID x 0.937"H	2.09	1.89	1.69



Standard Appliance Panel Mount Rocker Switches



* Web Code: VBU



Part No.	Mfr.	Product No.	Pins	Contact Form () Momentary	Contact Rating (A @ VAC)	Dimensions (L" x W" x D")	Lead Space		Rocker Color	Terminal Type	Pricing		
							A"	B"			1	10	100
2208198	JVP	RS-001G-A-BB-4	2	SPST on-off	6 @ 125 & 3 @ 250	.59 x .41 x .75	—	.20	Black	.145" quick connect	\$.75	\$.59	\$.45
316048	JVP	R13-66B-G-02	3	SPST on-off	9 @ 125 & 6 @ 250	.83 x .59 x .47	.31	.31	Green illum.	.187" quick connect	1.09	.99	.89
316128	JVP	R13-73B-R-02	3	SPST on-off	9 @ 125 & 6 @ 250	.83 x .59 x .87	.35	.35	Red illum.	.187" quick connect	1.09	.99	.89
316136	JVP	R13-73B-Y-02	3	SPST on-off	9 @ 125 & 6 @ 250	.83 x .59 x .87	.35	.35	Yellow illum.	.187" quick connect	.65	.55	.45
316451	JVP	R13-243A-02	2	SPST on-off	10 @ 125 & 6 @ 250	.83 x .37 x .85	.35	—	Black	.187" quick connect	.95	.85	.75
1945284	PRO	R13-66	2	SPST on-off	10 @ 125 & 6 @ 250	.83 x .59 x .55	.31	—	Dark gray	5.5" wire leads	.59	.49	.39
2218839	JVP	RS-105A-BB-3-UL	2	SPST on-off	10 @ 125 & 6 @ 250	.91 x .78 x .70	.30	—	Black	.187" quick connect	.95	.85	.75
577221	CHY	RRA22H3BBBNN	2	SPST on-off	12 @ 125 & 10 @ 250	.69 x .51 x .64	.35	—	Black	.187" quick connect	1.09	.99	.89
316022	JVP	R13-66A-R-02	2	SPST on-off	15 @ 125 & 8 @ 250	.83 x .59 x .63	.31	—	Red	.187" quick connect	.95	.85	.75
316014	JVP	R13-66A-B-02	2	SPST on-off	16 @ 125 & 10 @ 250	.83 x .59 x .63	.31	—	Black	.187" quick connect	.95	.85	.75
2201914	HNY	O28-01011-00	2	SPST on-off	16 @ 125 & 12 @ 250	1.3 x .55 x .90	.26	—	Black	.250" quick connect	.39	.35	.29
2182389	ARN	160112E	2	SPST (on)-off	6 @ 125 & 16 @ 250	1.0 x .48 x .98	.38	.38	White	.250" quick connect	.69	.59	.49
1945241	ITW	163-099-029	3	SPDT	16 @ 125 & 12 @ 250	1.2 x .55 x .59	.26	.26	Black	.250" quick connect	.59	.39	.35
2181255	C&K	7101J1V6BE2	3	SPDT on-none-on	5 @ 120 & 2 @ 250	.50 x .28 x .37	—	.19	Black	PC terminal	.85	.75	.65
2178566	CWI	GRS-4012-0050	3	SPDT on-on	8 @ 125 & 4 @ 250	.74 x .50 x .46	.22	—	Red	.187" quick connect	.45	.35	.25
2182354	ALC	MHL106D10M0	3	SPDT on-off	6 @ 125 & 3 @ 250	.50 x .30 x .39	.19	.19	Black	Solder lugs	.99	.89	.78
2182418	DIA	570-12/574-1212-0104-007	3	SPDT on-off-on	5 @ 125 & 2 @ 250	.50 x .28 x .37	—	.19	Black	PC terminal	.49	.39	.35
316072	JVP	R13-66D-02	3	SPDT on-off-on	16 @ 125 & 10 @ 250	.83 x .59 x .47	.31	.31	Black	.187" quick connect	1.09	.89	.79
2181722	C&K	7105J1V3QE2	3	SPDT (on)-off-(on)	5 @ 120 & 2 @ 250	.50 x .28 x .37	—	.19	Black	PC terminal	.69	.59	.55
617473	GCE	35-695	3	SPDT (on)-off-(on)	16 @ 125 & 16 @ 250	.93 x .43 x .62	.34	.56	Black	.250" quick connect	4.49	4.05	3.69
316153	JVP	R13-73C-R-02	4	DPST on-off	10 @ 125 & 6 @ 250	.83 x .59 x .87	.20	.34	Red illum.	.187" quick connect	1.19	1.09	.99
316111	JVP	R13-73A2-B-02	4	DPST on-off	12 @ 125 & 6 @ 250	.83 x .59 x .68	.20	.34	Black	.187" quick connect	1.39	1.25	1.09
2181271	OTT	K2ABHLCADA	4	DPST on-off	16 @ 125/250	1.06 x .65 x 1.45	—	—	Green illum.	.187" quick connect	2.95	2.75	2.49
2181183	C&K	ET21J1ABE2	6	DPDT on-none-on	.4VA @ 20VAC/VDC	.37 x .32 x .36	—	.10	Black	PC terminal	.75	.65	.55

* ALC = Alcoswitch | ARN = Arndt | CHY = Cherry | C&K = C&K Components | CWI = CW Ind. | DIA = Dialight | GCE = GC Elec. | HNY = Honeywell | JVP = ValuePro | ITW = Illinois Tool | OTT = Otto | PRO = Pronic Elec.

* For additional products, availability and specifications visit Jameco.com and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at www.Jameco.com