

AC-to-DC Wall Adapters & Table-Top Power Supplies


 
3 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS SPECIAL BUY

JAMECO ReliaPro AC-to-DC Unregulated Linear Wall Adapters (Continued)

2.1mm (3/32") 2.5mm (2/16") 1/8"

* Web Code: UAP

Input: 120VAC @ 60Hz Call for Additional OEM pricing.

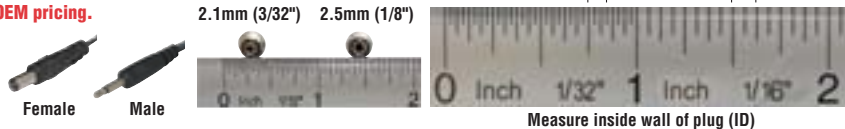

Part No.	Manufacturer	Product No.	Output Rating		Output Connector ID x OD mm Female/Male; Polarity ♦	Size (H" x W" x D")	Case Color	Output Cord Length	Wt. (lbs.)	Agency Approvals	Pricing			
			Voltage (VDC)	Current (mA)							1	10	50	100
2218118	Netgear	AD661F**	12	1500	2.1mm x 5.5mm F 2	3.0 x 2.0 x 1.4	Black	6'	0.3	UL/CUL/CEC	\$10.95	\$9.95	\$8.95	\$7.95
136881	ReliaPro	DDU120150K1960	12	1500	2.1mm x 5.5mm F 2	3.4 x 2.7 x 2.2	Black	6'	1.5	UL/CUL	12.95	11.49	9.95	8.95
101291	ReliaPro	DDU120150	12	1500	2.5mm x 5.5mm F 2	3.4 x 2.7 x 2.2	Black	6'	1.5	UL/CUL	12.95	11.49	9.95	8.95
2218003	ReliaPro	DFU120200R	12	2000	2.1mm x 5.5mm F 2	3.4 x 2.7 x 2.2	Black	6'	1.5	UL/CUL	14.95	13.49	11.95	10.95
2224008	ReliaPro	DFU120200R	12	2000	2.5mm x 5.5mm F 2	3.4 x 2.7 x 2.2	Black	6'	1.5	UL/CUL	14.95	13.49	11.95	10.95
308099	ReliaPro	DDU135100H3210	13.5	1000	2.1mm x 5.5mm F 2	2.9 x 2.3 x 1.9	Black	6'	1.0	UL/CUL	10.95	9.95	8.95	7.95
123932	ReliaPro	DDU140070Z7470	14	700	2.1mm x 5.5mm F 2	2.6 x 2.4 x 2.0	Black	6'	1.0	UL/CUL	8.95	7.95	6.95	6.25
190001	ReliaPro	DCU150050E3021	15	500	2.1mm x 5.5mm F 2	2.3 x 2.4 x 1.9	Black	6'	0.8	UL/CUL	7.95	6.95	6.25	5.95
189982	ReliaPro	DCU150050E3031	15	500	2.5mm x 5.5mm F 2	2.3 x 2.4 x 1.9	Black	6'	0.8	UL/CUL	8.95	7.95	7.29	6.49
191652	ReliaPro	DDU150100D7051	15	1000	2.1mm x 5.5mm F 2	3.3 x 2.2 x 1.9	Black	6'	1.0	UL/CUL	10.95	9.95	8.95	7.95
2081713	DVE	DV-1790	17	900	2.5mm x 5.5mm F 2	3.2 x 2.2 x 2.0	Black	6'	1.2	UL/CSA	2.95	2.59	2.25	1.95
2205261	ReliaPro	DDU180100H4550	18	1000	2.1mm x 5.5mm F 2	3.3 x 2.2 x 1.9	Black	6'	1.4	UL/CUL	10.95	9.95	8.95	7.95
206958	ReliaPro	DDU180100H4551	18	1000	2.5mm x 5.5mm F 2	3.3 x 2.2 x 1.9	Black	6'	1.4	UL/CUL	10.95	9.95	8.95	7.95
2228017	Arndt	WP572018DG†	18	1100	2.1mm x 5.5mm F 2	3.4 x 2.7 x 2.2	Black	6'	1.4	UL/CUL	9.95	8.95	7.95	6.95
102285	ReliaPro	DDU240040Z7860	24	400	2.1mm x 5.5mm F 2	3.0 x 2.3 x 2.0	Black	6'	0.9	UL/CUL	8.95	7.95	7.29	6.49
2192510	ReliaPro	DDU240050RS1160	24	500	2.1mm x 5.5mm F 2	2.9 x 2.3 x 1.9	Black	6'	1.0	UL/CUL	8.95	7.95	6.95	6.25
191556	ReliaPro	DDU240050E5852	24	500	2.5mm x 5.5mm F 2	3.1 x 2.3 x 1.9	Black	6'	1.0	UL/CUL	9.95	8.95	7.95	7.29
139088	ReliaPro	DDU240050E9160	24	500	3.5mm M 2	3.1 x 2.3 x 1.9	Black	6'	1.0	UL/CUL	8.95	7.95	6.95	5.95
168495	ReliaPro	DFU240080J3180	24	800	2.1mm x 5.5mm F 2	2.9 x 1.9 x 1.6	Black	6'	0.4	UL/CUL/TUV	11.95	10.95	9.95	8.95
220960	ReliaPro	DFU240100G2300	24	1000	2.1mm x 5.5mm F 1	3.4 x 2.7 x 2.2	Black	6'	1.6	UL/CUL	12.95	11.95	10.95	9.95
199523	ReliaPro	DDU300050E9340	30	500	2.5mm x 5.5mm F 2	2.9 x 2.3 x 1.9	Black	6'	1.1	UL/CUL	10.95	9.95	8.95	7.95
2167621	Seven Star	SS104*	1.5, 3, 4.5, 6, 7.5, 9, 12	500	0.7x2.3, 1.5x4, 2.1x5, 2.5x5.5 Female 2.5, 3.5 Male (LED indicator)	3.3 x 2.0 x 1.9	Black	6'	0.8	—	4.95	3.95	3.49	2.95
123158	ReliaPro	900-100*	1.5, 3, 4.5, 6, 7.5, 9, 12	1000	1.3x3.5, 2.1x5, 2.5x5.5 Female 2.5, 3.5 Male, 9V battery snap (LED ind.)	3.7 x 2.2 x 2.5	Black	6'	0.9	—	11.95	10.95	9.95	8.95

*110/220VAC input voltage **Slimline †3 prong ground

GlobTek® AC-to-DC Medical Table-Top Regulated Switching Power Supplies

* Web Code: WBM

- 2.5mm x 5.5mm female center positive
- Input voltage: 90-264VAC @ 47-63Hz
- Leakage current: 0.1mA max.
- Regulation (line & load): ±5%
- Isolation voltage: 4,000VAC
- Ripple & noise: 1% or 100mV, whichever is smaller
- Cord lengths: DC: 6'; AC: not included use P/N 132011, pg 102
- Size: 2.9"L x 2.0"W x 1.6"H



Part No.	Mfr. Part No.	Power (W)	Output VDC/Amps	Pricing		
				1	10	50
2179606	TR9CB2500LCP	15.0	+6/2.5	\$12.95	\$11.49	\$9.95
230683	TR9CE1250CP	15.0	+12/1.25	34.95	29.95	24.95
230798	TR9CI2100LCP	50.4	+24/2.1	59.95	53.95	47.95

* Interchangeable Power Supplies, Adapters and Tips — Enter Web Code NBH

Accessory Power Input Cords for Table-Top Power Supplies

* Web Code: UBF



Part No.	Ref. No.*	Description	Color	AWG	Certification	Cord Length	Wt. (lbs.)	Cord Type	Pricing			
									1	10	50	100
189587	1	2-conductor power cord (Figure 8 style)	Black	18/2	UL/CSA	6'	0.3	SPT	\$2.95	\$2.69	\$2.39	\$2.19
38050	2	3-conductor power cord	Black	18/3	UL/CSA	6'	0.4	SVT	4.95	4.49	3.95	3.59
1953559	3	3-conductor flat power cord (Mickey Mouse™ style)**	Black	18/3	UL/CSA	6'	0.4	SPT-2	2.95	2.59	2.29	1.95
1951123	3	3-conductor round power cord (Mickey Mouse™ style)**	Black	18/3	UL/CSA	6'	0.4	SVT	2.95	2.59	2.29	1.95

*These reference numbers for "AC cord needed" for Table-Top Power Supplies on pages 95-96

**Ref #3 chose flat or round cable

More Power Cords on page 102

REGULATED SWITCHING WALL ADAPTERS — BEST SELLERS

Part No.	Description	Page	Price
2188537	5V @ 2.0A	90	\$6.95
2224155	12V @ 0.75A	90	6.95
2208999	12V @ 1.0A	91	11.95
2173116	12V @ 3.0A	91	13.49
380191	18V @ 1.38A	91	12.49
2229941	24V @ 0.5A	91	11.95
2208972	24V @ 1.0A	91	12.95

UNREGULATED AC-to-AC WALL ADAPTERS — BEST SELLERS

Part No.	Description	Page	Price
100061	9V @ 0.5A	89	\$8.95
102234	9V @ 1.0A	89	9.95
112336	9V @ 1.5A	89	10.95
10081	12V @ 1.0A	89	9.95
2167576	12V @ 1.2A	89	6.95
2224008	12V @ 2.0A	94	14.95
87581	24V @ 0.5A	89	9.95
2100195	24V @ 1.5A	89	14.95