


Power Entry Filters, International Power Cords & Power Cord Adapters

JAMECO ValuePro

EMI Power Entry Filters (IEC Connector), Line Filters & AC Receptacles (IEC 320)

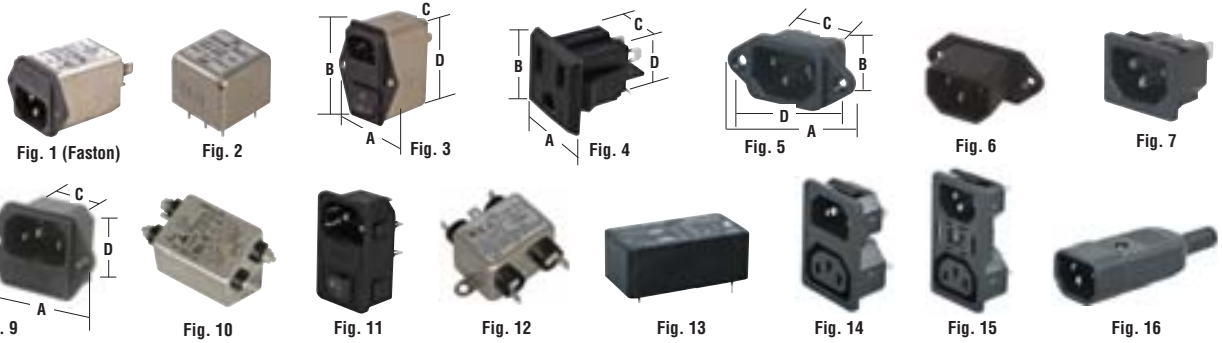

• Rated voltage: 115/250VAC • Operating frequency: 50/60Hz • Hipot rating (one minute) line to ground: 2250VDC; line to line: 1450VDC

* Web Code: ACR

EMI Power Entry Filter: Maximum leakage current each line to ground: @ 115VAC 60Hz: 0.20mA @ 250VAC 50Hz: 0.40mA

EMI Line Filter: Maximum leakage current each line to ground: @ 115VAC 60Hz: 0.25mA; 1.0mA (10000pF) @ 250VAC 50Hz: 0.45mA; 2.0mA (10000pF)

Part No.	Mfr.	Product No.	Description	Fig.	Current (A)	Hipot (VDC)	Terminals	Terminal Size	Agency Approvals	Dimension (in.)				Pricing		
										A	B	C	D	1	10	100
1172613	TE Conn.	1EGG1-2	Pwr entry filter, straight, fused (screw flanged)	1	1	2250	Faston	0.25"	UL/CSA/VDE	1.62	1.29	1.44	1.27	\$.99	\$.89	\$.79
2114116	Adam Tech	PLF-3PC	Line filter, metal case (PC mount)	2	3	250	Solder	0.039"	UL/CSA/VDE	0.984	0.984	0.787	—	5.95	5.39	4.79
2217879	Schaffner	FH365-4/05	Power entry filter, straight, fused (screw flanged)	1	4	2250	Faston	0.25"	UL/CSA/VDE	2.30	1.10	1.26	1.40	1.09	.99	.89
2234652	Schaffner	FN282B-6-06**	Pwr entry filter, strght, fuse & sw. (scrw flngd)	4	6	25000	Faston	0.25"	UL/CSA	1.26	3.23	—	2.36	14.95	13.49	11.95
2114124	Adam Tech	PLF-6DZ2KR	Pwr entry filter, strght, fuse & sw. (scrw flngd)	3	6	250	Faston	0.25"	UL/CSA/VDE	1.968	2.559	2.394	1.154	9.95	8.95	7.95
2234644	Schurter	5500.2014	Line filter (PC mount)	13	6.5	125	Solder	0.032"	UL/CSA	1.78	0.95	0.67	—	6.95	6.25	5.95
2178507	Arndt	6100-4115	AC power inlet, male (snap-in)	7	10	250	Solder	0.14"	UL/CSA/VDE	1.19	0.91	1.06	0.77	.29	.25	.19
117445	ValuePro	0717#	AC power inlet, male w/ fuse chamber (snap-in)	8	10	250	Faston	0.187"	UL/CSA/VDE	1.18	1.30	1.05	1.20	1.95	1.79	1.59
265528	ValuePro	WS-044#	AC power inlet, male w/ fuse chamber (screw)	9	10	250	Faston	0.187"	UL/CSA/VDE	1.40	1.28	1.06	1.21	1.75	1.49	1.25
2232868	Schurter	DC11.0001.001	AC power inlet, male w/ switch (screw)	9	10	250	Faston	0.187"	UL/CSA/VDE	1.73	1.34	1.06	1.43	7.95	6.95	5.95
2197880	Delta	10DRCS5	Power entry filter (flange mount)	10	10	2250	Threadpost	0.164"	UL/CSA/VDE	3.87	1.52	2.94	1.21	3.95	3.59	3.29
2230176	Qualtech	851-10/007	Power line EMI filter (flange mount)	12	10	2250	Faston	0.25"	UL/CSA/VDE	2.54	2.13	1.18	—	6.95	2.59	2.39
2114095	Adam Tech	NEMA-5-2*	AC power outlet, NEMA receptacles (snap-in)	4	15	125	Fork	0.25"	UL/CSA/VDE	1.063	1.063	0.70	0.866	.99	.85	.69
2235989	Kobiconn	161R301-B07	AC power inlet, male, PC type	6	10	250	PCB	0.18"	UL	1.92	0.88	1.06	1.58	.89	.79	.69
2236033	Kobiconn	161R301SN01	AC power inlet, male, snap-in	6	15	250	Faston	0.187"	UL	1.97	0.76	1.06	1.58	1.09	.99	.89
2178515	Arndt	EAC-409	AC power inlet, male (snap-in)	7	15	250	Solder	0.16"	UL/CSA/VDE	1.22	0.94	1.06	0.78	.29	.25	.19
1954640	ValuePro	K2415	AC power inlet, female (snap-in)	7	15	250	Faston	0.187"	UL/CSA/VDE	1.38	0.98	1.26	1.10	.29	.25	.19
2178494	Arndt	EAC-324	AC power inlet, male, straight (screw flanged)	6	15	250	Solder	0.16"	UL/CSA/VDE	1.96	0.89	1.09	1.09	.29	.25	.19
2229298	Schurter	6100-43	AC power inlet, male (snap-in)	7	15	250	Faston	0.25"	UL/CSA/VDE	1.18	0.90	1.06	0.77	.49	.39	.29
2235874	Kobiconn	161-R3012E	AC power inlet/outlet male/female (snap-in)	14	15	250	Faston	0.187"	UL/CSA/VDE	1.38	2.08	1.08	—	1.95	1.75	1.49
2235891	Kobiconn	161-R3012S	AC power inlet/outlet snap-in, fused	15	15	250	Faston	0.187"	UL/CSA/VDE	1.38	2.58	1.15	—	1.95	1.75	1.49
2235920	Kobiconn	161-R331	AC power cable conn inlet	16	10	250	—	—	UL	2.28	1.15	.826	1.02	1.95	1.75	1.49
147109	ValuePro	42R02	AC power inlet, male (snap-in)	7	15	250	Faston	0.25"	UL/CSA/VDE	1.23	0.95	1.04	0.77	.99	.89	.75
147901	ValuePro	701R	AC power inlet, male (screw flanged)	5	15	250	Faston	0.187"	UL/CSA/VDE	1.97	0.76	1.06	1.58	1.09	.99	.79
16652	ValuePro	JR101	AC power inlet, male (screw flanged)	5	15	250	Faston	0.25"	UL/CSA/VDE	1.97	0.76	1.06	1.58	1.09	.99	.79
2189521	Adam Tech	IEC-GS-1-150#2	Pwr entry male filter, w/ fuse & switch (snap-in)	11	15	250	Faston	0.187"	UL/CSA/VDE	1.20	1.97	1.07	1.84	2.95	2.75	2.49
2095525	Adam Tech	IEC-GS-1-100#1	AC pwr inlet, male w/ sw. & fuse folder (snap-in)	11	15	250	Faston	0.187"	UL/CSA/VDE	1.20	1.97	1.07	1.84	2.95	2.75	2.49
2157546	Adam Tech	IEC-GS-1-200#3	AC pwr fused inlet, male w/ switch (snap-in)	11	15	250	Faston	0.187"	UL/CSA/VDE	1.20	1.97	1.07	1.84	2.95	2.59	2.39

* For 14-16 AWG wire ** Medical version # Includes spare fuse holder - fuse type 5mm x 20mm (250V); Panel thickness: 1.04", 2.06", 3.08"

JAMECO ValuePro

International Power Cords

- Voltage rating: 300V
- Cord type: H05VVf
- 3-conductor detachable power cords
- BSI: British Standard Institution
- Cord color: black



* Web Code: XAQ

Part No.	Cross Ref. No.	Country	Agency Approvals	Plug Fig.	Cord Length	Conductors	Pricing		
							1	10	100
117911	2171H576	Europe	All	1	6 ft.	3/0.75mm	\$4.95	\$4.49	\$3.95
174633	21071H5182	UK/Ireland	BSI	2	8 ft.	3/1.0mm	6.95	6.25	5.59

European Agency Approvals					
Germany	VDE		France	LCIE	
Austria	DVE		Netherlands	KEMA	
Belgium	CEBEC		Norway	NEMKO	
Denmark	DENMKO		Sweden	SEMKO	
Finland	FIMKO		Switzerland	SEV	

JAMECO ValuePro

Power Cord Adapters



Part No.	Product No.	Description	1	10	50	100
2188545	YL-3215	IEC C14 plug to Nema 5-15R	\$3.95	\$3.59	\$3.29	\$2.95
2233991	YL-3412	IEC C6 plug to IEC C13 receptacle	3.95	3.59	3.29	2.95
2234003	YL-3114	IEC C8 plug to IEC C5 receptacle plug adapter	3.95	3.59	3.29	2.95
2234011	YL-3214	IEC C14 plug to IEC C5 receptacle plug adapter	3.95	3.59	3.29	2.95
2234020	YL-3113	NEMA 1-15P plug to IEC C7 receptacle plug adapter	3.95	3.59	3.29	2.95
2234038	YL-1212	NEMA 5-15P plug to IEC C13 receptacle plug adapter	3.95	3.59	3.29	2.95
2188553	YL-2215	IEC C13 to Nema 5-15P plug	3.95	3.59	3.29	2.95

* For additional products, availability and specifications visit Jameco.com and enter the Web Code in the product search box

3 LEVELS OF SAVINGS
NAME BRANDS HOUSE BRANDS SPECIAL BUY

Order by Phone at 1-800-831-4242 or Online at www.Jameco.com