

Battery Holders

3 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS SPECIAL BUY

JAMECO ReliaPro

Coin Cell, Single and Dual-Sided Battery Holders

eagle

KEYSTONE


* Web Code: UAB

Eliminate battery mounting problems in portable DC power applications and products. These holders are made from special materials that maintain retention properties longer than conventional holders. They can come with leads, tabs or snaps.

NEW
 MARKED IN PINK

Part No.	Cross Ref. No.	*Mfr.	Fig.	No. of Cells	Conn. (L")	Sides	Features*	1	10	100	500
2236981	12-051	JRP	1	2-AAA	Pins, 2.5	Single	Breadboard-ready	\$1.09	\$.99	\$.89	\$.79
216292	SBH-421-AS*	JRP	1	2-AAA	Wires, 5.5	Single	w/ cover&sw, 26 AWG	1.25	1.15	.95	.85
216283	BH-421-1A	JRP	1	2-AAA	Wires, 5.5	Single	26 AWG	.99	.89	.75	.69
216303	BH-431-1A	JRP	4	3-AAA	Wires, 5.5	Single	26 AWG	1.15	1.05	.95	.85
216312	SBH-431-1AS*	JRP	4	3-AAA	Wires, 6.0	Single	w/ cover&sw, 26 AWG	1.15	1.05	.95	.85
216339	SBH-441-AS*	JRP	5	4-AAA	Wires, 5.5	Single	w/ cover&sw, 26 AWG	1.59	1.45	1.29	1.15
2232833	UM-4	JRP	5	4-AAA	PC mount	Single	.478" (12mm) spacing	1.49	1.25	1.09	.95
2245546	BH-482B	JRP	18	8-AAA	Snap	Dual	Series (12V)	1.69	1.49	1.35	1.19
2197935	BC-0302	JRP	12	1-AA/AAA	PC mount	Single	.3" (7.62mm) spacing	.29	.25	.19	.17
216072	BH-311-2A	JRP	6	1-AA	Wires, 5.5	Single	26 AWG	.75	.65	.55	.49
2222133	209.	KEY	3	1-AA,CR2,CR123A	Solder lugs	Single	Metal contact	.29	.25	.19	.17
2222230	590	KEY	7	1-AA,CR2,CR123A,9V	PC mount	Single	Metal contact	.25	.17	.12	.10
2270007	12BH321PR	EAG	29	2-AA	PC mount	Single	.478" (12mm) spacing	1.25	1.15	.95	.85
216081	BH-321-2A	JRP	1	2-AA	Wires, 5.5	Single	26 AWG	.89	.79	.69	.59
216099	BH-321-4A	JRP	1	2-AA	Wires, 5.5	Single	w/ mnt. tabs, 26 AWG	.69	.59	.55	.49
216102	SBH-321-2A	JRP	8	2-AA	Wires, 5.5	Single	w/ cover, 26 AWG	1.49	1.25	1.09	.99
216120	SBH-321-1AS*	JRP	8	2-AA	Wires, 5.5	Single	w/ cover&sw, 26 AWG	1.95	1.75	1.59	1.45
2222176	5212	KEY	10	2-AA	Screwable	Single	Metal contact	.39	.35	.25	.19
216136	BH-331-A	JRP	4	3-AA	Wires, 5.5	Single	26 AWG	.95	.85	.69	.65
216144	SBH-331-AS*	JRP	11	3-AA	Wires, 6.0	Single	w/ cover&sw, 26 AWG	1.65	1.45	1.25	1.15
2207013	4XAA-2.1	JRP	2	4-AA	Plug, 5.0	Single	2.1mm plug, 22 AWG	2.49	2.25	1.95	1.75
216152	BH-341-2A	JRP	5	4-AA	Wires, 5.5	Single	26 AWG	1.19	1.09	.99	.89
105858	BH-PC §	JRP	13	4-AA	Wires, 5.5	Single	w/ conn., 26 AWG	.99	.89	.75	.65
216179	BH-343-1A	JRP	14	4-AA	Wires, 5.5	Dual	26 AWG	1.09	.95	.79	.69
2191883	12BH341-GR	EAG	15	4-AA	Snaps	Dual	—	1.19	1.09	.89	.79
216187	SBH-341-1AS*	JRP	5	4-AA	Wires, 6.0	Single	w/ cover&sw, 26 AWG	2.49	2.25	1.95	1.75
2095453	SBH-341-1A	JRP	5	4-AA	Wires, 5.5	Single	w/ cover, 26 AWG	1.49	1.35	1.19	.99
216223	BH-364-A	JRP	16	6-AA	Wires, 5.5	Single	26 AWG	1.69	1.49	1.35	1.19
2207021	6XAA-2.1	JRP	16	6-AA	Plug, 3.5	Single	2.1mm plug, 22 AWG	3.95	3.59	3.19	2.89
2228455	BH16AASF	MPD	15	6-AA	Snaps	Dual	—	1.19	.99	.85	.69
216240	BH-383-A	JRP	17	8-AA	Wires, 6.0	Dual	26 AWG	1.95	1.75	1.59	1.39
216267	BH-383-B	JRP	17	8-AA	Snaps	Dual	—	.99	.89	.79	.69
216259	BH-382-B	JRP	18	8-AA	Snaps	Dual	—	1.39	1.25	1.15	.99
216363	BH-242-1A	JRP	19	4-C	Wires, 5.5	Single	24 AWG	1.39	1.25	1.15	.99
216371	BH-111-1A	JRP	6	1-D	Wires, 5.5	Single	26 AWG	1.15	1.05	.89	.79
2243920	HHE BATTERY HOLDER	JRP	32	1-D	3/8" tab	Single	Modular	1.49	1.35	1.19	.99
216390	BH-121-1A	JRP	1	2-D	Wires, 5.5	Single	24 AWG	1.39	1.25	1.15	.99
216401	BH-142-A	JRP	19	4-D	Wires, 5.5	Single	24 AWG	1.09	.99	.89	.79
2128067	SBH-9VAS*	JRP	8	1-9V	Wires, 5.5	Single	w/ cover&sw, 26 AWG	1.49	1.35	1.19	1.05
2228447	BC9VPC	MPD	9	1-9V	PC mount	Single	Open holder, THM	1.49	1.35	1.19	.99
2234118	BH9VPC	MPD	33	1-9V	PC mount	Single	Open, snaps, THM	1.59	1.45	1.29	1.05
2207048	1X9V-2.1 CS	JRP	21	1-9V	Plug, 5.5	Single	2.1mm plug, 22 AWG	3.59	3.25	2.95	2.59
216427	BH-9V-A	JRP	20	1-9V	Wires, 5.5	Single	26 AWG	.89	.79	.69	.59
11280	A104-R	JRP	22	1-9V	Wires, 2.5	Single	26 AWG, snaps	.49	.45	.39	.35
2191891	12BH079-GR	JRP	23	1-9V	Screwable	Single	Metal holder, flat	.69	.65	.59	.49
105794	GBH-1009-R	JRP	23	1-9V	Screwable	Single	Metal holder, side	.49	.45	.39	.29
2191904	121-0426/IM-GR §	EAG	24	1-9V	Wires, 4.0	Single	w/ conn., 26 AWG	1.49	1.29	1.19	1.09
1949488	BAT-SNAP-4	JRP	25	1-9V	Wires, 3.5	Single	26 AWG, snaps	.49	.39	.35	.29
109154	BC6-R	JRP	25	1-9V	Wires, 5.5	Single	26 AWG, snaps	.49	.39	.35	.29
216452	SBS-IR-1-R	JRP	26	1-9V	Wires, 5.5	Single	26 AWG, snaps	.55	.45	.39	.35
101470	A102-R	JRP	25	1-9V	Wires, 10.0	Single	26 AWG, snaps	.49	.39	.35	.29
2207056	1X9V-2.1 SNAP	JRP	22	1-9V	Plug, 5.5	Single	2.1mm plug, 24 AWG	1.95	1.75	1.59	1.39
2203899	9VSNAP0B6	JRP	27	1-9V	Snaps	Single	PCB mount	.49	.45	.35	.29
2265735	12BH521PR	EAG	28	2-N (E90)	PC mount	Single	Release strap, THM	1.09	.99	.85	.75
2146231	BH-18650-2S	JRP	28	2-18650	Wires, 6.0	Single	26 AWG	1.95	1.75	1.59	1.39
2258646	AAA-BAT-054	ADT	29	1-0.79"Dia. max	2-pin SMT	Coin cell	CR2032 battery	.99	.89	.85	.75
236996	103	KEY	30	1-0.79"Dia. max	PC mount	Coin cell	CR2032 battery	1.69	1.39	1.19	1.05
38543	2S2325	JRP	30	1-0.85"Dia. max	PC mount	Coin cell	CR2325 battery	.79	.75	.65	.59
355434	17002-00603	JRP	31	1-0.79"Dia. max	PC mount	Coin cell	CR2325 battery	.75	.69	.59	.55

§ 2-pin connector * SW = switch

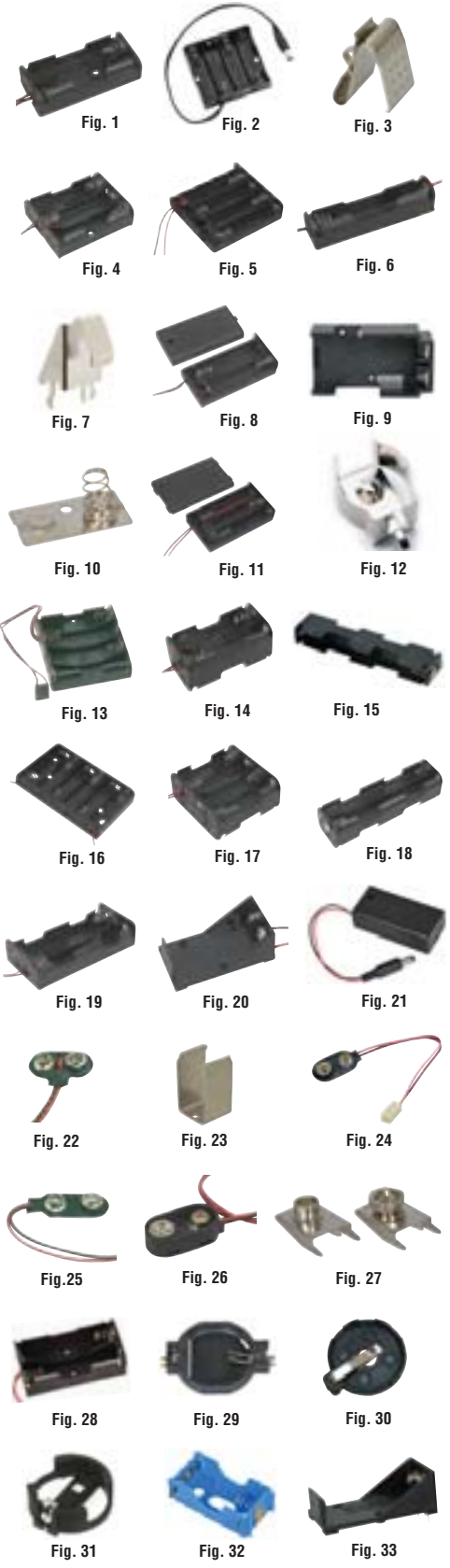

* ADT = Arndt | EAG = Eagle Plastics | JRP = Jameco ReliaPro | KEY = Keystone | MPD = Memory Protection Devices