

Weller® 40-Watt Soldering Station

- Lighted on/off switch
- Adjustable power from 5 watts to 40 watts
- 120V @ 60Hz
- Temp. is electronically controlled from 350°F to 850°F
- Illuminated on/off switch • Light weight pencil iron
- Size: 5.5"L x 4.5"W x 3.5"H • Weight: 1.9 lbs.



Includes: ST3 1/8" screwdriver tip and manual

Part No.	Mfr. Part No.	1	5
146595	WLC100	\$51.49	\$49.95
2082783	WCC104 Sponge	2.25	1.95

Velleman 50W Soldering Stations

- Manual temperature setting
- Electronic temperature control
- Power-on LED indication
- Input voltage: 115VAC
- Input power: 50VA max.
- Temp. range: 374°F to 896°F (2130626); 302°F to 842°F (2196801)
- Size: 7.3" x 4.0" x 3.5" • Weight: 1.6 lbs.



Includes: AC cord, iron stand and sponge

Part No.	Mfr. Part No.	Description	1	5
2196801	VTSS4NU	48W station	\$24.95	\$22.49
2130626	VTSS5U	50W station	21.95	20.49
2174864	BITS5	Conical tip	1.75	1.49

* Soldering/Desoldering Stations — Enter Web Code GEJ

Weller® 50-Watt Analog & Digital Display Soldering Stations

Innovative heater and sensor combination for quick heat-up and rapid temperature recovery.

- Tip temperature offset capability allows user to reset temperature readings to match tip size and style
- Wireless temp. lockout
- Auto power-down after 90 minutes of inactivity • Temp. accuracy: ±9°F
- Temperature range: 350°F to 850°F • ESD safe
- Size: 5.9"L x 4.5"W x 3.6"H • Weight: 4.0 lbs.



Includes: PES51 50W soldering iron with ETA tip, PH50 stand and sponge, and adjustment tool

Part No.	Mfr. Part No.	Description	1	5
217461	WES51	Analog	\$128.95	\$122.49
233533	WESD51	Digital	179.95	174.95
2082847	PES51	Soldering iron	46.95	44.95
2082783	WCC104	Replacement sponge	2.25	1.95

HAKKO 70-Watt Digital ESD-Safe Soldering Station

- Adjustable temp. control
- Temperature range: 122°F to 896°F (50°C to 480°C)
- Ceramic heating element and sensor ensures rapid heat-up temperature and fast thermal recovery
- Password protected temperature setting



Includes: iron stand, brass wool cleaner, sponge, AC cord, conical tip

Part No.	Mfr. Part No.	1	5
2174611	FX888D-29BY/P	\$105.95	\$101.95

* SMD Rework Stations — Enter Web Code NAT

Weller® 60-Watt ESD-Safe Soldering Station

- Temperature controllable: 600°F, 700°F or 800°F
- Closed-loop method of controlling maximum tip temperature to protect sensitive components
- Ferromagnetic temperature sensor, no adjustments necessary
- Quick disconnect plug for soldering iron and lighted on/off switch • Weight: 4.0 lbs.
- Impact-resistant plastic power unit
- Input: 120VAC @ 60Hz • Size: 5.9"L x 4.5"W x 3.6"H



Includes: Power unit, soldering pencil with PTA7 tip (below), stand and sponge

Part No.	Mfr. P/N	Description	1	5
170552	WTCPT	Solder station	\$179.95	\$174.95
192161	TC201T	Replacement iron	97.95	94.95
192188	PTA7	Screwdriver tip 700°F	3.95	3.75
192196	PTA8	Screwdriver tip 800°F	3.95	3.75

60 & 80W Lead-Free Digital Soldering Stations

Grounded Soldering Tip

- 150°C to 480°C (302°F to 896°F)
- Fully grounded
- Insulated ceramic heating element for rapid heat-up and heat recovery
- Heater insulation exceeds 100MΩ
- Zero voltage circuitry eliminating high voltage spike and magnetic field generation
- Size: 4.1"L x 3.5"W x 3.5"H • Weight: 2.5 lbs.



Includes: Manual, soldering iron with 1/32" tip, stand, tip cleaner and sponge

156814: Sharp conical chisel tip

156822: Conical chisel tip

Part No.	Mfr. Part No.	Description	1	5
2174733	LF-389D	60W station	\$59.95	\$53.95
2193782	LF-399D	80W station	64.95	58.95
156814	XYB01	1/32" tip	3.95	3.59
156822	XYB04	1/16" tip	3.95	3.59
134631	SP715	Sponge	2.95	2.59

100-Watt Soldering & Desoldering Station with Fume Extractor

- Input voltage: 110-120VAC @ 60Hz
- Soldering iron: 32VAC/100W 150°C to 480°C (302°F to 896°F) • Size: 4.2"W x 3.6"D x 5.0"H
- Desoldering iron: 32VAC/100W 300°C to 450°C (572°F to 842°F) • Weight: 28 lbs.
- Heater and sensor failed detection and temperature lockout features • Digital temperature readout

Includes: 307A soldering iron, DIA100 desoldering iron, soldering stands, fume extractor, AX205 micro cutting pliers, 5-piece high precision tweezers, filter and cleaning accessories, AC power cord and manual

Part No.	Description	1	5
2099198	LF-8800 station	\$299.95	\$284.95
127634	Desolder tip 1.0mm	5.95	5.49
2095509	Desolder tip 1.2mm	7.95	7.19
2095517	Desolder tip 1.5mm	7.95	7.19

120-Watt ESD Safe, Digital Lead-Free Soldering Station

- Input: 220-240VAC @ 50Hz, 100-120VAC @ 60Hz
- 0-volt. switching circuitry
- Precise temp. regulation
- Heater/sensor failure detection
- Temperature range: 200°C to 500°C (392°F to 932°F)
- PTC sensor for quick heat-up time
- Temp lock out feature, password protected
- High-quality sensor and heat transfer technology
- Aluminum housing • Size: 4.4"W x 6.2"H x 5.4"D



Includes: Separate iron holder with brass tip cleaner, soldering tip and AC cord

Part No.	Mfr. Part No.	Wattage	1	5
2181503	LF-3200	120W	\$129.95	\$119.95

Weller® Soldering Tips


ST Series: Replacement tips for WLC100, WP25, WP30, WP35 soldering irons and stations.

Precision ground copper tips plated with iron, nickel and chromium

* Web Code: NAB

ET Series: Replacement tips for PES51 soldering pencil (P/N 2082847). Contains a sensor hole in base of tip fitted with a stainless steel liner

MT Series: Replacement tips for SP23 and SP23D soldering irons. Solid copper tips, nickel-plated and tinned

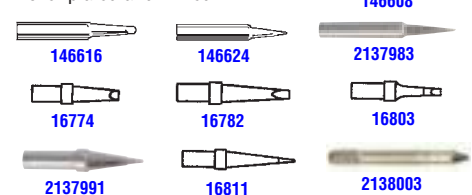

Part No.	Mfr. P/N	Description	1	10
192145	ST6	Screwdriver tip 1/32" ...	\$3.95	\$3.69
146608	ST1	Screwdriver tip 1/16" ...	3.69	3.49
2137975	ST2	Screwdriver tip 1/10" ...	3.95	3.69
146616	ST3	Screwdriver tip 1/8" ...	4.95	4.75
146624	ST7	Conical tip 1/32" ...	3.95	3.69
2137983	ST5	Single flat tip 1/32" ...	3.95	3.69
16774	ETA	Screwdriver tip 1/16" ...	4.49	3.95
2138020	ETH	Screwdriver tip 1/32" ...	4.19	3.75
16782	ETJ	Long screwdriver tip 1/32" ...	4.49	3.95
16803	ETR	Narrow screwdriver tip 1/16" ...	4.49	3.95
2137991	ETP	Conical tip 1/32" ...	4.49	3.95
16811	ETS	Long conical tip 1/64" ...	4.49	3.95
2138011	ETO	Long conical tip 1/32" ...	4.49	3.95
2138003	MT1	Cone-shape tip 1/8" ...	4.95	4.75

CHIPQUIK® SMD Removal Kit

- Potential damage to printed circuit boards is eliminated
- 2.5" of CHIPQUIK® material removes 1250-1500 SMD pins

Includes: 2.5 ft. removal alloy material, 1cc syringe rework paste flux, alcohol pads for cleaning & complete instructions

Part No.	Description	1	5
141305	SMD removal kit	\$14.49	\$13.95

* Soldering Tips & Sponges — Enter Web Code NAB

* Solder — Enter Web Code ABD

* For additional products, availability and specifications visit Jameco.com and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at www.Jameco.com