

# D-Sub Connectors, Contacts, Hoods & Hardware

3 LEVELS OF SAVINGS  
 NAME BRANDS HOUSE BRANDS SPECIAL BUY

JAMECO ValuePro



## D-Subminiature Connectors (Continued)



### IDC Ribbon Cable

- Contact material: phosphor bronze 109226
- Terminates with standard D-type connectors

\* Web Code: MAP

Part No.	Manufacturer	Product No.	Shell	Cont.	Gender	1	10	100
109226	ValuePro	1007-9P/M-R	Metal	9	M	\$2.09	\$1.89	\$1.65
12504	ValuePro	1007-9P/P-R	Plastic	9	M	1.75	1.49	1.25
109218	ValuePro	1007-9S/M-R	Metal	9	F	2.09	1.89	1.65
117382	ValuePro	1007-15P/M-R	Metal	15	M	2.25	1.95	1.75
116012	ValuePro	1007-15SM-R	Metal	15	F	1.95	1.75	1.49
2235831	Kobiconn	156-1625	Metal	25	M	2.25	1.95	1.75
115984	ValuePro	1007-25P/M-R	Metal	25	M	2.49	2.25	1.95
115976	ValuePro	1007-25S/M-R	Metal	25	F	2.65	2.39	2.09

\* Additional D-Sub Connectors — Enter Web Code DSB

### IDC Ribbon Cable (Continued)

Part No.	Manufacturer	Product No.	Shell	Cont.	Gender	1	10	100
2162708	CWI	CWR-180-373-003W/O#	Metal	37	M	\$.69	\$.59	\$.49
115992	ValuePro	1007-37P/M-R	Metal	37	M	2.95	2.65	2.39
116004	ValuePro	1007-37S/M-R	Metal	37	F	2.95	2.65	2.39

# Without strain relief

### Crimp-Type


\* Web Code: UBR

Part No.	Manufacturer	Product No.	Contacts	Gender	1	10	100
73189	Steren	500-010	9	M	\$.69	\$.59	\$.49
73197	Steren	500-110	9	F	.69	.59	.49
38789	ValuePro	500-027	25	M	.89	.75	.65
38771	Steren	500-1N27	25	F	.89	.75	.65



## D-Sub Solder & Crimp Contacts

\* Web Code: JDC

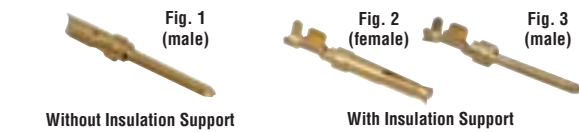

### Male Crimp Contact – Fig. 1

Part No.	Mfr.	Product No.	AWG	1	10	100
234982	TE Conn.	66570-3	28-24	\$.39	\$.35	\$.29

### Female Crimp Contacts – Fig. 2

Order in multiples of 10

Part No.	Mfr.	Product No.	AWG	10	100	1000
43369	Steren	500-155	28-24	\$.17	\$.15	\$.12
185412	ValuePro	1006-PS	28-24	\$.05	\$.04	\$.03
223298	TE Conn.	66504-9	24-20	\$.22	\$.19	\$.15
223255	TE Conn.	1-66504-0	24-20	\$.19	\$.15	\$.12

\* Terminal Blocks — Enter Web Code XBD

\* D-Sub Hoods — Enter Web Code DAB

### Male Crimp Contacts— Fig. 3

\* Order in multiples of 10

Part No.	Mfr.	Product No.	AWG	1	10	100
185421	ValuePro	1006-PP	28-24	\$.07	\$.05	\$.04
43377	Steren	500-055	28-24	\$.17	\$.15	\$.12
223108	TE Conn.	66507-9	28-24	\$.29	\$.25	\$.19
223191	TE Conn.	66506-9	24-20	\$.19	\$.15	\$.12

### Female Solder Contact (M39029/63-368) – Fig. 4

• Machined

Part No.	Mfr.	Product No.	1	10	100
449351	TE Conn.	205090-1	\$.55	\$.49	\$.45

### Male Solder Contact (M39029/64-369) – Fig. 5

• Machined

Part No.	Mfr.	Product No.	1	10	100
449342	TE Conn.	205089-1	\$.49	\$.45	\$.39

JAMECO ValuePro

## Hardware for D-Sub Connector Hoods



\* Web Code: PAM



### 4-40 Hex Jack Screw Sets

- 16548: 4-40 Hex (.187" W x .187" H x .315" L thread) jack screw, nut & washer set – plating B
- 2100283: 4-40 Hex (.187" W x .187" H x .315" L thread) jack screw with lock washer – plating C
- 2185766: 4-40 Hex (.187" W x .187" H x .356" L thread) jack screw, nut & washers screws & clip – plating A

\* Order in multiples of 10

Part No.	Mfr.	Prod. No.	Plating*	1	10	100
16548	ValuePro	14-522	B	\$.75	\$.59	\$.55
2100283	ValuePro	JS4403LW	C	\$.19	\$.15	\$.12
2185766	Arndt	17-768	A	\$.59	\$.55	\$.45

### 4-40 x .187"/.195" Standoffs

Part No.	Mfr.	Length	Plating*	1	10	100
175636	ValuePro	.187"	B	\$.49	\$.45	\$.39
102796	ValuePro	.235"	A	\$.29	\$.25	\$.19

### 4-40 x .187" Jack Screws

Part No.	Mfr.	Length	Plating*	1	10	100
2228949	Molex	.250"	A	\$.29	\$.25	\$.19
169931	ValuePro	.275"	A	\$.25	\$.19	\$.15
102816	ValuePro	.437"	B	\$.39	\$.35	\$.29
108987	ValuePro	.515"	A	\$.45	\$.39	\$.35

### 4-40 Slotted D-Sub Plastic Thumbscrew

Part No.	Mfr.	Length	Plating*	1	10	100
125015	ValuePro	1.65"	A	\$.25	\$.15	\$.12

### 4-40 Slotted D-Sub Knurled Thumbscrews

Part No.	Mfr.	Length	Plating*	1	10	100
2186216	ValuePro	1.54"	B	\$.29	\$.25	\$.19
2179438	SPC (2pk)	2.83"	B	\$.25	\$.19	\$.15

\* Plating – A: Zinc, clear chromate B: Chrome C: Chrome with lock washer

More Hardware on pages 77-78

JAMECO ValuePro

## D-Sub Connector Hoods

\* Web Code: DAB



- Use with D-sub solder cup and housing style connectors (hardware included)
- D Series:** Plastic hood with strain relief (gray)
- MD Series:** Metal coated plastic hood w/ strain relief
- MH Series:** Die-cast metal hood with strain relief

Part No.	Mfr.	Product No.	Pins	1	10	100
15722	ValuePro	DB9H	9	\$.75	\$.59	\$.55
25620	Steren	MDB9H	9	\$.85	\$.79	\$.69
2185740	Amphenol	17-1587-3	9	\$.79	\$.69	\$.59
147741	ValuePro	MHDB9*	9	1.85	1.59	1.39
15019	ValuePro	DA15H	15	\$.95	\$.79	\$.69
25567	ValuePro	MDA15H	15	\$.99	\$.85	\$.65
15086	ValuePro	DB25H	25	\$.75	\$.65	\$.55
25604	ValuePro	MDB25H	25	1.05	\$.89	\$.75
15107	ValuePro	MHDB25	25	2.25	1.95	1.75

\* No strain relief

JAMECO ValuePro

## Slim-Line D-Sub Gender Changers/Coupler

For Confined Applications!

\* Web Code: YAB

- Captive locking screw (male)
- Captive locking nut (female)
- Tin plated shells
- Grounding tangs (male)
- Width: 0.69"




Part No.	Description	1	10	100
18498	9-pin male to male	\$2.09	\$1.89	\$1.65
18489	9-pin female to female	1.95	1.75	1.49
119320	15-pin female to female HD	4.95	4.49	3.95
18420	25-pin female to female	2.65	2.39	2.09



## D-Sub Crimping Tool

- Heavy-duty metal tool with cutter and insulated handles
- For computer pins & sockets, D-sub 26-28 AWG wire; butt-insulated connectors, 22-26 AWG wire; telephone spade lugs, 22-26 AWG wire and non-insulated connectors, 20-22 AWG & 14-18 AWG
- Coiled spring return • Size: 7.3" L x 1.5" W

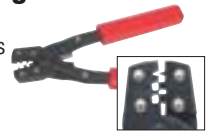

\* Web Code: GBU

Part No.	Mfr.	Part No.	1	5	25
99443	HT202A		\$9.95	\$8.95	\$7.95

More Tools on pages 118-121