


# Headers, Housings & Crimp Terminals

3 LEVELS OF SAVINGS  
**NAME BRANDS** **HOUSE BRANDS** **SPECIAL BUY**



JAMECO ValuePro

## .100" (2.54mm) Straight and Right Angle Friction Lock Headers

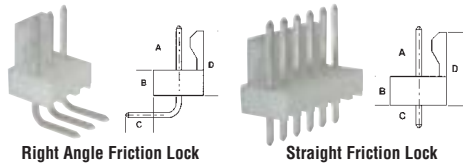

879588



\* Web Code: GBN

### .100" (2.54mm) Right Angle Friction Lock Headers

\* Order in multiples of 10

Part No.	Mfr.	Product No.	Pos.	Size (A"xB"xC"xD")	Plating	1	10	100
233437	Molex	22-05-3021	2	.26 x .13 x .14 x .32	Tin	..... *	\$ .19	\$ .15
233445	Molex	22-05-3031	3	.26 x .13 x .14 x .32	Tin	.....	.25	.19
233453	Molex	22-05-3041	4	.26 x .13 x .14 x .32	Tin	.....	.29	.25

### .100" (2.54mm) Straight Friction Lock Headers

\* Order in multiples of 10

Part No.	Mfr.	Product No.	Pos.	Size (A"xB"xC"xD")	Plating	1	10	100
232266	Molex	22-23-2021	2	.30 x .13 x .14 x .32	Tin	..... *	\$ .15	\$ .09
879588	Molex	22-29-2021	2	.30 x .13 x .14 x .46	Gold	.....	.29	.25
232274	Molex	22-23-2031	3	.30 x .13 x .14 x .32	Tin	..... *	.22	.19
232282	Molex	22-23-2041	4	.30 x .13 x .14 x .32	Tin	.....	.29	.25
232291	Molex	22-23-2051	5	.30 x .13 x .14 x .32	Tin	.....	.29	.25
348082	ValuePro	641215-5	5	.30 x .10 x .14 x .31	Gold	.....	.29	.25
232303	Molex	22-23-2061	6	.30 x .13 x .14 x .32	Tin	.....	.29	.25
232320	Molex	22-23-2081	8	.30 x .13 x .14 x .32	Tin	.....	.39	.35
232346	Molex	22-23-2101	10	.30 x .13 x .14 x .32	Tin	.....	.49	.45

## molex KK® Series .100" (2.54mm) Crimp Terminals

- Current: phosphor bronze – 4.0A max.; brass – 2.5A max.
- Insulation range: 0.062" (1.58mm) diameter max.
- Accommodates 22 to 30 AWG
- Material: 736501/234923/234931: brass; 736595/462969/463005: phosphor bronze

\* Web Code: JCT



### Bulk Packaged

Order in multiples of 10

Part No.	Mfr.	Part No.	Plating	10	100	1000
736501	08-50-0113	Tin*	.....	\$ .06	\$ .05	\$ .04
234923	08-50-0114	Tin	.....	.07	.06	.05
234931	08-55-0102	15µ" gold	.....	.12	.10	.08
736595	08-52-0123	Tin	.....	.12	.09	.08
462969	08-65-0805	Tin (cat ear)	.....	.12	.10	.08
463005	08-65-0816	15µ" gold	.....	.22	.19	.15

\* Cut tape packaging

## molex .100" (2.54mm) Pitch SL™ Wire-to-Board Crimp Housing

### Single Row, Version G, Positive Latch

- Housing: black glass filled polyester, UL94V-0

\* Web Code: VDD



Order in multiples of 10

Part No.	Mfr.	Part No.	Pos.	10	100
884328	50-57-9402	2	.....	\$ .25	\$ .15

### Female Crimp Terminals

741685



Order in multiples of 10

Part No.	Mfr.	Part No.	AWG	Plating	10	100
741685	16-02-0103	22-24	15µ" gold	..	\$ .09	\$ .08
741677	16-02-0086	22-24	Tin	.....	.06	.05

## D-SUB TERMINAL CRIMPERS

 
- With cutter
- Cushioned grip



99443

Part No.	Mfr.	Part No.	AWG	Price
99443	HT202A	26-28	.....	\$9.95
159266	HT213	20-28	.....	15.95

## JAMECO ValuePro .118" (3.00mm) Micro-Fit Crimp Terminals



- Material: phosphor bronze, tin

\* Web Code: UBW

Order in multiples of 10

Part No.	Mfr.	Product No.	Fig.	AWG	10	100
337720	ValuePro	43030-0007	1	20-24	\$ .12	\$ .09
883093	Molex	43030-0007	1	20-24	.09	.07
337746	ValuePro	43030-0010	1	20-24	.12	.07
337762	Adam Tech	43031-0007	2	20-24	.07	.06

## Hand Tools for Mini-Fit Jr.™

- 304928: Crimp tool wire range from 14-24 AWG, 8.5"L
- 304936: Extraction tool, 3.5"L
- 308030: Cuts 14-24 AWG, 8.3"L
- 227491: Cuts 10-20 AWG, 8.3"L

\* Web Code: GBU



Part No.	Mfr.	Mfr. Part No.	1	5
304928	Molex	63811-1000	....	\$54.95 \$50.95
304936	Molex	11-03-0044	.....	20.95 19.95
308030	GC/Waldom	W-HT-1919*	.....	15.95 14.49
227491	GC/Waldom	W-HT-1921*	.....	15.95 14.49

\* Strips 10-20 AWG wire

## Tools for Micro-Fit Connectors



Part No.	Cross Ref. No.	Description	Length	1	5
338678	HT-225D	Crimp	8.25"	\$25.95	\$23.49
338669	11-03-0043	Extraction	3.0"	12.95	11.49

\* Automotive Housings & Terminals — Web Code QZX

## YAZAKI YESC Housings

- Automotive applications
- Wire to wire/wire to device
- HPA – heat resistance nylon
- Operating temperature: -40°C to +100°C

2232702

Part No.	Mfr.	Part No.	Description	1	10	50
2232702	7282-5567-401	12 pos. M	.....	\$4.95	\$4.49	\$3.95
2232737	7283-5916-401	12 pos. F	.....	4.95	4.49	3.95
2232729	7283-5643-402	13 pos. F	.....	5.95	5.39	4.79

1,2 Use with corresponding terminals on the right

## TE MATE-N-LOCK Housings

- Automotive applications
- Pb free RoHS

527056

525608

\* Web Code: MQZ

Part No.	Mfr.	Part No.	Description	1	10	100
527056	1-480318-0	Female 2 pos.	.....	\$ .25	\$ .15	\$ .12
525608	770017-1	Male 2 pos.	.....	.89	.75	.65

1 Use with corresponding terminals below

## MATE-N-LOCK Crimp Terminals

- Automotive applications
- 600 voltage rating

† Material/plating:

- A: Phosphor bronze/pre-tin
- B: Copper alloy/tin
- C: Copper/tin
- D: Brass/gold

\* Web Code: MQZ

Part No.	Mfr.	P/N	M/F	Material†	AWG	1	10	100
2232665	770004-3	1	F	A	10-12	\$ .29	\$ .19	\$ .17
1977403	770003-3	M	A	10-12	..	.29	.19	.17
2232673	66740-7	F	C	12-16	.....	3.95	3.49	2.95
2231128	1-66255-1	M	B	12-16	.....	1.19	.99	.85
2232681	1326032-5	F	B	14	.....	.35	.29	.19
2231101	1326031-5	M	B	14	.....	.25	.19	.17
2231110	1326031-0*	M	B	14	.....	.25	.19	.17
967983	66100-9	F	D	16-18	..	.39	.35	.29
2232690	1326032-1	F	B	22	.....	.29	.25	.19

1 Use with corresponding housings above \* Reel

## YESC Crimp Terminals

- Material/plating: copper alloy/tin
- Automotive applications
- Operating temperature: -40°C to +100°C
- Isolation resistance: 500VDC, 20MΩ
- Voltage drop: 10mV



Part No.	Mfr.	Part No.	Descrip.	AWG	1	10	100
2231275	7114-4112-02	1,2	2.8mm M	14	\$ .25	\$ .19	\$ .15
2231241	7114-4120-02	2	6.3mm M	14	..	.25	.19
2232411	7114-4121-02	2	6.3mm M	14	.....	.25	.19
2231224	7116-4112-02	1,2	2.8mm F	14	.....	.25	.09
2231283	7114-4111-02	1,2	2.8mm M	16-18	.....	.25	.19
2231232	7116-4111-02	1,2	2.8mm F	16-18	.....	.25	.09
2231259	7114-4110-02	1,2	2.8mm M	20-22	.....	.25	.19
2231267	7116-4110-02	1,2	2.8mm F	20-22	.....	.25	.09

1,2 Use with corresponding housings on the left