

# DIN, USB & CPC Connectors & Sockets

## JAMECO ValuePro Mini DIN & DIN Panel Mount Female Sockets

- With solder lugs
- Metal body



**\*Web Code: FAB**

Part No.	Product No.	Fig.	Description	1	10	100
2235971	DINJ3	1	3-pin DIN	\$1.95	\$1.79	\$1.59
2272743	DINJ4	1	4-pin DIN	2.09	1.89	1.69
2205501	57HB5F*	1	5-pin DIN	1.89	1.69	1.39
15844	DINJ5	1	5-pin DIN	2.09	1.89	1.65
15852	DINJ6	1	6-pin DIN	2.09	1.89	1.65
15861	DINJ8	1	8-pin DIN	2.25	1.95	1.85
2272791	MD-30SN	1	3-pin mDIN	1.35	1.19	1.09
2205510	MD-40SN	1	4-pin mDIN	1.49	1.35	1.19
2272799	MD-50SN	1	5-pin mDIN	1.69	1.49	1.29
2272807	MD-60SN	1	6-pin mDIN	1.79	1.59	1.39
2272815	MD-80SN	1	8-pin mDIN	1.95	1.75	1.49
2272687	MD-30CV	2	3-pin mDIN	1.59	1.45	1.25
2272711	MD-40CV	2	4-pin mDIN	1.69	1.55	1.29
2272695	MD-50CV	2	5-pin mDIN	1.75	1.59	1.35
2246531	A170718LH†	2	6-pin mDIN	1.49	1.25	1.09
2076762	MD-60CV	2	6-pin mDIN	1.79	1.59	1.39
2272703	MD-80CV	2	8-pin mDIN	1.95	1.75	1.49
2182961	M14HNV✓	3	M14x1.0 nut	.49	.45	.39

\*.04" recessed frame †w/ plastic hex nut ✓ Metal hex nut for fig. 2 mDIN

## Mini DIN & DIN PC Mount Female Sockets

- Set back: 0.5"

**\*Web Code: DMS**



**Shielded, Right Angle mini DIN**

Part No.	Product No.	Description	1	10	100
140791	MD-40SM	4-pin mini DIN	\$1.15	\$ .99	\$ .89
119475	MD-60SM	6-pin mini DIN	1.25	1.09	.99
207722	MD-80SM	8-pin mini DIN	1.39	1.19	1.05

**Unshielded, Right Angle DIN**

Part No.	Product No.	Description	1	10	100
2272767	SDS-30J	3-pin DIN	\$1.19	\$ .99	\$ .85
2178531	SDS-40J	4-pin DIN	1.05	.89	.79
29399	SDS-50J	5-pin DIN	1.05	.89	.75
2272783	SDS-60J	6-pin DIN	1.29	1.15	.99
29410	SDS-80J	8-pin DIN	1.59	1.45	1.29

## Amphenol® RF Military Connectors

- Solder terminals • Aluminum alloy
- Straight plug or Jamnut receptacle
- Military spec: Mil-C-26432-1
- Electrically conductive bayonet lock connector • Hermetic sealed
- General duty back shell • Pin and socket contacts

Part No.	Mfr. Part No.	1	10	25
2231021	PT06A-14-5S	\$19.95	\$17.95	\$15.95
2232403	PT06E-18-32P	29.95	27.95	25.95
2231013	PT07A-12-10P	19.95	17.95	15.95

## TE CPC Circular Plastic Connectors

**Series 1 — Standard density, signal and low-current applications**

- Accepts type III+, high-current type II and subminiature coax contacts
- Voltage rating: 600V (UL)

### Receptacles — Panel Mount

**\*Web Code: WBK**

Part No.	Mfr. P/N	Size/Pos.	Gender	Mating Connector	1	10
495218	206430-1	11-4	Reverse	495091	\$3.29	\$2.95
495162	206061-1	11-4	Standard	495082	3.49	3.19
495234	206705-1	13-9	Standard	495103	3.49	3.19
421382	206036-1	17-16	Standard	495322	3.49	3.19



### Plugs — Free Hanging

Part No.	Mfr. P/N	Size/Pos.	Gender	Mating Connector	1	10
495091	206429-1	11-4	Reverse	495218, 839501, 495226	\$3.95	\$3.59
495082	206060-1	11-4	Standard	495162, 839324, 495197	3.25	2.95
495103	206708-1	13-9	Standard	919447, 495234, 495242	4.25	3.89
495031	206044-1	17-14	Reverse	750311, 495146	4.49	3.95
495322	206037-1	17-16	Standard	421382, 495314	4.49	3.95

\*For additional products, availability and specifications visit [Jameco.com](http://Jameco.com) and enter the Web Code in the product search box

3 LEVELS OF SAVINGS  
 NAME BRANDS HOUSE BRANDS SPECIAL BUY

Order by Phone at 1-800-831-4242 or Online at [www.Jameco.com](http://www.Jameco.com)

## ADAM TECH Displayport Receptacle

Displayport receptacles are royalty free products that can be used in any application where an HDMI connection was previously required.

**\*Web Code: DPP**



Part No.	Mfr. Part No.	Description	Type	Mounting Style	1	10	100
2114247	MDPC-S-RA	Mini displayport, receptacle, right angle	DIP	Through hole	\$2.49	\$2.25	\$1.95

## ADAM TECH USB-A & B 1.0 & 2.0 Female Connectors

**\*Web Code: DAZ**



Part No.	Mfr.	Product No.	Description	1	10	100
2096181	Adam Tech	USB-A-S-RA	USB-A, right angle	\$.55	\$.49	\$.45
2097011	Adam Tech	USB-A-S-VT	USB-A, vertical	.55	.49	.45
2234142	OST	USB-A1VSW6-S	USB-A, vertical	.49	.45	.39
161024	ValuePro	1040	USB-A 1.0	.89	.79	.69
2076551	Kobiconn	UAR64-8W2100	USB-A 2.0, dual port	.69	.59	.29
2096261	Adam Tech	MUSB-B5-S-RA-SMT	Mini USB-B, right angle, surface mount	.99	.89	.75
2096245	Adam Tech	USB-B-S-RA	USB-B, right angle	.45	.39	.35
230958	Adam Tech	USB-B-S-RA-WT	USB-A 2.0, right angle, white insulator	.99	.89	.79

## JAMECO ValuePro DIN Plugs

**\*Web Code: DAV**



- Solder barrels w/ strain relief
- See pg 42 for cable

Part No.	Pins	Type	1	10	100
2272719	3	Mini DIN plug	\$1.39	\$1.25	\$1.09
2272727	4	Mini DIN plug	1.45	1.29	1.15
2272735	5	Mini DIN plug	1.49	1.35	1.19
142262	6	Mini DIN plug	1.29	1.09	.89
111878	8	Mini DIN plug	1.59	1.45	1.29
2272759	3	DIN plug	1.25	1.09	.99
2272751	4	DIN plug	1.29	1.15	.95
15879	5	DIN plug	1.39	1.19	1.05
15887	6	DIN plug	1.39	1.19	1.05
2178638	6	DIN plug*	1.49	1.25	1.09
15895	8	DIN plug	1.49	1.25	1.09

\*Nickel plated diecast handle

## TE Circular Cable Clamps

Provides strain relief and can be used in all series receptacles and plugs.

- Material: thermoplastic black, UL94V-0 rated (plastic); zinc alloy (metal)

**\*Web Code: OLI**




Part No.	Mfr. Part No.	Shell Size	Cable OD (max.)	1	10
494039	206062-6	11*	.329"	\$4.49	\$3.95
745441	206062-4	11†	.329"	3.59	3.29
494055	206966-1	13	.453"	4.49	3.95
494063	206070-1	17	.453"	4.49	3.95
749812	206070-8	17	.453"	2.95	2.75

Screw length: \*.375" †.500"

## TE CPC Contacts

**Type III+ Snap-In Crimp Pins with Retention Spring**

**\*Web Code: LEF**

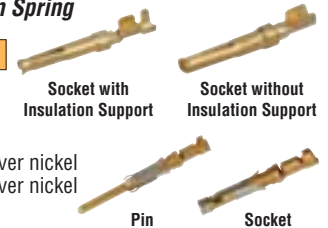

- Finish:
  - A: 30µ" gold over nickel
  - B: 15µ" gold over nickel
  - C: Tin-lead
- Crimp type
- Contact body: brass or phosphor bronze

Part No.	Mfr. P/N	AWG	Finish	Type	1	10
526441	1-66361-1	18-14	A	Pin	\$.95	\$.85
526424	66180-1*	18-16	A	Pin	.99	.89
526432	66181-1	18-16	A	Socket	1.59	1.45
526459	66103-3	24-20	B	Pin	.65	.55
526563	1-66103-5	24-20	C	Pin	.55	.49
526379	66105-3	24-20	B	Socket	.69	.65
526504	1-66105-6	24-20	C	Socket	.65	.59

\*Solder type

### Size 20DF Contacts

- A: 30µ" gold over nickel B: gold flash over nickel
- Contact body: brass

Part No.	Mfr. P/N	AWG	Finish	Type	10	100
223298	66504-9	24-20	A	Socket	\$.22	\$.19
223255	1-66504-0	24-20	B	Socket	.19	.15