

Pushbutton Switches




Pushbutton Switches

NEW
MARKED IN PINK

For additional Pushbutton Switches, visit Jameco.com and use Web Code

★ Web Code: **UBU**

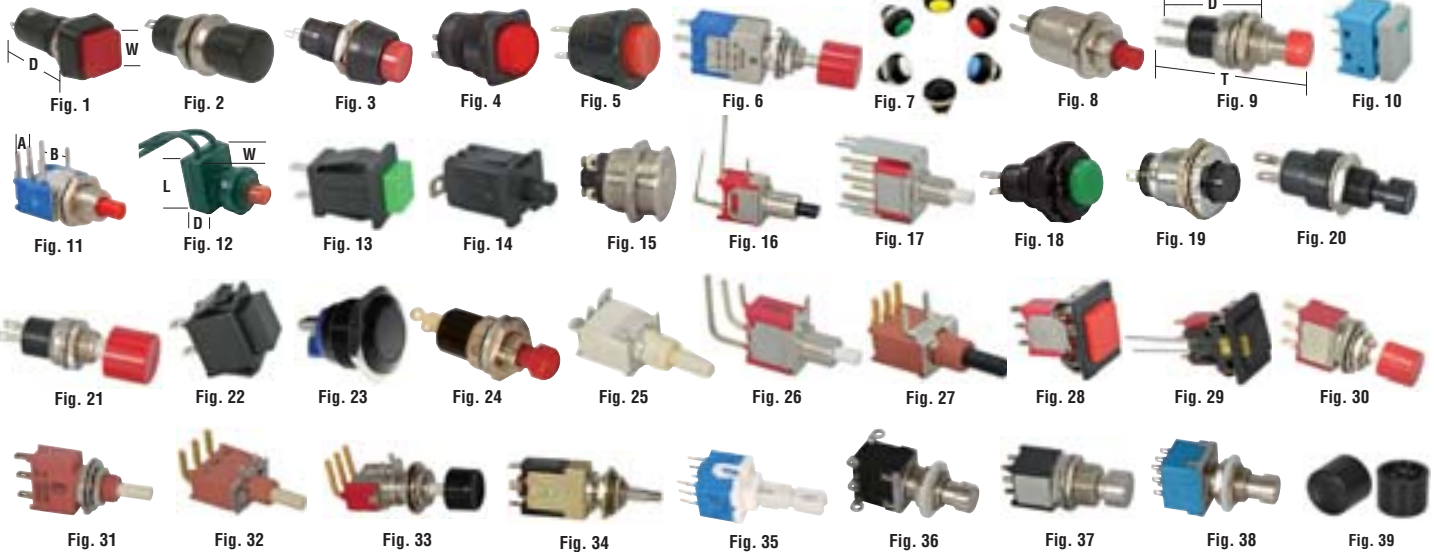

Part No.	Manufacturer	Product No.	Fig.	Pins	Contact Form () Momentary	Contact Rating (A @ VAC)	Mounting Hole Dia.	Dimension (L" x W" x D")	Lead Spacing	Terminal Type	Button Color	Pricing		
												1	10	100
315492	ValuePro	R13-23B-B	1	2	SPST off-on	3 @ 125	.480"	1.13 (D) x 1.53 (T)	.20"	Solder lugs	Black	\$1.19	\$1.09	\$.99
315484	ValuePro	R13-23B-R	1	2	SPST off-on	3 @ 125	.480"	1.13 (D) x 1.53 (T)	.20"	Solder lugs	Red	1.19	1.09	.99
315521	ValuePro	R13-23B-Y	1	2	SPST off-on	3 @ 125	.480"	1.38 (D) x 1.53 (T)	.18"	Solder lugs	Yellow	1.19	1.09	.89
2228640	ValuePro	GP9-4A-R	2	2	SPST off-on	3 @ 125	.480"	.98 (D) x 1.56 (T)	.20"	Solder lugs	Red	1.49	1.25	1.09
2228631	ValuePro	GP9-4A-K	2	2	SPST off-on	3 @ 125	.480"	.98 (D) x 1.56 (T)	.20"	Solder lugs	Black	1.75	1.49	1.25
164494	ValuePro	R13-84B	3	2	SPST off-on	3 @ 125	.406"	.59 (D) x 1.2 (T)	.175"	Solder lugs	Red	2.49	2.25	1.95
2171145	Mountain Switch	DS-450-RED	3	2	SPST off-on	3 @ 125	.406"	.59 (D) x 1.2 (T)	.175"	Solder lugs	Red	3.95	3.59	3.29
2267871	Mountain Switch	107-3038-EVX	1	2	SPST off-on	3 @ 125 & 1 @ 250	.393"	.393 Dia. x .77 D	.181"	Solder lugs	Black	2.95	2.59	2.29
2267863	Mountain Switch	107-3036-EVX	1	2	SPST off-on	3 @ 125 & 1 @ 250	.393"	.393 Dia. x .77 D	.181"	Solder lugs	Red	2.95	2.59	2.29
2267831	Mountain Switch	107-3028-EVX	3	2	SPST off-on	3 @ 125 & 1 @ 250	.393"	.393 Dia. x .77 D	.181"	Solder lugs	Silver	2.95	2.59	2.29
2267847	Mountain Switch	107-3030-EVX	3	2	SPST off-on	3 @ 125 & 1 @ 250	.393"	.393 Dia. x .77 D	.181"	Solder lugs	Silver#	2.95	2.59	2.29
2267855	Mountain Switch	107-3033-EVX	1	2	SPST off-on	3 @ 125 & 1 @ 250	.393"	.393 Dia. x .77 D	.181"	Solder lugs	Silver	2.95	2.59	2.29
2268079	ValuePro	R13-23B-05-BB	1	2	SPST off-on	3 @ 125 & 1.5 @ 250	.480"	.47 Dia. x 1.1 (T)	.181"	Solder lugs	Blue	1.95	1.75	1.49
2269687	ValuePro	R13-23B-05-BL	1	2	SPST off-on	3 @ 125 & 1.5 @ 250	.480"	.47 Dia. x 1.1 (T)	.181"	Solder lugs	Blue	1.95	1.75	1.49
2268191	ValuePro	R13-23B-05-BW	1	2	SPST off-on	3 @ 125 & 1.5 @ 250	.480"	.47 Dia. x 1.1 (T)	.181"	Solder lugs	White	1.95	1.75	1.49
2269647	ValuePro	R13-511B-05-B	4	2	SPST off-on	3 @ 125 & 1.5 @ 250	.50"L x .45"W	.50 L x .93 (T)	.25"	Solder lugs	Black	2.95	2.59	2.29
2268311	ValuePro	R13-508AL-05-BRR-L3	4	2	SPST off-on	3 @ 125 & 1.5 @ 250	.63"L x .59"W	.63 x .59 x .94	.24"	Solder lugs	Black	2.95	2.59	2.29
2268263	ValuePro	R13-523BL-05-BRRL1	5	2	SPST off-on	3 @ 125 & 1.5 @ 250	.63"L x .59"W	.63 Dia. x .75 (T)	.19"	Solder lugs	Red illum.	3.95	3.59	3.29
2269639	ValuePro	PA101A1-B/BL	6	2	SPST off-on	6 @ 125 & 3 @ 250	.240"	.51 x .32 x .87	.18"	Solder lugs	Black	1.95	1.75	1.49
2217588	Seeed Studio	TEM12121B	7	2	SPST off-(on)	.1 @ 125	.620"	.69 x .69 x .75	.20"	Screw	6 colors	4.95	4.49	3.95
315643	ValuePro	R13-81-R	8	2	SPST off-(on)	.5 @ 125	.203"	.44 (D) x .78 (T)	.08"	PC terminal	Red	.95	.85	.75
164671	ValuePro	NS-801MO-BLACK	18	2	SPST off-(on)	1 @ 125	.480"	1.0 (D) x 1.1 (T)	.16"	Solder lugs	Black	1.95	1.75	1.49
2238186	ValuePro	GR18-29B	9	2	SPST off-(on)	1 @ 125	.250"	.65 (D) x 1.1 (T)	.148"	Solder lugs	Black	.89	.79	.75
2267983	Mountain Switch	107-6613	10	2	SPST off-(on)	1 @ 125	.61"L x .40"W	.61 x .46 x .71	.20"	PC Terminal	Gray/Gr illum.	1.49	1.25	1.09
71643	ValuePro	SWB210	11	2	SPST off-(on)	1 @ 120	.219"	.36 x .20 x .33	.20"	PC right angle	Black	2.75	2.49	2.25
2210870	Leviton	PB-1A-125-W	12	2	SPST off-(on)	1 @ 125 & .25 @ 250	.370"	.90 x .63 x .73	.80"	6" wire LDS	Black	1.49	1.25	1.09
2266823	Mountain Switch	103-1209-EV	13	2	SPST off-(on)	1 @ 125 & .5 @ 250	.49"L x .44"W	.57 x .44 x .80	.25"	Solder lugs	Green	1.49	1.25	1.09
2229626	C&K Switch	8531-S-C-Q	8	2	SPST off-(on)	1 @ 250	.250"	.23 (D) x 1.1 (T)	.21"	PC terminal	Black	3.95	3.59	3.29
2268063	ValuePro	R13-504A-05-BB	14	2	SPST off-(on)	2 @ 125 & 1 @ 250	.57"L x .57"W	.62 x .62 x .73	.65"	Solder lugs	Black	1.25	1.09	.99
2131274	Velleman	R1400A	15	2	SPST off-(on)	2 @ 48VDC	.750"	.87 (D) x 1.2 (T)	.37"	Screw	Silver	3.95	3.59	3.29
171774	Apem	AV191003C900	15	2	SPST off-(on)	2 @ 48VDC	.750"	.87 (D) x 1.2 (T)	.37"	Screw	Silver	13.95	12.49	10.95
2267807	Mountain Switch	107-3025-EVX	16	2	SPST off-(on)	3 @ 120 & 1 @ 250	.195"	.20 x .56 x .85	.20"	PC right angle	Black	2.49	2.25	1.95
2267815	Mountain Switch	107-3026-EVX	17	2	SPST off-(on)	3 @ 120 & 1 @ 250	.195"	.40 x .20 x .48	.20"	PC terminal	Black	2.49	2.25	1.95
26623	ValuePro	MS102	9	2	SPST off-(on)	3 @ 125	.250"	.65 (D) x 1.10 (T)	.14"	Solder lugs	Red	.89	.79	.75
315432	ValuePro	R13-23A-R	1	2	SPST off-(on)	3 @ 125	.480"	1.13 (D) x 1.53 (T)	.20"	Solder lugs	Red	1.49	1.25	1.09
174414	ValuePro	R13-510A	4	2	SPST off-(on)	3 @ 125	.500"	.82 (D) x 1.02 (T)	.16"	Solder lugs	Red	1.75	1.49	1.25
2231865	ValuePro	662412	9	2	SPST off-(on)	3 @ 125	.275"	.57 (D) x 1.0 (T)	.14"	Solder lugs	Black	.99	.89	.79
315599	ValuePro	R13-40A-R	2	2	SPST off-(on)	3 @ 125	.480"	.98 (D) x 1.56 (T)	.20"	Solder lugs	Red	1.49	1.25	1.09
315791	ValuePro	R13-508A-05-BB	4	2	SPST off-(on)	3 @ 125	.630"	.94 (D) x 1.16 (T)	.24"	Solder lugs	Black	1.49	1.25	1.09

§ Illuminated: red/green # Silver body ✓ Use 2202132 cap Additional panel mounting hardware: † 2182688, see pg 78

Continued on next page

* For additional products, availability and specifications visit Jameco.com and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at www.Jameco.com