

# Toggle Switches


 


JAMECO ValuePro

## Standard Toggle Switches

\*Web Code: NAJ

- Mounting hole diameter: 1/2"
- Shaft thread: M12 x 0.75
- Waterproof boot seals (below)

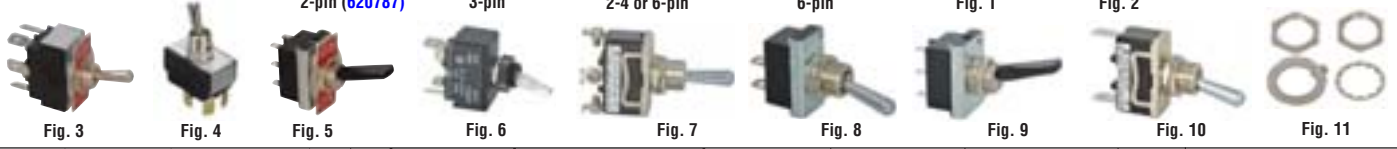

Part No.	Manufacturer	Product No.	Fig.	Pins	Contact Form	Contact Rating (A @ VAC)	Dimensions (L" x W" x D")	Lead Spacing			Terminal Type	Lever Type	Pricing		
								A"	B"	C"			1	10	100
76241	ValuePro	SWM128	1	2	SPST on-off	4 @ 125 & 2 @ 250	1.00 x .56 x .52	.23	—	—	Solder lugs	Round	\$1.95	\$1.75	\$1.49
76232	ValuePro	SWM125	2	2	SPST on-off	6 @ 125 & 3 @ 250	1.00 x .53 x .51	.23	—	—	6" lead wire	Round	1.95	1.75	1.55
2269583	ValuePro	R13-25A2-01	8	2	SPST on-off	10 @ 125 & 6 @ 250	1.10 x .79 x .87	—	.37	—	.250" quick connect	Round	2.95	2.59	2.29
317825	ValuePro	R13-25A2-01	3	2	SPST on-off	10 @ 125 & 6 @ 250	1.14 x .59 x .62	.38	—	—	.250" quick connect	Round	2.95	2.59	2.29
2266807	Mountain Switch	103-0010-EVX✓	10	2	SPST on-off	15 @ 125 & 10 @ 250	1.20 x .62 x 1.2	—	1.0	—	.250" quick connect	Round	4.95	4.49	3.95
318027	ValuePro	R13-28A-06	3	2	SPST on-off	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.46	—	M3 screw	Round	2.75	2.49	2.25
318002	ValuePro	R13-28A-01	3	2	SPST on-off	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.57	—	.250" quick connect	Round	3.25	2.95	2.59
2266759	Mountain Switch	103-0001-EVX\$✓	8	3	SPST on-off	20 @ 12VDC (White)	1.10 x .63 x 2.5	—	1.0	—	.250" quick connect	Round	4.95	4.49	3.95
2266767	Mountain Switch	103-0002-EVX\$✓	8	3	SPST on-off	20 @ 12VDC (Blue)	1.10 x .63 x 2.5	—	1.0	—	.250" quick connect	Round	4.95	4.49	3.95
2266775	Mountain Switch	103-0003-EVX\$✓	8	3	SPST on-off	20 @ 12VDC (Green)	1.10 x .63 x 2.5	—	1.0	—	.250" quick connect	Round	4.95	4.49	3.95
621499	GC Electronics	35-3005*	4	2	SPST on-off	20 @ 125 & 10 @ 250	.92 x .64 x .40	.47	—	.96	.250" quick connect	Round	4.95	4.49	3.95
158060	ValuePro	JKN32†	1	4	SPDT on-off	4 @ 125 & 2 @ 250	1.00 x .56 x .52	.23	.65	.23	Solder lugs	Round	1.25	1.09	.99
2266799	Mountain Switch	103-0007-EVX\$✓	6	5	SPDT on-off	30 @ 12VDC (Red/Green)	1.35 x .75 x 1.30	.45	.44	—	.250" quick connect	Flat	4.95	4.49	3.95
2266791	Mountain Switch	103-0006-EVX\$✓	6	5	SPDT on-on	30 @ 12VDC (Red/Green)	1.35 x .75 x 1.30	.45	.44	—	.250" quick connect	Flat	4.95	4.49	3.95
2266847	Mountain Switch	103-13293-EVX	7	3	SPDT on-off-on	15 @ 125 & 10 @ 250	1.20 x .62 x 1.0	—	.57	—	M3 Screw	Round	4.95	4.49	3.95
318123	ValuePro	R13-28D-01	3	3	SPDT on-off-on	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.65	.45	.250" quick connect	Round	2.75	2.49	2.25
2266783	Mountain Switch	103-0005-EVX\$✓	6	5	SPDT on-off-on	30 @ 12VDC (Red/Clear/Gm)	1.35 x .75 x 1.30	.45	.44	—	.250" quick connect	Flat	4.95	4.49	3.95
2229749	Arndt	DPDT-C-OFE	3	6	DPDT on-off	10 @ 125 & 20 @ 125	1.31 x .75 x .75	.45	.44	.45	M3 screw	Round	2.75	2.49	2.25
2269591	Arndt	R13-25B1-05	9	6	DPDT on-on	10 @ 125 & 6 @ 250	1.10 x .79 x .87	.32	.37	—	Solder lugs	Flat	3.25	2.95	2.59
317850	ValuePro	R13-25B1-05P	5	6	DPDT on-on	10 @ 125 & 6 @ 250	1.14 x .79 x .62	.40	.38	.40	Solder lugs	Flat	3.49	3.19	2.79
158078	ValuePro	JKN3CC	3	6	DPDT on-on	15 @ 125 & 10 @ 250	1.19 x .76 x .73	.44	.59	1.0	Screw lugs	Round	1.75	1.49	1.25
318043	ValuePro	R13-28B-01	3	6	DPDT on-on	15 @ 125 & 10 @ 250	1.33 x .75 x .75	.45	.61	2.5	.250" quick connect	Round	4.95	4.49	3.95
567761	ValuePro	T-1224	3	6	DPDT on-off-on	10 @ 125 & 5 @ 250	1.18 x .77 x .75	.40	.60	2.64	M3 screw	Round	3.95	3.59	3.29
2269575	ValuePro	R13-25E1-05	9	6	DPDT on-off-on	10 @ 125 & 6 @ 250	1.10 x .79 x .87	.32	.37	—	Solder lugs	Flat	3.25	2.95	2.59
317972	ValuePro	R13-25E1-05P	5	6	DPDT on-off-on	10 @ 125 & 6 @ 250	1.14 x .59 x .62	.38	.38	.38	Solder lugs	Flat	3.49	3.19	2.79
2265959	ValuePro	L603T3B3H2	3	6	DPDT on-off-on	20 @ 125 & 10 @ 250	1.20 x .72 x .76	.58	.66	.58	M3 screw	Round	5.95	5.49	4.95
2182733	ValuePro	M12HDWR	11	Additional M12 hardware (2 hex nuts, 1 internal lock washer, 1 key lock washer)									.99	.89	.79

\* Shaft thread: 15/32-32 use 2182506 (pg 78) for additional panel mounting hardware † Alternate action \$ Illuminated ✓ Sealed

## Protective and Waterproof Boot Seal Switch Covers

- Full protection from water, oil, sand, dust, dirt, humidity, moisture and other contaminants
- Applications: aerospace, automotive, computer and electronic equipment
- IP68 rated

\*Web Code: SBS



Part No.	Manufacturer	Product No.	Description	Dimensions	1	10	100
2150192	Zago	TH 606-GY	Toggle switch boot seal, gray, 15/32-32, fits standard toggle switches (above)	0.625" OD x 0.209" ID x 0.890"H	\$1.95	\$1.75	\$1.49
2192683	Zago	TH609-BLK	Toggle switch boot seal, black, 15/32-32, fits standard toggle switches (above)	0.324" OD x 0.226" ID x 0.937"H	1.95	1.75	1.49


## Miniature Toggle Switches

C&K Alcoswitch



\*Web Code: PAJ

- Mounting hole dia.: 1/4"
- Thread: 1/4-40 UNS-2B
- See page 63 for waterproof boot seals

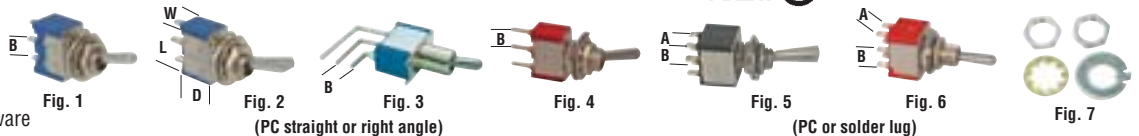

Includes: Panel mounting hardware

(PC straight or right angle)

(PC or solder lug)

Part No.	Mfr.	Product No.	Fig.	Pins	Contact Form ( ) Momentary	Contact Rating (A @ VAC)	Dimensions (L" x W" x D")	Lead Spacing		Terminal Type	Lever Type	Pricing		
								A"	B"			1	10	100
2135478	JVP	T100T1B4A2	3	2	SPST on-off	5 @ 120 & 2 @ 250	.50 x .28 x .35	—	0.185	PC straight	Round	\$1.49	\$1.25	\$1.09
317228	JVP	1MS9T1B1M1QE <sup>1</sup>	1	2	SPST on-off	5 @ 120 & 2 @ 250	.50 x .27 x .35	—	0.185	Solder lugs	Round	1.75	1.59	1.45
317287	JVP	1MS9T6B11M1QE <sup>1</sup>	2	2	SPST on-off	5 @ 120 & 2 @ 250	.50 x .27 x .35	—	0.185	Solder lugs	Flat	1.95	1.75	1.49
76523	JVP	JMT113 <sup>1</sup>	1	2	SPST on-off	5 @ 125 & 2 @ 250	.52 x .32 x .38	—	0.185	Solder lugs	Round	1.49	1.25	1.09
2230328	JVP	66-1201	1	2	SPST on-off	6 @ 125 & 3 @ 250	.52 x .31 x .37	—	0.190	Solder lugs	Round	1.25	1.09	.99
2235735	CAR	2M1-SP1-T7-B0-M2RE <sup>2</sup>	4	3	SPST on-on	0.4VA @ 20VDC/AC	.50 x .27 x .39	—	0.185	PC straight	Round	1.49	1.25	1.09
75854	JVP	T101T1B1A1QN <sup>1</sup>	1	3	SPDT on-on	5 @ 120 & 2 @ 250	.52 x .32 x .38	—	0.185	Solder lugs	Round	1.19	1.09	.99

1,2: See page 64 for the note

Continued on next page

\* CAR = Carling Technologies | JVP = ValuePro

\* For additional products, availability and specifications visit [Jameco.com](http://Jameco.com) and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at [www.Jameco.com](http://www.Jameco.com)